


- Ideal for moving large or heavy loads
- Completely smooth surfaces
- With double hinge
- Materials:
 - Plates: low friction acetal
 - Pin: stainless steel 304
- Operating temp.: -40°C to +85°C (+70°C in humid environments)
- Length 3048mm (80 plates)

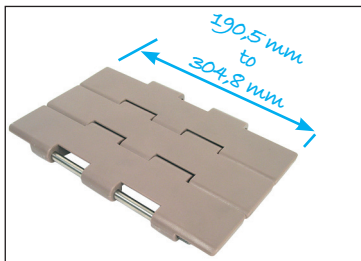

 
 

Advantages

- Large width
- High carrying capacity

Associated products

- Drive sprocket **PT821**
- Idler sprocket **PR821**
- Idler **DBL821**

Direction of travel

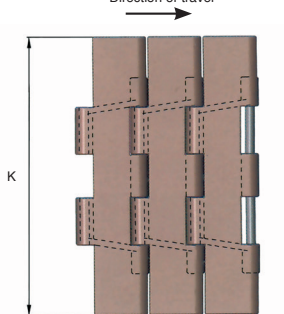

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP821-190	190,5	3048	6500	2,50	268,68 €
CAP821-254	254,0	3048	6500	2,95	283,64 €
CAP821-304	304,8	3048	6500	3,25	312,37 €

Dimensions in mm

Our other products



D19 D29

Compression springs in metre length stainless steel, by the metre



 
BPHF

Ball transfer unit push fit, Heavy



TSRTC

Stem support for caster, For swivel caster with central hole



M1

Worm and wheel set, Machined plastic (delrin)



GBS

Nut for ballscrew, Flanged ballscrew nut



AC156-157

Strike for toggle latch, 25.5mm




RHTtcss

High Temperature Castor, up to 200kg



YG1

 HEAVY DUTY spur gear, Steel 35NCD6



PRZ

Wear strip for slat top chain, Z profile to be clipped



FR

Steel thread inserts, Steel



DB

Steel bevel gear, 2:1



SCA

Flat cable clamp, Steel

Complementary products




PT821

Drive sprocket for slat top chain, Ranges 821 and 805



PR821

Idler sprocket for slat top chain, Ranges 821 and 805

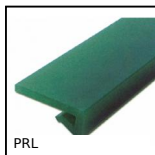

PRL

Wear strip for slat top chain, L profile to be clipped