

# Side flexing slim plate chain



## CAP880T

## Range 880 TAB

- Bending radius allows chain to follow a curved path


- Materials:

Plates: low friction acetal

Pin: stainless steel 304

- Operating temp.: -40°C to +85°C  
(+70°C in humid environments)

- Length 3048mm (80 plates)

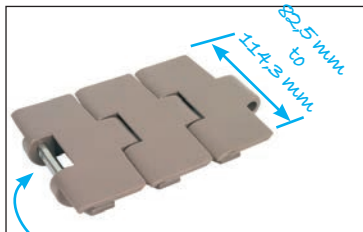

### Advantages

- Special shape prevents products being carried moving or falling whilst on curves

### Associated products

 

- Drive sprocket **PT880**

- Idler sprocket **PR880**


- Idler **DBL880**

- Straight track **GRD880T**


- Curved track **GCB880T**

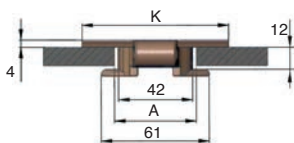

A  $\left\{ \begin{array}{l} \text{Straight} - 46 \\ \text{Curved} - 44,2 \end{array} \right.$

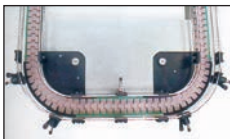

Typical application

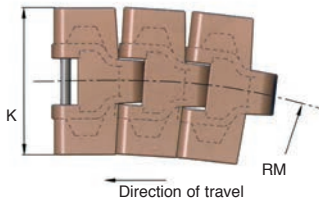


### DISCOUNTS

Qty	1+	5+	10+
Disc. List	-5%	On request	

Part number	Width K (mm)	Length (mm)	Bend radius RM (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP880T-82	82,5	3048	457	5200	1,04	115,13 €
CAP880T-114	114,3	3048	532	5200	1,21	132,26 €

Dimensions in mm
 
## Our other products



PF30NM

Worm and wheel gear reducer, up to 8.8 Nm



E20

Right angle helical reducers, from 0.60 to 3.84 Nm



H2

Crossed helical gear crossed axis at 90°, Steel 20NCD2



VHEH

Hexagonal headed screw with collar Hygienic Usit®, Stainless steel



PSPT

Flexible tube handle, PVC




NSA

Adjustable clamp, Articulated



DOMI80

Accessories, Turntable

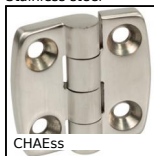

CHAess

Decorative hinge, Stainless steel



VTAP

Magnetic head screw, With rubber coating



ABL100000

Antistatic brush, For sensitive surfaces



TFR

Rigid manual tensioner, Fixed



PRF\_JL6

Lip seal for panel, Door seal - Ø 6mm

## Complementary products



PR880

Idle sprocket for slat top chain, Range 880



PT880

Drive sprocket for slat top chain, Range 880



CAP881

Side flexing slim slat top chain stainless steel, Narrow range 881



GDR880

Straight track for slat top chain, Ranges 880 and 881