

# Side flexing slim plate chain



## CAP880T

## Range 880 TAB

- Bending radius allows chain to follow a curved path


- Materials:

Plates: low friction acetal

Pin: stainless steel 304

- Operating temp.: -40°C to +85°C  
(+70°C in humid environments)

- Length 3048mm (80 plates)

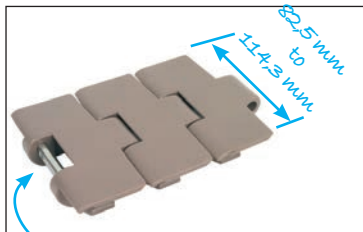

### Advantages

- Special shape prevents products being carried moving or falling whilst on curves

### Associated products


- Drive sprocket **PT880**

- Idler sprocket **PR880**




- Idler **DBL880**

- Straight track **GRD880T**

- Curved track **GCB880T**

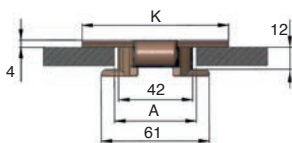

 A  $\left\{ \begin{array}{l} \text{Straight} - 46 \\ \text{Curved} - 44,2 \end{array} \right.$

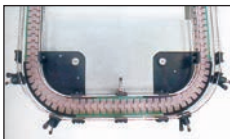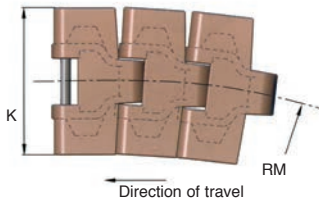

Typical application

### DISCOUNTS

Qty	1+	5+	10+
Disc. List	-5%	On request	

Part number	Width K (mm)	Length (mm)	Bend radius RM (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP880T-82	82,5	3048	457	5200	1,04	115,13 €
CAP880T-114	114,3	3048	532	5200	1,21	132,26 €

Dimensions in mm

## Our other products



STL

Guidance brush - Rail,  
Rail



ALCRP

Wheel for aluminium  
profile, Integrated  
bearing



CHTRB

Single and dual  
output gearboxes, Up  
to 4,7 Nm



PV2R

Adjustable suction-  
cup support,  
Increased grip



PRES

Manual workbench  
press accessory for  
PRES-3HR end  
PRES-4HR, Set of s...



CLG1

Moulded plastic spur  
gear, Moulded plastic  
(nylon)



H02SS

Needle roller universal  
joint - Stainless steel,  
Heavy duty  
DIN808-7...



BABTV

Ball lock pins lockable  
, Stainless steel



VTA

Vari-Tork® slip  
friction clutch, 0.53 to  
1.32 Nm



CHM30

Worm and wheel gear  
reducer, up to 28 Nm



GALRUB

60mm rubber wheel  
for conveyor belt,  
Rubber



PGNT

Thermoplastic T  
handle, With threaded  
spindle

## Complementary products



PR880

Idler sprocket for slat  
top chain, Range 880



PT880

Drive sprocket for slat  
top chain, Range 880



CAP881

Side flexing slim slat  
top chain stainless  
steel, Narrow range  
881



GDR880

Straight track for slat  
top chain, Ranges 880  
and 881