

Side flexing slim plate chain



CAP880T

Range 880 TAB

- Bending radius allows chain to follow a curved path


- Materials:

Plates: low friction acetal

Pin: stainless steel 304

- Operating temp.: -40°C to +85°C
(+70°C in humid environments)

- Length 3048mm (80 plates)

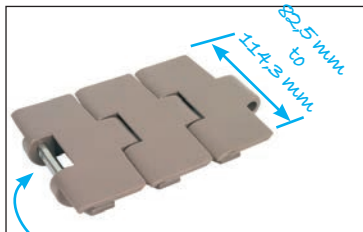

Advantages

- Special shape prevents products being carried moving or falling whilst on curves

Associated products


- Drive sprocket **PT880**

- Idler sprocket **PR880**




- Idler **DBL880**

- Straight track **GRD880T**

- Curved track **GCB880T**

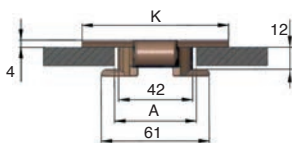

 A $\left\{ \begin{array}{l} \text{Straight} - 46 \\ \text{Curved} - 44,2 \end{array} \right.$

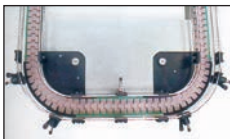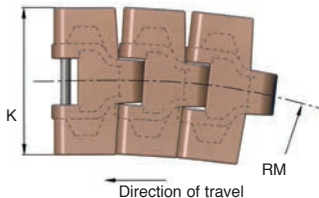

Typical application

DISCOUNTS

Qty	1+	5+	10+
Disc. List	-5%	On request	

Part number	Width K (mm)	Length (mm)	Bend radius RM (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP880T-82	82,5	3048	457	5200	1,04	115,13 €
CAP880T-114	114,3	3048	532	5200	1,21	132,26 €

Dimensions in mm

Our other products



TRMSS

Spur round rack,
Stainless steel -
module 1-5



 
WINGbrEcrou

Manually tightened
wing nut, Brass DIN
315



JCDss

Universal joint -
stainless steel, Low
duty



SLHHlok

Horizontal toggle
clamp, Horizontal
toggle clamp /
horizontal foot



GPB

Threaded spherical
knob, Moulded thread



VTHbr

Hexagonal headed
screw VTH - DIN 933,
Brass



S_ZZ

Stainless steel ball
bearings, Stainless
steel



DB_ECO

Eco. range steel bevel
gear, 2:1



AKN

Bellows coupling
Gerwah®, from 22 to
180Nm



IBjss

Ball and socket joint,
Stainless steel



SLV

Vertical toggle clamp,
Vertical Lever Clamp -
stainless steel



EX

Optional shaft for E-
type gear reducers, E
Gearboxes double
sided ou...

Complementary products



PR880

Idler sprocket for
plate chain, Range
880



PT880

Drive sprocket for
plate chain, Range
880



CAP881

Side flexing slim plate
chain stainless steel,
Narrow range 881



GDR880

Straight track for
plate chain, Ranges
880 and 881