



Side flexing slim plate chain **stainless steel**

Range 881 TAB


CAP881Tss

- Bending radius allows chain to follow a curved path
- Materials:
 - Plates: polished cold-laminated stainless steel (30HRC min.)
 - Pin: stainless steel 302 (1400N/mm²)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)
- Length 3048mm (80 plates)



Associated products


- Drive sprocket **PT881**
- Idler sprocket **PR881**
- Idler **DBL880**
- Straight track **GRD880T**
- Curved track **GCB880T**

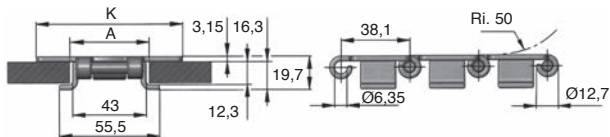

A $\left\{ \begin{array}{l} \text{Straight} - 46 \\ \text{Curved} - 44,5 \end{array} \right.$



Typical application

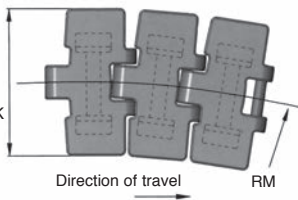

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Bend radius		Breaking load (N)	Weight (kg/m)	Price each 1 to 4
			RM (mm)				
CAP881T-82/SS	82,5	3048	500		9500	2,9	221,65 €
CAP881T-114/SS	114,3	3048	500		9500	3,6	286,56 €

Dimensions in mm

Our other products



BPMc
Stainless steel slotted
spring plunger with
ceramic ball tip, 303
St...



SLB
Indexing plunger,
stainless steel



SH0
Parallel axis helical
gear, Machined plastic
(delrin)



PRFSRAD
Dual lock for
aluminium profile,
Quick fitting, self
locking door du...




RTL450
Self-centering locking
assembly, High torque



AT10courroie
AT type timing belt,
AT10 Steel cored
polyurethane



 DOG258
Motor-gearbox 12V
and 24V DC, from 12
to 15 Nm



RPP
Connecting plate for
RPP type timing belts,
RRP5



BPHT
Ball transfer unit bolt
fitting, Heavy



RFVbr
Stainless steel
reaction arm,
Reaction arm



NRR
Adjustable support
clamp, Adjustable
support clamp



CHA38_SS
Stainless steel face
frame hinge, Surface
mount

Complementary products



PT881
Drive sprocket for slat
top chain, Range 881



PR881
Idler sprocket for slat
top chain, Range 881



CAP880
Side flexing slim slat
top chain acetal,
Narrow range 880