



Side flexing slim plate chain **stainless steel**

Range 881 TAB


CAP881Tss

- Bending radius allows chain to follow a curved path
- Materials:
 - Plates: polished cold-laminated stainless steel (30HRC min.)
 - Pin: stainless steel 302 (1400N/mm²)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)
- Length 3048mm (80 plates)



Associated products


- Drive sprocket **PT881**
- Idler sprocket **PR881**
- Idler **DBL880**
- Straight track **GRD880T**
- Curved track **GCB880T**

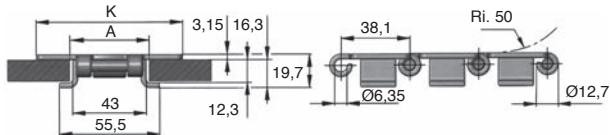

A $\left\{ \begin{array}{l} \text{Straight} - 46 \\ \text{Curved} - 44,5 \end{array} \right.$



Typical application

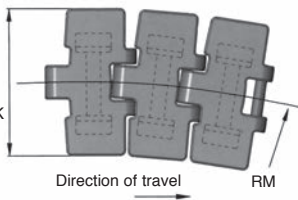

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Bend radius		Breaking load (N)	Weight (kg/m)	Price each 1 to 4
			RM (mm)				
CAP881T-82/SS	82,5	3048	500		9500	2,9	221,65 €
CAP881T-114/SS	114,3	3048	500		9500	3,6	286,56 €

Dimensions in mm

Our other products



ETP

Modular handle for aluminium profile,
Modular handle



DB

Steel bevel gear, 2:1



AHEX

Hexagonal shaft,
Hexagonal shaft




UCFL_PBT

Stainless steel/Polymer flanged bearing, Polymer and stainless steel



PV1R

Adjustable suction-cup support, Standard grip

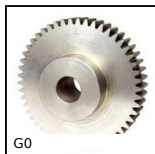

G0

Steel spur gear, Steel 20NCD2



HTD8M_50

HTD Heavy duty timing pulley, HTD8 Cast



UCP_PBT

Stainless/Polymer pillow block bearing, Polymer and stainless steel



NSB

Standard linear bearing housing,



DOMI50

Accessories, Plate



ETQ

Magnetic label holder for aluminium profile,



NSKB

Drylin® Rail end cap,
Rail end cap

Complementary products



PT881

Drive sprocket for slat top chain, Range 881



PR881

Idler sprocket for slat top chain, Range 881



CAP880

Side flexing slim slat top chain acetal,
Narrow range 880