



Side flexing slim plate chain **stainless steel**

Range 881 TAB


CAP881Tss

- Bending radius allows chain to follow a curved path
- Materials:
 - Plates: polished cold-laminated stainless steel (30HRC min.)
 - Pin: stainless steel 302 (1400N/mm²)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)
- Length 3048mm (80 plates)



Associated products


- Drive sprocket **PT881**
- Idler sprocket **PR881**
- Idler **DBL880**
- Straight track **GRD880T**
- Curved track **GCB880T**

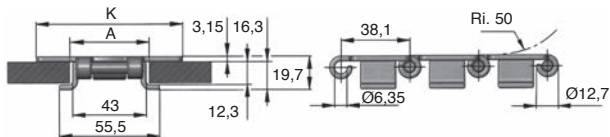

A $\left\{ \begin{array}{l} \text{Straight - 46} \\ \text{Curved - 44,5} \end{array} \right.$



Typical application

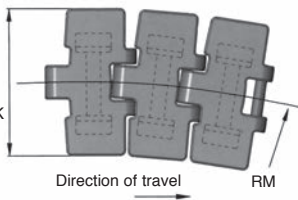

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Bend radius		Breaking load (N)	Weight (kg/m)	Price each 1 to 4
			RM (mm)				
CAP881T-82/SS	82,5	3048	500		9500	2,9	221,65 €
CAP881T-114/SS	114,3	3048	500		9500	3,6	286,56 €

Dimensions in mm

Our other products



MRAeco
Low cost quick link,
Steel



BAP
Plastic clamping
collar, Ø10 - Ø20



SME
Male rod ends ,
Stainless steel / PTFE



MDB_MTB
Moulded plastic bevel
gear (nylon), 2:1



PTA150
Articulated levelling
foot, pressed base
Ø150, Ø 150



DPAR_DKON
Progressive stop,
Steel



UCP_SS
Stainless steel pillow
block bearing,
Stainless steel



H1
Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



PF40
Worm and wheel gear
reducer, up to 18 Nm



AC156-157
Strike for toggle latch,
25.5mm



GLB
Small 6 lobe threaded
handle - female,
Technopolymer -



PTAF100-PAMF100
Articulated fixable
foot with pressed
base Ø100, Ø 100

Complementary products



PT881
Drive sprocket for slat
top chain, Range 881



PR881
Idler sprocket for slat
top chain, Range 881



CAP880
Side flexing slim slat
top chain acetal,
Narrow range 880