



Side flexing slim plate chain **stainless steel**

Range 881 TAB


CAP881Tss

- Bending radius allows chain to follow a curved path
- Materials:
 - Plates: polished cold-laminated stainless steel (30HRC min.)
 - Pin: stainless steel 302 (1400N/mm²)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)
- Length 3048mm (80 plates)



Associated products


- Drive sprocket **PT881**
- Idler sprocket **PR881**
- Idler **DBL880**
- Straight track **GRD880T**
- Curved track **GCB880T**

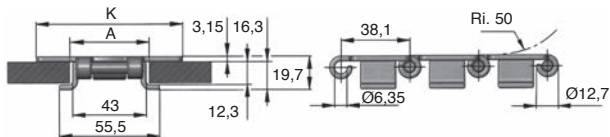

A $\left\{ \begin{array}{l} \text{Straight} - 46 \\ \text{Curved} - 44,5 \end{array} \right.$



Typical application

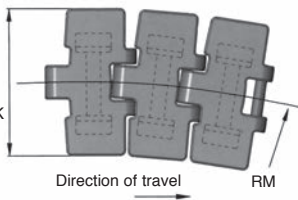

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Bend radius		Breaking load (N)	Weight (kg/m)	Price each 1 to 4
			RM (mm)				
CAP881T-82/SS	82,5	3048	500		9500	2,9	221,65 €
CAP881T-114/SS	114,3	3048	500		9500	3,6	286,56 €

Dimensions in mm

Our other products



CHAFR-MINI
Miniature friction
hinge, Friction



HBM
Adjustment bushing
for half-rail guide,
Adjustment bushing



GP
Spring loaded toggle
latch, With padlock-
holder



TSRTC
Stem support for
caster, For swivel
caster with central
hole



SLBW
Indexing plunger,
weldable, Weldable -
Steel



CLB_M
Die cast zinc clamping
lever - female, Zamak



SCE_SS
Stainless steel U-
shaped clamp,
Stainless steel



PR125
Articulated foot Ø123,
Ø 123




HDSS
Needle roller double
universal joint -
Stainless steel, Heavy



KKSS
Rounded end feather
key, Stainless steel



DIL
Lever operated
locking bolt, lever
clamp

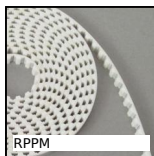

RPPM
RPP type belt per
metre, RPP14 Steel
cored polyurethane

Complementary products



PT881
Drive sprocket for slat
top chain, Range 881



PR881
Idler sprocket for slat
top chain, Range 881



CAP880
Side flexing slim slat
top chain acetal,
Narrow range 880