



Side flexing slim plate chain **stainless steel**

Range 881 TAB


CAP881Tss

- Bending radius allows chain to follow a curved path
- Materials:
 - Plates: polished cold-laminated stainless steel (30HRC min.)
 - Pin: stainless steel 302 (1400N/mm²)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)
- Length 3048mm (80 plates)



Associated products


- Drive sprocket **PT881**
- Idler sprocket **PR881**
- Idler **DBL880**
- Straight track **GRD880T**
- Curved track **GCB880T**

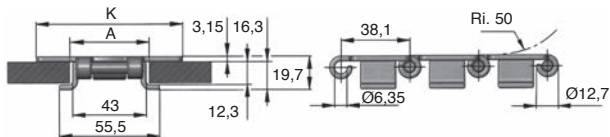

A $\left\{ \begin{array}{l} \text{Straight} - 46 \\ \text{Curved} - 44,5 \end{array} \right.$



Typical application

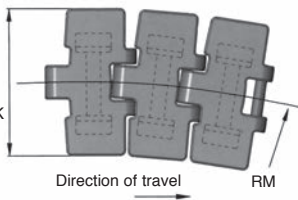


DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Bend radius		Breaking load (N)	Weight (kg/m)	Price each 1 to 4
			RM (mm)				
CAP881T-82/SS	82,5	3048	500		9500	2,9	221,65 €
CAP881T-114/SS	114,3	3048	500		9500	3,6	286,56 €

Dimensions in mm

 Our other products



TBV
Manual lifting tables,
3kg



 
BPL
Ball transfer unit light
duty, Light



PW_PWG25
Worm - precision
range, Steel



ACLAPA
Magnetic stop for
aluminium profile,
Magnetic stop



T2
T type timing belt,
T2.5 Steel cored
polyurethane



J65
Spur gear coaxial
gearbox, from 0.80 to
2.95 Nm - Inline



ADSR
Backlash free
coupling Gerwah®,
from 12.5 to 525Nm



PGNT
Thermoplastic T
handle, With threaded
insert




SER
Magnetic doorstop for
aluminium profile,
Magnetic doorstop



INS_BR
Self tapping brass
insert, Brass



 NT122
Spur gear coaxial
gearbox, from 32 to
85 Nm - Inline



H0
Crossed helical gear
crossed axis at 90°,
Machined plastic
(delrin)

Complementary products



PT881
Drive sprocket for slat
top chain, Range 881



PR881
Idler sprocket for slat
top chain, Range 881



CAP880
Side flexing slim slat
top chain acetal,
Narrow range 880