

Side flexing wide plate chain



CAP882T

Range 882 TAB

- Bending radius allows chain to follow a curved path

- Materials:

Plates: self lubricating brown acetal

Pin: stainless steel 304

- Operating temp.: -40°C to +85°C
(+70°C in humid environments)

- Length 3048mm (80 plates)



Advantages

- Special shape prevents products being carried moving or falling whilst on curves

Associated products


- Drive sprocket **PT882**

- Idler sprocket **PR882**

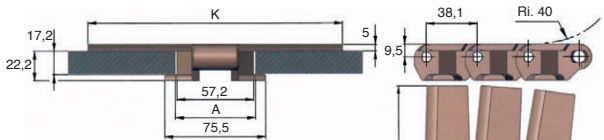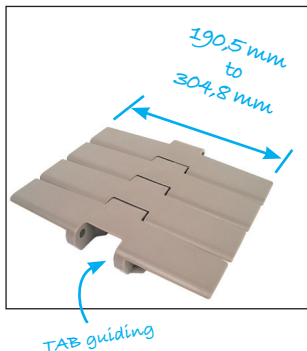

A $\left\{ \begin{array}{l} \text{Straight} - 60 \\ \text{Curved} - 58 \end{array} \right.$

Direction of travel

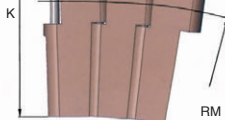

Typical application

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Bend radius		Breaking load (N)	Weight (kg/m)	Price each 1 to 4
			RM (mm)	RM (mm)			
CAP882T-190	190,5	3048	610	8000	2,43	284,83 €	
CAP882T-254	254,0	3048	610	8000	2,87	296,96 €	
CAP882T-304	304,8	3048	610	8000	3,41	325,33 €	

Dimensions in mm

Our other products



Screw-in garnet hinge, Screw-on



Crossed helical gear crossed axis at 90°, Steel 20NCD2



 
Offset spur gear reducer, from 111 to 425 Nm



T type timing belt per metre, T10 Steel cored polyurethane



Stainless steel protective cover, Closed protective cover



Stainless steel cylindrical stop, stainless steel



Indexing plunger, stainless steel



Flat suction cup, nitrile



Long-Lok spring plunger with internal hexagonal socket,



Articulated foot Ø83, Ø 83



Anchoring bracket for aluminium profile, Anchor



Motor-gearbox 12V and 24V DC, from 0,075 to 0,6Nm

Complementary products



Drive sprocket for slat top chain, Range 882



Idler sprocket for slat top chain, Range 882