

Side flexing wide plate chain



CAP882T

Range 882 TAB

- Bending radius allows chain to follow a curved path

- Materials:

Plates: self lubricating brown acetal

Pin: stainless steel 304

- Operating temp.: -40°C to +85°C
(+70°C in humid environments)

- Length 3048mm (80 plates)



Advantages

- Special shape prevents products being carried moving or falling whilst on curves

Associated products

- Drive sprocket **PT882**

- Idler sprocket **PR882**

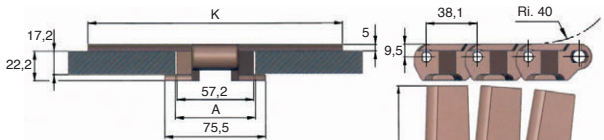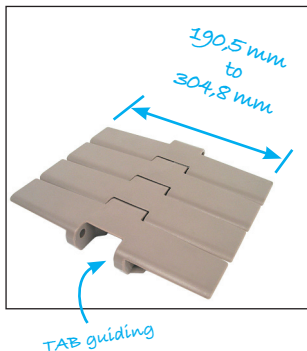

A $\left\{ \begin{array}{l} \text{Straight} - 60 \\ \text{Curved} - 58 \end{array} \right.$

Direction of travel



Typical application


DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Bend radius		Breaking load (N)	Weight (kg/m)	Price each 1 to 4
			RM (mm)	RM (mm)			
CAP882T-190	190,5	3048	610	8000	2,43	284,83 €	
CAP882T-254	254,0	3048	610	8000	2,87	296,96 €	
CAP882T-304	304,8	3048	610	8000	3,41	325,33 €	

Dimensions in mm

 
Our other products



PO
Pull handle - Multi-sector, Smooth hole



 PSG25
Spur gear - precision range, Case hardened steel 20NCD2



IN1
Internal gear, Machined plastic (delrin)



DBL805
Idler for slat top chain, Range 805



SLB
Indexing plunger, steel class 5.8



PF60
Worm and wheel gear reducer, up to 118 Nm



ES
Bipod support base, Plastic



CT
Telescopic universal joint, Normal duty



PCS_PA6
Plastic sprocket, 12.7mm (DIN 08B-1)



AC
Strike for toggle latch, 13mm



SF_ZZ
Deep groove ball bearing, Stainless



G2
Steel spur gear, Steel 20NCD2

Complementary products



PT882
Drive sprocket for slat top chain, Range 882



PR882
Idler sprocket for slat top chain, Range 882