

Side flexing wide plate chain



CAP882T

Range 882 TAB



- Bending radius allows chain to follow a curved path
- Materials:
 - Plates: self lubricating brown acetal
 - Pin: stainless steel 304
- Operating temp.: -40°C to +85°C (+70°C in humid environments)
- Length 3048mm (80 plates)

Advantages

- Special shape prevents products being carried moving or falling whilst on curves

Associated products

- Drive sprocket **PT882**
- Idler sprocket **PR882**

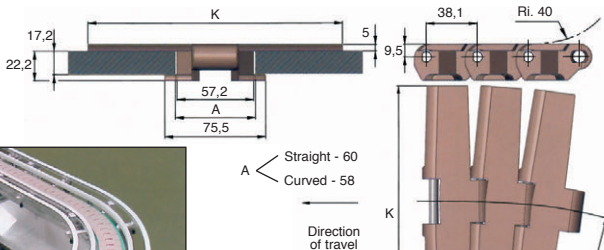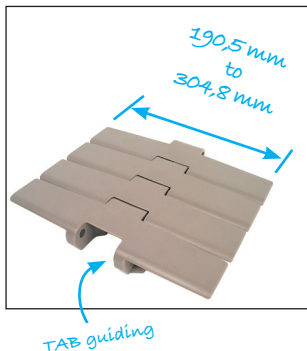

Typical application

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Bend radius		Breaking load (N)	Weight (kg/m)	Price each 1 to 4
			RM (mm)				
CAP882T-190	190,5	3048	610		8000	2,43	284,83 €
CAP882T-254	254,0	3048	610		8000	2,87	296,96 €
CAP882T-304	304,8	3048	610		8000	3,41	325,33 €

Dimensions in mm

Our other products



CHT

Asynchronous AC Motor 1.1 to 1.85kW, 1.1 to 1.85kW



CHAR7520

Spring hinge, screwed



RURp

Swivel castor with double brake, Polyurethane - Aluminium rim (Free)



DOMI50

Connecting kits, XZ linking kit



UCP PBT

Stainless/Polymer pillow block bearing, Polymer and stainless steel



BOX-SHNA

Hexagonal nut - DIN934, Box set of steel nuts



RAG-12-M8

Roller guide accessory, Anchoring system



G2

Steel spur gear, Steel 20NCD2



HTD14M_55

HTD Heavy duty timing pulley, HTD14




PV2R

Adjustable suction-cup support,



RCX-6

Spherical tilt washer - DIN6319, concave

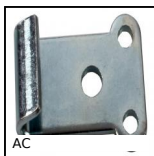

AC

Strike for toggle latch, 15mm

Complementary products



PT882

Drive sprocket for slat top chain, Range 882



PR882

Idler sprocket for slat top chain, Range 882