

# Side flexing wide plate chain



## CAP882T

## Range 882 TAB



- Bending radius allows chain to follow a curved path
- Materials:
  - Plates: self lubricating brown acetal
  - Pin: stainless steel 304
- Operating temp.: -40°C to +85°C (+70°C in humid environments)
- Length 3048mm (80 plates)

### Advantages

- Special shape prevents products being carried moving or falling whilst on curves


### Associated products

- Drive sprocket **PT882**
- Idler sprocket **PR882**

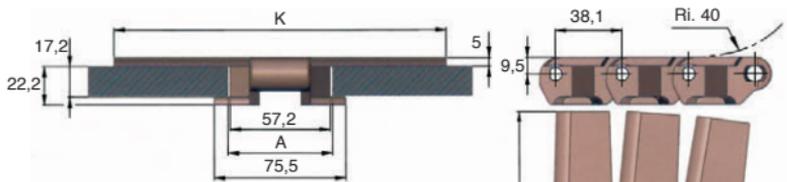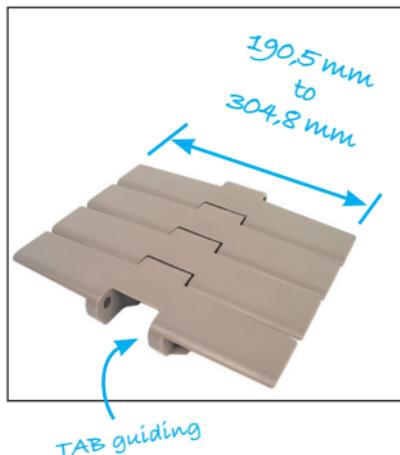

A  $\left\{ \begin{array}{l} \text{Straight} - 60 \\ \text{Curved} - 58 \end{array} \right.$

Direction of travel

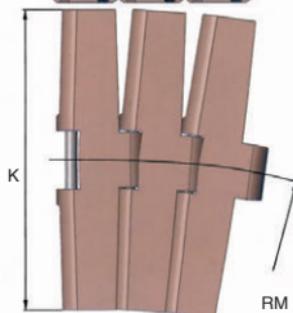

Typical application


### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Bend radius		Breaking load (N)	Weight (kg/m)	Price each 1 to 4
			RM (mm)	RM (mm)			
CAP882T-190	190,5	3048	610	8000	2,43	284,83 €	
CAP882T-254	254,0	3048	610	8000	2,87	296,96 €	
CAP882T-304	304,8	3048	610	8000	3,41	325,33 €	

Dimensions in mm

## Our other products

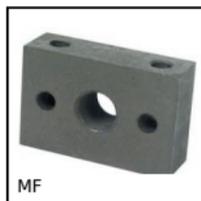

MF  
Shock Absorber  
-universal flange,  
Universal fixing



PLM-SC  
Magnetic stud with  
threaded hole, With  
threaded hole



BPLF  
Ball transfer unit light  
duty, Light



DHX  
Dowel pin internal  
thread, Extractable  
DIN 7979D



SSDB  
Stainless steel bevel  
gear, 2:1



HLC24  
Right angle spiro  
bevel gearbox, Up to  
78Nm



PRESSHR  
Manual workbench  
press, Force up to  
500kg



RAG  
Roller guide,



SEV  
Vertical stirrup toggle  
clamp, Vertical Latch



DOMI50  
Accessories, Turntable



PO  
Pull handle - Multi-  
sector, Smooth hole



ALIDRP240  
24V DC power supply,  
10 A

## Complementary products



PT882  
Drive sprocket for slat  
top chain, Range 882



PR882  
Idler sprocket for slat  
top chain, Range 882