

# Side flexing wide plate chain



## CAP882T

## Range 882 TAB

- Bending radius allows chain to follow a curved path

- Materials:

Plates: self lubricating brown acetal

Pin: stainless steel 304

- Operating temp.: -40°C to +85°C  
(+70°C in humid environments)

- Length 3048mm (80 plates)



### Advantages

- Special shape prevents products being carried moving or falling whilst on curves

### Associated products

- Drive sprocket **PT882**

- Idler sprocket **PR882**

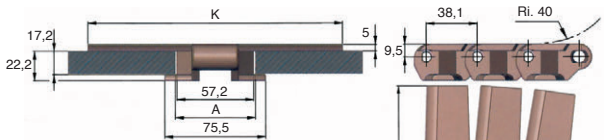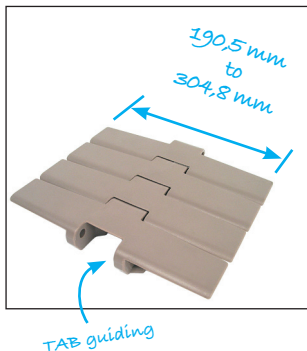

A  $\left\{ \begin{array}{l} \text{Straight} - 60 \\ \text{Curved} - 58 \end{array} \right.$

Direction of travel



Typical application

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Bend radius		Breaking load (N)	Weight (kg/m)	Price each 1 to 4
			RM (mm)				
CAP882T-190	190,5	3048	610		8000	2,43	284,83 €
CAP882T-254	254,0	3048	610		8000	2,87	296,96 €
CAP882T-304	304,8	3048	610		8000	3,41	325,33 €

Dimensions in mm

## Our other products



SCA  
Flat cable clamp,  
Steel



PITAss  
Locking bolt, with T  
handle



PW\_PWG2  
Worm - precision  
range, Stainless steel



HBM  
Adjustment bushing  
for half-rail guide,  
Adjustment bushing



VTLF  
3 lobed handle,  
Polyamide - Brass



ERT  
Sliding nut, For T slot



SCR  
Suction cup threaded  
insert, Adaptor for  
insert



AKN  
Bellows coupling  
Gerwah®, from 22 to  
180Nm



SNG  
Stainless/Polymer  
pillow block bearing,



HW\_HT  
Half-rail guide, Rail



HK  
Manual locking clamp,  
Manual locking clamp



HTD8M-BAR  
HTD type tooth bar  
stock, HTD8

## Complementary products



PT882  
Drive sprocket for slat  
top chain, Range 882



PR882  
Idler sprocket for slat  
top chain, Range 882