


- Fitting elements
- Wire thimble for use with CAB steel cable
- Material:
Steel Fe360B, zinc plated

Info.

- Sold by the packet

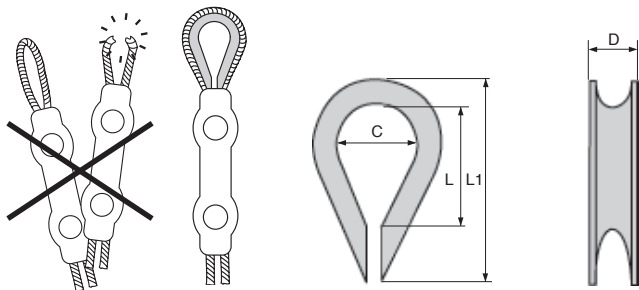

DISCOUNTS

| Qty | 1+ | 30+ | 60+ | 90+ | 120+ | 150+ |
|------------|-----|------|------|------|------------|------|
| Disc. List | -5% | -10% | -15% | -20% | On request | |

| Part number | Cable Ø | C | L | D | L1 | Weight (g) | Qty per packet | Stock* | Price each 1 to 29 |
|-------------|---------|----|------|------|----|------------|----------------|--------|--------------------|
| CCL-3/B | 3 | 10 | 15 | 5 | 24 | 2,30 | 20 | ✓ | 0,23 € |
| CCL-4/B | 4 | 12 | 17,5 | 6 | 28 | 3,00 | 20 | ✓ | 0,27 € |
| CCL-5/B | 5 | 14 | 23 | 7 | 35 | 5,00 | 20 | ✓ | 0,27 € |
| CCL-6/B | 6 | 17 | 26 | 8,5 | 40 | 8,00 | 20 | ✓ | 0,31 € |
| CCL-8/B | 8 | 19 | 32 | 11,5 | 49 | 15,00 | 20 | ✓ | 0,45 € |
| CCL-10/B | 10 | 22 | 34 | 13,5 | 55 | 23,00 | 20 | - | 0,66 € |

*Depending on availability - Dimensions in mm

Our other products




DOMI50

Domino 50 adjustable slide, Slide DOMILINE 50



BLOC

Doorstop, Doorstop

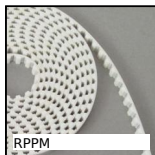

RPPM

RPP type belt per metre, RPP5 Steel cored polyurethane



SVG

Adjustable latch clamp with strike plate, Stroke from 118mm to 130,5mm



RJA00_28

Sealing strip, Clipping



PV2R

Adjustable suction-cup support, Increased grip



MDB_MTB

Moulded plastic bevel gear (nylon), 3:1



S_ZZ

Deep groove ball bearing, Stainless steel



ACLEPP

Right angled bracket for aluminium profile, 8 holes



T5sourroie

T type timing belt, T5 Steel cored polyurethane



BFA

Shaft locking washer, E clip



CLA

Clamping lever Hygienic Usit® - female, Stainless steel

Complementary products

 


CABPVC

PVC covered galvanised steel cable, Galvanised steel with



Stainless steel wire
thimble, Stainless
steel



Galvanised steel
cable, Galvanised
steel



Flat cable clamp,
Steel