


- Fitting elements
- Wire thimble for use with CAB steel cable
- Material:  
Steel Fe360B, zinc plated

### Info.

- Sold by the packet

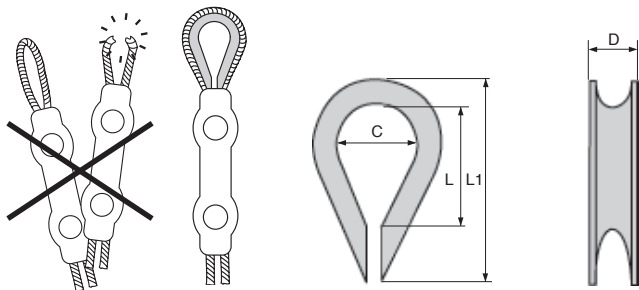

### DISCOUNTS

Qty	1+	30+	60+	90+	120+	150+
Disc. List	-5%	-10%	-15%	-20%	On request	

Part number	Cable Ø	C	L	D	L1	Weight (g)	Qty per packet	Stock*	Price each 1 to 29
CCL-3/B	3	10	15	5	24	2,30	20	✓	0,23 €
CCL-4/B	4	12	17,5	6	28	3,00	20	✓	0,27 €
CCL-5/B	5	14	23	7	35	5,00	20	✓	0,27 €
CCL-6/B	6	17	26	8,5	40	8,00	20	✓	0,31 €
CCL-8/B	8	19	32	11,5	49	15,00	20	✓	0,45 €
CCL-10/B	10	22	34	13,5	55	23,00	20	-	0,66 €

\*Depending on availability - Dimensions in mm

## Our other products



F7-I

Multifunction display,  
With internal sensor



GE32

Sprung toggle latch  
with connecting link,  
Standard



NT91

Spur gear coaxial  
gearbox, from 10 to  
35 Nm - Inline



GP

Spring loaded toggle  
latch, Standard  
(GP22-GP23)



CHV

Mechanical speed  
variator, from 0,18 to  
1,5kW



HTD8M\_20

HTD Heavy duty  
timing pulley, HTD8  
Steel



PRF JL5

Lip seal for panel,  
Door seal - Ø 5mm



CHINV

Invisible hinge,  
Invisible - 90° opening



 
F7-P-AM

Multifunction display,  
Magnetic band



AFM

Flanged polymer  
bush, Food grade  
polymer



TBV


Manual lifting tables,  
20kg



T10\_21\_AL

T type timing pulley,  
Economy range - T10  
aluminium

## Complementary products

 

CAB

Galvanised steel  
cable, Galvanised  
steel



SCA

Flat cable clamp,  
Steel



CABPVC

PVC covered  
galvanised steel  
cable, Galvanised  
steel with

transparen...



SCA

Flat cable clamp,  
Steel