

Cylindrical drill bushing

CDP

Treated steel

- For guiding drill bits during repetitive drilling or countersinking operations
- Good resistance in operation
- Material:
Case hardened steel

Info.

- Bore tolerance: DH7

Advantages

- Facilitates the drilling operation and avoids wear of the drill bit
- Ensures high repeatability




DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	Ød1	l1	Ød2 (n6)	r	Weight (g)	Price each 1 to 4	Part number	Ød1	l1	Ød2 (n6)	r	Weight (g)	Price each 1 to 4
CDP2-5-6	2	6	5	1	0,7	4,02 €	CDP5.1-10-20	5,1	20	10	1,5	8,9	8,59 €
CDP2-5-9	2	9	5	1	1,1	4,39 €	CDP5.5-10-10	5,5	10	10	1,5	4,1	4,16 €
CDP2.1-5-6	2,1	6	5	1	0,7	4,02 €	CDP5.5-10-16	5,5	16	10	1,5	6,7	4,80 €
CDP2.1-5-9	2,1	9	5	1	1,1	4,39 €	CDP5.5-10-20	5,5	20	10	1,5	8,4	8,59 €
CDP2.5-5-6	2,5	6	5	1	0,7	4,02 €	CDP6-10-10	6	10	10	1,5	3,8	4,16 €
CDP2.5-5-9	2,5	9	5	1	1	4,39 €	CDP6-10-16	6	16	10	1,5	6,1	4,80 €
CDP3-6-8	3	8	6	1	1,3	4,02 €	CDP6-10-20	6	20	10	1,5	7,7	8,59 €
CDP3-6-12	3	12	6	1	1,9	4,39 €	CDP6.1-12-10	6,1	10	12	1,5	6,3	4,39 €
CDP3-6-16	3	16	6	1	2,6	8,97 €	CDP6.1-12-16	6,1	16	12	1,5	10	4,95 €
CDP3.1-6-8	3,1	8	6	1	1,2	4,02 €	CDP6.1-12-20	6,1	20	12	1,5	13	8,97 €
CDP3.1-6-12	3,1	12	6	1	1,9	4,39 €	CDP6.5-12-10	6,5	10	12	1,5	6	4,39 €
CDP3.1-6-16	3,1	16	6	1	2,5	8,97 €	CDP6.5-12-16	6,5	16	12	1,5	9,7	4,95 €
CDP3.5-7-8	3,5	8	7	1	1,7	6,32 €	CDP6.5-12-20	6,5	20	12	1,5	12	8,97 €
CDP3.5-7-12	3,5	12	7	1	2,6	4,16 €	CDP7-12-10	7	10	12	1,5	5,6	4,39 €
CDP3.5-7-16	3,5	16	7	1	3,6	8,97 €	CDP7-12-16	7	16	12	1,5	9,1	4,95 €
CDP4-7-8	4	8	7	1	1,5	3,64 €	CDP7-12-20	7	20	12	1,5	11	8,97 €
CDP4-7-12	4	12	7	1	2,4	4,16 €	CDP7.1-12-10	7,1	10	12	1,5	5,5	4,39 €
CDP4-7-16	4	16	7	1	3,2	8,97 €	CDP7.1-12-16	7,1	16	12	1,5	9	4,95 €
CDP4.1-8-8	4,1	8	8	1	2,2	3,79 €	CDP7.1-12-20	7,1	20	12	1,5	11	8,97 €
CDP4.1-8-12	4,1	12	8	1	3,4	4,39 €	CDP7.5-12-10	7,5	10	12	1,5	5,1	4,39 €
CDP4.1-8-16	4,1	16	8	1	4,6	7,87 €	CDP7.5-12-16	7,5	16	12	1,5	8,4	4,95 €
CDP4.5-8-8	4,5	8	8	1	2,1	3,79 €	CDP7.5-12-20	7,5	20	12	1,5	11	8,97 €
CDP4.5-8-12	4,5	12	8	1	3,1	4,39 €	CDP8-12-10	8	10	12	1,5	4,7	4,39 €
CDP4.5-8-16	4,5	16	8	1	4,2	7,87 €	CDP8-12-16	8	16	12	1,5	7,6	4,95 €
CDP5-8-8	5	8	8	1	1,8	3,79 €	CDP8-12-20	8	20	12	1,5	9,6	8,97 €
CDP5-8-12	5	12	8	1	2,8	4,39 €	CDP8.1-15-12	8,1	12	15	2	11	4,57 €
CDP5-8-16	5	16	8	1	3,7	7,87 €	CDP8.1-15-20	8,1	20	15	2	19	5,58 €
CDP5.1-10-10	5,1	10	10	1,5	4,4	4,16 €	CDP8.1-15-25	8,1	25	15	2	24	9,68 €
CDP5.1-10-16	5,1	16	10	1,5	7,1	4,80 €	CDP8.5-15-12	8,5	12	15	2	11	4,57 €

Dimensions in mm

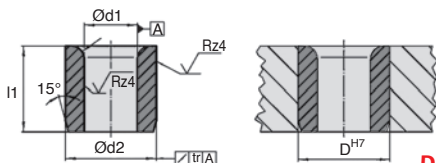

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	Ød1	l1	Ød2 (n6)	r	Weight (g)	Price each	Part number	Ød1	l1	Ød2 (n6)	r	Weight (g)	Price each
CDP8.5-15-20	8,5	20	15	2	18	5,58 €	CDP13-22-36	13	36	22	2	69	12,53 €
CDP8.5-15-25	8,5	25	15	2	23	9,68 €	CDP14-22-16	14	16	22	2	27	5,93 €
CDP9-15-12	9	12	15	2	10	4,57 €	CDP14-22-28	14	28	22	2	49	8,02 €
CDP9-15-20	9	20	15	2	17	5,58 €	CDP14-22-36	14	36	22	2	63	12,53 €
CDP9-15-25	9	25	15	2	22	9,68 €	CDP15-22-16	15	16	22	2	25	5,93 €
CDP9.1-15-12	9,1	12	15	2	10	4,57 €	CDP15-22-28	15	28	22	2	44	8,02 €
CDP9.1-15-20	9,1	20	15	2	17	5,58 €	CDP15-22-36	15	36	22	2	56	12,53 €
CDP9.1-15-25	9,1	25	15	2	21	9,68 €	CDP16-26-16	16	16	26	2	45	8,02 €
CDP9.5-15-12	9,5	12	15	2	9,5	4,57 €	CDP16-26-28	16	28	26	2	71	10,12 €
CDP9.5-15-20	9,5	20	15	2	16	5,58 €	CDP16-26-36	16	36	26	2	92	15,75 €
CDP9.5-15-25	9,5	25	15	2	20	9,68 €	CDP16.1-26-16	16,1	16	26	2	40	12,19 €
CDP10-15-12	10	12	15	2	8,8	4,57 €	CDP16.1-26-28	16,1	28	26	2	71	14,90 €
CDP10-15-20	10	20	15	2	15	5,58 €	CDP16.1-26-36	16,1	36	26	2	91	21,14 €
CDP10-15-25	10	25	15	2	19	9,68 €	CDP16.5-26-16	16,5	16	26	2	39	8,02 €
CDP10.1-18-12	10,1	12	18	2	16	5,32 €	CDP16.5-26-28	16,5	28	26	2	68	10,12 €
CDP10.1-18-20	10,1	20	18	2	27	6,47 €	CDP16.5-26-36	16,5	36	26	2	88	15,75 €
CDP10.1-18-25	10,1	25	18	2	33	10,01 €	CDP17-26-16	17	16	26	2	37	8,02 €
CDP10.5-18-12	10,5	12	18	2	15	5,32 €	CDP17-26-28	17	28	26	2	65	10,12 €
CDP10.5-18-20	10,5	20	18	2	26	6,47 €	CDP17-26-36	17	36	26	2	84	15,75 €
CDP10.5-18-25	10,5	25	18	2	32	10,01 €	CDP18-26-16	18	16	26	2	33	8,02 €
CDP11-18-12	11	12	18	2	14	5,32 €	CDP18-26-28	18	28	26	2	59	10,12 €
CDP11-18-20	11	20	18	2	24	6,47 €	CDP18-26-36	18	36	26	2	77	15,75 €
CDP11-18-25	11	25	18	2	31	10,01 €	CDP19-30-20	19	20	30	3	64	9,90 €
CDP11.1-18-12	11,1	12	18	2	14	5,32 €	CDP19-30-36	19	36	30	3	117	12,42 €
CDP11.1-18-20	11,1	20	18	2	24	6,47 €	CDP19-30-45	19	45	30	3	147	20,05 €
CDP11.1-18-25	11,1	25	18	2	30	10,01 €	CDP20-30-20	20	20	30	3	59	9,90 €
CDP11.5-18-12	11,5	12	18	2	14	5,32 €	CDP20-30-36	20	36	30	3	108	12,42 €
CDP11.5-18-20	11,5	20	18	2	23	6,47 €	CDP20-30-45	20	45	30	3	136	20,05 €
CDP11.5-18-25	11,5	25	18	2	29	10,01 €	CDP20.1-30-20	20,1	20	30	3	59	14,48 €
CDP12-18-12	12	12	18	2	13	5,32 €	CDP20.1-30-36	20,1	36	30	3	108	17,51 €
CDP12-18-20	12	20	18	2	22	6,47 €	CDP20.1-30-45	20,1	45	30	3	135	27,24 €
CDP12-18-25	12	25	18	2	27	10,01 €	CDP22-30-20	22	20	30	3	49	9,90 €
CDP12.1-22-16	12,1	16	22	2	32	5,93 €	CDP22-30-36	22	36	30	3	90	12,42 €
CDP12.1-22-28	12,1	28	22	2	57	8,02 €	CDP22-30-45	22	45	30	3	113	20,05 €
CDP12.1-22-36	12,1	36	22	2	74	12,53 €	CDP25-35-20	25	20	35	3	71	11,69 €
CDP12.5-22-16	12,5	16	22	2	31	5,93 €	CDP25-35-36	25	36	35	3	130	14,48 €
CDP12.5-22-28	12,5	28	22	2	66	8,02 €	CDP25-35-45	25	45	35	3	163	23,29 €
CDP12.5-22-36	12,5	36	22	2	69	12,53 €	CDP30-42-25	30	25	42	3	129	20,99 €
CDP13-22-16	13	16	22	2	30	5,93 €	CDP30-42-45	30	45	42	3	235	25,93 €
CDP13-22-28	13	28	22	2	53	8,02 €	CDP30-42-56	30	56	42	3	293	39,44 €

Dimensions in mm

 
Fax 0 825 88 6000
 Service 0,15 € / min
 + prix appel

Our other products



DFG

Flat suction cup,
nitrile



R_RR

Narrow spur rack,
Steel



DIL

Lever operated
locking bolt, lever
clamp



BAG-MI

Split shaft collar with
clamp lever, Steel



SHA_PT

Handwheel with
handle, Polyamide



SBF

Sealed flange bearing
unit for Food Industry,
cover



CHM40

Worm and wheel gear
reducer, up to 57 Nm



RFK58B

Hypoid gearbox -
Stainless steel, up to
500 Nm



CHTRB

Single and dual
output gearboxes, Up



NKX

Combined bearing
without inner ring,



PMB

Anti-vibration
machine mount, Oval



PTMC

Telescopic furniture
foot, square plate

Complementary products



CDPC

Flanged drill bushing,
Steel



PRES2HR

Manual workbench
press, Force up to
200kg



PRES4HR

Manual workbench
press, Force up to
600kg



PRES5HR

Manual workbench
press, Force up to
500kg