

Cylindrical drill bushing

CDP

Treated steel

- For guiding drill bits during repetitive drilling or countersinking operations
- Good resistance in operation
- Material:
Case hardened steel

Info.

- Bore tolerance: DH7

Advantages

- Facilitates the drilling operation and avoids wear of the drill bit
- Ensures high repeatability




DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	Ød1	l1	Ød2 (n6)	r	Weight (g)	Price each 1 to 4	Part number	Ød1	l1	Ød2 (n6)	r	Weight (g)	Price each 1 to 4
CDP2-5-6	2	6	5	1	0,7	4,02 €	CDP5.1-10-20	5,1	20	10	1,5	8,9	8,59 €
CDP2-5-9	2	9	5	1	1,1	4,39 €	CDP5.5-10-10	5,5	10	10	1,5	4,1	4,16 €
CDP2.1-5-6	2,1	6	5	1	0,7	4,02 €	CDP5.5-10-16	5,5	16	10	1,5	6,7	4,80 €
CDP2.1-5-9	2,1	9	5	1	1,1	4,39 €	CDP5.5-10-20	5,5	20	10	1,5	8,4	8,59 €
CDP2.5-5-6	2,5	6	5	1	0,7	4,02 €	CDP6-10-10	6	10	10	1,5	3,8	4,16 €
CDP2.5-5-9	2,5	9	5	1	1	4,39 €	CDP6-10-16	6	16	10	1,5	6,1	4,80 €
CDP3-6-8	3	8	6	1	1,3	4,02 €	CDP6-10-20	6	20	10	1,5	7,7	8,59 €
CDP3-6-12	3	12	6	1	1,9	4,39 €	CDP6.1-12-10	6,1	10	12	1,5	6,3	4,39 €
CDP3-6-16	3	16	6	1	2,6	8,97 €	CDP6.1-12-16	6,1	16	12	1,5	10	4,95 €
CDP3.1-6-8	3,1	8	6	1	1,2	4,02 €	CDP6.1-12-20	6,1	20	12	1,5	13	8,97 €
CDP3.1-6-12	3,1	12	6	1	1,9	4,39 €	CDP6.5-12-10	6,5	10	12	1,5	6	4,39 €
CDP3.1-6-16	3,1	16	6	1	2,5	8,97 €	CDP6.5-12-16	6,5	16	12	1,5	9,7	4,95 €
CDP3.5-7-8	3,5	8	7	1	1,7	6,32 €	CDP6.5-12-20	6,5	20	12	1,5	12	8,97 €
CDP3.5-7-12	3,5	12	7	1	2,6	4,16 €	CDP7-12-10	7	10	12	1,5	5,6	4,39 €
CDP3.5-7-16	3,5	16	7	1	3,6	8,97 €	CDP7-12-16	7	16	12	1,5	9,1	4,95 €
CDP4-7-8	4	8	7	1	1,5	3,64 €	CDP7-12-20	7	20	12	1,5	11	8,97 €
CDP4-7-12	4	12	7	1	2,4	4,16 €	CDP7.1-12-10	7,1	10	12	1,5	5,5	4,39 €
CDP4-7-16	4	16	7	1	3,2	8,97 €	CDP7.1-12-16	7,1	16	12	1,5	9	4,95 €
CDP4.1-8-8	4,1	8	8	1	2,2	3,79 €	CDP7.1-12-20	7,1	20	12	1,5	11	8,97 €
CDP4.1-8-12	4,1	12	8	1	3,4	4,39 €	CDP7.5-12-10	7,5	10	12	1,5	5,1	4,39 €
CDP4.1-8-16	4,1	16	8	1	4,6	7,87 €	CDP7.5-12-16	7,5	16	12	1,5	8,4	4,95 €
CDP4.5-8-8	4,5	8	8	1	2,1	3,79 €	CDP7.5-12-20	7,5	20	12	1,5	11	8,97 €
CDP4.5-8-12	4,5	12	8	1	3,1	4,39 €	CDP8-12-10	8	10	12	1,5	4,7	4,39 €
CDP4.5-8-16	4,5	16	8	1	4,2	7,87 €	CDP8-12-16	8	16	12	1,5	7,6	4,95 €
CDP5-8-8	5	8	8	1	1,8	3,79 €	CDP8-12-20	8	20	12	1,5	9,6	8,97 €
CDP5-8-12	5	12	8	1	2,8	4,39 €	CDP8.1-15-12	8,1	12	15	2	11	4,57 €
CDP5-8-16	5	16	8	1	3,7	7,87 €	CDP8.1-15-20	8,1	20	15	2	19	5,58 €
CDP5.1-10-10	5,1	10	10	1,5	4,4	4,16 €	CDP8.1-15-25	8,1	25	15	2	24	9,68 €
CDP5.1-10-16	5,1	16	10	1,5	7,1	4,80 €	CDP8.5-15-12	8,5	12	15	2	11	4,57 €

Dimensions in mm

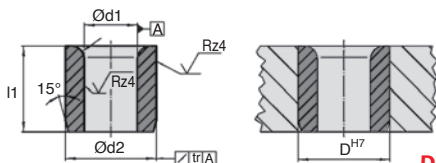

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	Ød1	l1	Ød2 (n6)	r	Weight (g)	Price each	Part number	Ød1	l1	Ød2 (n6)	r	Weight (g)	Price each
CDP8.5-15-20	8,5	20	15	2	18	5,58 €	CDP13-22-36	13	36	22	2	69	12,53 €
CDP8.5-15-25	8,5	25	15	2	23	9,68 €	CDP14-22-16	14	16	22	2	27	5,93 €
CDP9-15-12	9	12	15	2	10	4,57 €	CDP14-22-28	14	28	22	2	49	8,02 €
CDP9-15-20	9	20	15	2	17	5,58 €	CDP14-22-36	14	36	22	2	63	12,53 €
CDP9-15-25	9	25	15	2	22	9,68 €	CDP15-22-16	15	16	22	2	25	5,93 €
CDP9.1-15-12	9,1	12	15	2	10	4,57 €	CDP15-22-28	15	28	22	2	44	8,02 €
CDP9.1-15-20	9,1	20	15	2	17	5,58 €	CDP15-22-36	15	36	22	2	56	12,53 €
CDP9.1-15-25	9,1	25	15	2	21	9,68 €	CDP16-26-16	16	16	26	2	45	8,02 €
CDP9.5-15-12	9,5	12	15	2	9,5	4,57 €	CDP16-26-28	16	28	26	2	71	10,12 €
CDP9.5-15-20	9,5	20	15	2	16	5,58 €	CDP16-26-36	16	36	26	2	92	15,75 €
CDP9.5-15-25	9,5	25	15	2	20	9,68 €	CDP16.1-26-16	16,1	16	26	2	40	12,19 €
CDP10-15-12	10	12	15	2	8,8	4,57 €	CDP16.1-26-28	16,1	28	26	2	71	14,90 €
CDP10-15-20	10	20	15	2	15	5,58 €	CDP16.1-26-36	16,1	36	26	2	91	21,14 €
CDP10-15-25	10	25	15	2	19	9,68 €	CDP16.5-26-16	16,5	16	26	2	39	8,02 €
CDP10.1-18-12	10,1	12	18	2	16	5,32 €	CDP16.5-26-28	16,5	28	26	2	68	10,12 €
CDP10.1-18-20	10,1	20	18	2	27	6,47 €	CDP16.5-26-36	16,5	36	26	2	88	15,75 €
CDP10.1-18-25	10,1	25	18	2	33	10,01 €	CDP17-26-16	17	16	26	2	37	8,02 €
CDP10.5-18-12	10,5	12	18	2	15	5,32 €	CDP17-26-28	17	28	26	2	65	10,12 €
CDP10.5-18-20	10,5	20	18	2	26	6,47 €	CDP17-26-36	17	36	26	2	84	15,75 €
CDP10.5-18-25	10,5	25	18	2	32	10,01 €	CDP18-26-16	18	16	26	2	33	8,02 €
CDP11-18-12	11	12	18	2	14	5,32 €	CDP18-26-28	18	28	26	2	59	10,12 €
CDP11-18-20	11	20	18	2	24	6,47 €	CDP18-26-36	18	36	26	2	77	15,75 €
CDP11-18-25	11	25	18	2	31	10,01 €	CDP19-30-20	19	20	30	3	64	9,90 €
CDP11.1-18-12	11,1	12	18	2	14	5,32 €	CDP19-30-36	19	36	30	3	117	12,42 €
CDP11.1-18-20	11,1	20	18	2	24	6,47 €	CDP19-30-45	19	45	30	3	147	20,05 €
CDP11.1-18-25	11,1	25	18	2	30	10,01 €	CDP20-30-20	20	20	30	3	59	9,90 €
CDP11.5-18-12	11,5	12	18	2	14	5,32 €	CDP20-30-36	20	36	30	3	108	12,42 €
CDP11.5-18-20	11,5	20	18	2	23	6,47 €	CDP20-30-45	20	45	30	3	136	20,05 €
CDP11.5-18-25	11,5	25	18	2	29	10,01 €	CDP20.1-30-20	20,1	20	30	3	59	14,48 €
CDP12-18-12	12	12	18	2	13	5,32 €	CDP20.1-30-36	20,1	36	30	3	108	17,51 €
CDP12-18-20	12	20	18	2	22	6,47 €	CDP20.1-30-45	20,1	45	30	3	135	27,24 €
CDP12-18-25	12	25	18	2	27	10,01 €	CDP22-30-20	22	20	30	3	49	9,90 €
CDP12.1-22-16	12,1	16	22	2	32	5,93 €	CDP22-30-36	22	36	30	3	90	12,42 €
CDP12.1-22-28	12,1	28	22	2	57	8,02 €	CDP22-30-45	22	45	30	3	113	20,05 €
CDP12.1-22-36	12,1	36	22	2	74	12,53 €	CDP25-35-20	25	20	35	3	71	11,69 €
CDP12.5-22-16	12,5	16	22	2	31	5,93 €	CDP25-35-36	25	36	35	3	130	14,48 €
CDP12.5-22-28	12,5	28	22	2	66	8,02 €	CDP25-35-45	25	45	35	3	163	23,29 €
CDP12.5-22-36	12,5	36	22	2	69	12,53 €	CDP30-42-25	30	25	42	3	129	20,99 €
CDP13-22-16	13	16	22	2	30	5,93 €	CDP30-42-45	30	45	42	3	235	25,93 €
CDP13-22-28	13	28	22	2	53	8,02 €	CDP30-42-56	30	56	42	3	293	39,44 €

Dimensions in mm

Fax 0 825 88 6000
 Service 0,15 € / min
 + prix appel

Our other products



Drylin® W rail, Rail



Technopolymer clamping lever - female, Plastic



Chain sprocket- stainless steel, 4mm



 
Tensioner pulley, For flat belts



Spring hinge, welded




Driving collar, Driving collar



Cylindrical polymer bush, Universal polymer



 Connecting kits, XZ linking kit



Worm and wheel set, Bronze



Spherical bushing, Hard chromium / PTFE



HTD Heavy duty timing pulley, HTD8 Cast



Asynchronous AC motorgearboxes 0.09 to 0.22kW, 0.09 to 0.22kW

Complementary products



Flanged drill bushing, Steel



Manual workbench press, Force up to 200kg



Manual workbench press, Force up to 600kg



Manual workbench press, Force up to 500kg