

Cylindrical drill bushing

CDP

Treated steel

- For guiding drill bits during repetitive drilling or countersinking operations
- Good resistance in operation
- Material:
Case hardened steel

Info.

- Bore tolerance: DH7

Advantages

- Facilitates the drilling operation and avoids wear of the drill bit
- Ensures high repeatability




DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	Ød1	l1	Ød2 (n6)	r	Weight (g)	Price each 1 to 4	Part number	Ød1	l1	Ød2 (n6)	r	Weight (g)	Price each 1 to 4
CDP2-5-6	2	6	5	1	0,7	4,02 €	CDP5.1-10-20	5,1	20	10	1,5	8,9	8,59 €
CDP2-5-9	2	9	5	1	1,1	4,39 €	CDP5.5-10-10	5,5	10	10	1,5	4,1	4,16 €
CDP2.1-5-6	2,1	6	5	1	0,7	4,02 €	CDP5.5-10-16	5,5	16	10	1,5	6,7	4,80 €
CDP2.1-5-9	2,1	9	5	1	1,1	4,39 €	CDP5.5-10-20	5,5	20	10	1,5	8,4	8,59 €
CDP2.5-5-6	2,5	6	5	1	0,7	4,02 €	CDP6-10-10	6	10	10	1,5	3,8	4,16 €
CDP2.5-5-9	2,5	9	5	1	1	4,39 €	CDP6-10-16	6	16	10	1,5	6,1	4,80 €
CDP3-6-8	3	8	6	1	1,3	4,02 €	CDP6-10-20	6	20	10	1,5	7,7	8,59 €
CDP3-6-12	3	12	6	1	1,9	4,39 €	CDP6.1-12-10	6,1	10	12	1,5	6,3	4,39 €
CDP3-6-16	3	16	6	1	2,6	8,97 €	CDP6.1-12-16	6,1	16	12	1,5	10	4,95 €
CDP3.1-6-8	3,1	8	6	1	1,2	4,02 €	CDP6.1-12-20	6,1	20	12	1,5	13	8,97 €
CDP3.1-6-12	3,1	12	6	1	1,9	4,39 €	CDP6.5-12-10	6,5	10	12	1,5	6	4,39 €
CDP3.1-6-16	3,1	16	6	1	2,5	8,97 €	CDP6.5-12-16	6,5	16	12	1,5	9,7	4,95 €
CDP3.5-7-8	3,5	8	7	1	1,7	6,32 €	CDP6.5-12-20	6,5	20	12	1,5	12	8,97 €
CDP3.5-7-12	3,5	12	7	1	2,6	4,16 €	CDP7-12-10	7	10	12	1,5	5,6	4,39 €
CDP3.5-7-16	3,5	16	7	1	3,6	8,97 €	CDP7-12-16	7	16	12	1,5	9,1	4,95 €
CDP4-7-8	4	8	7	1	1,5	3,64 €	CDP7-12-20	7	20	12	1,5	11	8,97 €
CDP4-7-12	4	12	7	1	2,4	4,16 €	CDP7.1-12-10	7,1	10	12	1,5	5,5	4,39 €
CDP4-7-16	4	16	7	1	3,2	8,97 €	CDP7.1-12-16	7,1	16	12	1,5	9	4,95 €
CDP4.1-8-8	4,1	8	8	1	2,2	3,79 €	CDP7.1-12-20	7,1	20	12	1,5	11	8,97 €
CDP4.1-8-12	4,1	12	8	1	3,4	4,39 €	CDP7.5-12-10	7,5	10	12	1,5	5,1	4,39 €
CDP4.1-8-16	4,1	16	8	1	4,6	7,87 €	CDP7.5-12-16	7,5	16	12	1,5	8,4	4,95 €
CDP4.5-8-8	4,5	8	8	1	2,1	3,79 €	CDP7.5-12-20	7,5	20	12	1,5	11	8,97 €
CDP4.5-8-12	4,5	12	8	1	3,1	4,39 €	CDP8-12-10	8	10	12	1,5	4,7	4,39 €
CDP4.5-8-16	4,5	16	8	1	4,2	7,87 €	CDP8-12-16	8	16	12	1,5	7,6	4,95 €
CDP5-8-8	5	8	8	1	1,8	3,79 €	CDP8-12-20	8	20	12	1,5	9,6	8,97 €
CDP5-8-12	5	12	8	1	2,8	4,39 €	CDP8.1-15-12	8,1	12	15	2	11	4,57 €
CDP5-8-16	5	16	8	1	3,7	7,87 €	CDP8.1-15-20	8,1	20	15	2	19	5,58 €
CDP5.1-10-10	5,1	10	10	1,5	4,4	4,16 €	CDP8.1-15-25	8,1	25	15	2	24	9,68 €
CDP5.1-10-16	5,1	16	10	1,5	7,1	4,80 €	CDP8.5-15-12	8,5	12	15	2	11	4,57 €

Dimensions in mm

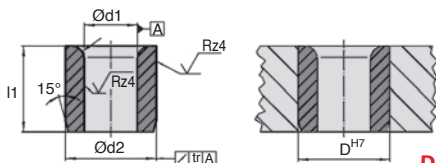

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	Ød1	l1	Ød2 (n6)	r	Weight (g)	Price each	Part number	Ød1	l1	Ød2 (n6)	r	Weight (g)	Price each
CDP8.5-15-20	8,5	20	15	2	18	5,58 €	CDP13-22-36	13	36	22	2	69	12,53 €
CDP8.5-15-25	8,5	25	15	2	23	9,68 €	CDP14-22-16	14	16	22	2	27	5,93 €
CDP9-15-12	9	12	15	2	10	4,57 €	CDP14-22-28	14	28	22	2	49	8,02 €
CDP9-15-20	9	20	15	2	17	5,58 €	CDP14-22-36	14	36	22	2	63	12,53 €
CDP9-15-25	9	25	15	2	22	9,68 €	CDP15-22-16	15	16	22	2	25	5,93 €
CDP9.1-15-12	9,1	12	15	2	10	4,57 €	CDP15-22-28	15	28	22	2	44	8,02 €
CDP9.1-15-20	9,1	20	15	2	17	5,58 €	CDP15-22-36	15	36	22	2	56	12,53 €
CDP9.1-15-25	9,1	25	15	2	21	9,68 €	CDP16-26-16	16	16	26	2	45	8,02 €
CDP9.5-15-12	9,5	12	15	2	9,5	4,57 €	CDP16-26-28	16	28	26	2	71	10,12 €
CDP9.5-15-20	9,5	20	15	2	16	5,58 €	CDP16-26-36	16	36	26	2	92	15,75 €
CDP9.5-15-25	9,5	25	15	2	20	9,68 €	CDP16.1-26-16	16,1	16	26	2	40	12,19 €
CDP10-15-12	10	12	15	2	8,8	4,57 €	CDP16.1-26-28	16,1	28	26	2	71	14,90 €
CDP10-15-20	10	20	15	2	15	5,58 €	CDP16.1-26-36	16,1	36	26	2	91	21,14 €
CDP10-15-25	10	25	15	2	19	9,68 €	CDP16.5-26-16	16,5	16	26	2	39	8,02 €
CDP10.1-18-12	10,1	12	18	2	16	5,32 €	CDP16.5-26-28	16,5	28	26	2	68	10,12 €
CDP10.1-18-20	10,1	20	18	2	27	6,47 €	CDP16.5-26-36	16,5	36	26	2	88	15,75 €
CDP10.1-18-25	10,1	25	18	2	33	10,01 €	CDP17-26-16	17	16	26	2	37	8,02 €
CDP10.5-18-12	10,5	12	18	2	15	5,32 €	CDP17-26-28	17	28	26	2	65	10,12 €
CDP10.5-18-20	10,5	20	18	2	26	6,47 €	CDP17-26-36	17	36	26	2	84	15,75 €
CDP10.5-18-25	10,5	25	18	2	32	10,01 €	CDP18-26-16	18	16	26	2	33	8,02 €
CDP11-18-12	11	12	18	2	14	5,32 €	CDP18-26-28	18	28	26	2	59	10,12 €
CDP11-18-20	11	20	18	2	24	6,47 €	CDP18-26-36	18	36	26	2	77	15,75 €
CDP11-18-25	11	25	18	2	31	10,01 €	CDP19-30-20	19	20	30	3	64	9,90 €
CDP11.1-18-12	11,1	12	18	2	14	5,32 €	CDP19-30-36	19	36	30	3	117	12,42 €
CDP11.1-18-20	11,1	20	18	2	24	6,47 €	CDP19-30-45	19	45	30	3	147	20,05 €
CDP11.1-18-25	11,1	25	18	2	30	10,01 €	CDP20-30-20	20	20	30	3	59	9,90 €
CDP11.5-18-12	11,5	12	18	2	14	5,32 €	CDP20-30-36	20	36	30	3	108	12,42 €
CDP11.5-18-20	11,5	20	18	2	23	6,47 €	CDP20-30-45	20	45	30	3	136	20,05 €
CDP11.5-18-25	11,5	25	18	2	29	10,01 €	CDP20.1-30-20	20,1	20	30	3	59	14,48 €
CDP12-18-12	12	12	18	2	13	5,32 €	CDP20.1-30-36	20,1	36	30	3	108	17,51 €
CDP12-18-20	12	20	18	2	22	6,47 €	CDP20.1-30-45	20,1	45	30	3	135	27,24 €
CDP12-18-25	12	25	18	2	27	10,01 €	CDP22-30-20	22	20	30	3	49	9,90 €
CDP12.1-22-16	12,1	16	22	2	32	5,93 €	CDP22-30-36	22	36	30	3	90	12,42 €
CDP12.1-22-28	12,1	28	22	2	57	8,02 €	CDP22-30-45	22	45	30	3	113	20,05 €
CDP12.1-22-36	12,1	36	22	2	74	12,53 €	CDP25-35-20	25	20	35	3	71	11,69 €
CDP12.5-22-16	12,5	16	22	2	31	5,93 €	CDP25-35-36	25	36	35	3	130	14,48 €
CDP12.5-22-28	12,5	28	22	2	66	8,02 €	CDP25-35-45	25	45	35	3	163	23,29 €
CDP12.5-22-36	12,5	36	22	2	69	12,53 €	CDP30-42-25	30	25	42	3	129	20,99 €
CDP13-22-16	13	16	22	2	30	5,93 €	CDP30-42-45	30	45	42	3	235	25,93 €
CDP13-22-28	13	28	22	2	53	8,02 €	CDP30-42-56	30	56	42	3	293	39,44 €

Dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



SME
Male rod ends ,
Stainless steel / PTFE



BAC110
Swivel storage bin,
Adjustable support




MSP3815
Masterplate®
glueable insert
rectangular,
rectangular with



MAX22
Motor-gearbox 12V
and 24V DC, from
0,07 to 0,2Nm



 CHALss
Piano hinge, Stainless
steel



SCH
Horizontal hook
toggle clamp,
Horizontal Hook
clamp - steel



PW_PWG05
Worm - precision
range, Stainless steel



GAL_25
Ø25 conveyor roller,
Without ball bearing




SBF
Sealed flange bearing
unit for Food Industry,
Steel



PRF4545_P
Stripp Aluminium
profile with



 PR65C
Half-articulated foot Ø
65, Ø 65



B
Steel bevel gear, 1:1

Complementary products



CDPC
Flanged drill bushing,
Steel



PRES2HR
Manual workbench
press, Force up to
200kg



PRES4HR
Manual workbench
press, Force up to
600kg



PRES5HR
Manual workbench
press, Force up to
500kg