

Cylindrical drill bushing

CDP

Treated steel

- For guiding drill bits during repetitive drilling or countersinking operations
- Good resistance in operation
- Material:
Case hardened steel

Info.

- Bore tolerance: DH7

Advantages

- Facilitates the drilling operation and avoids wear of the drill bit
- Ensures high repeatability




DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	Ød1	l1	Ød2 (n6)	r	Weight (g)	Price each 1 to 4	Part number	Ød1	l1	Ød2 (n6)	r	Weight (g)	Price each 1 to 4
CDP2-5-6	2	6	5	1	0,7	4,02 €	CDP5.1-10-20	5,1	20	10	1,5	8,9	8,59 €
CDP2-5-9	2	9	5	1	1,1	4,39 €	CDP5.5-10-10	5,5	10	10	1,5	4,1	4,16 €
CDP2.1-5-6	2,1	6	5	1	0,7	4,02 €	CDP5.5-10-16	5,5	16	10	1,5	6,7	4,80 €
CDP2.1-5-9	2,1	9	5	1	1,1	4,39 €	CDP5.5-10-20	5,5	20	10	1,5	8,4	8,59 €
CDP2.5-5-6	2,5	6	5	1	0,7	4,02 €	CDP6-10-10	6	10	10	1,5	3,8	4,16 €
CDP2.5-5-9	2,5	9	5	1	1	4,39 €	CDP6-10-16	6	16	10	1,5	6,1	4,80 €
CDP3-6-8	3	8	6	1	1,3	4,02 €	CDP6-10-20	6	20	10	1,5	7,7	8,59 €
CDP3-6-12	3	12	6	1	1,9	4,39 €	CDP6.1-12-10	6,1	10	12	1,5	6,3	4,39 €
CDP3-6-16	3	16	6	1	2,6	8,97 €	CDP6.1-12-16	6,1	16	12	1,5	10	4,95 €
CDP3.1-6-8	3,1	8	6	1	1,2	4,02 €	CDP6.1-12-20	6,1	20	12	1,5	13	8,97 €
CDP3.1-6-12	3,1	12	6	1	1,9	4,39 €	CDP6.5-12-10	6,5	10	12	1,5	6	4,39 €
CDP3.1-6-16	3,1	16	6	1	2,5	8,97 €	CDP6.5-12-16	6,5	16	12	1,5	9,7	4,95 €
CDP3.5-7-8	3,5	8	7	1	1,7	6,32 €	CDP6.5-12-20	6,5	20	12	1,5	12	8,97 €
CDP3.5-7-12	3,5	12	7	1	2,6	4,16 €	CDP7-12-10	7	10	12	1,5	5,6	4,39 €
CDP3.5-7-16	3,5	16	7	1	3,6	8,97 €	CDP7-12-16	7	16	12	1,5	9,1	4,95 €
CDP4-7-8	4	8	7	1	1,5	3,64 €	CDP7-12-20	7	20	12	1,5	11	8,97 €
CDP4-7-12	4	12	7	1	2,4	4,16 €	CDP7.1-12-10	7,1	10	12	1,5	5,5	4,39 €
CDP4-7-16	4	16	7	1	3,2	8,97 €	CDP7.1-12-16	7,1	16	12	1,5	9	4,95 €
CDP4.1-8-8	4,1	8	8	1	2,2	3,79 €	CDP7.1-12-20	7,1	20	12	1,5	11	8,97 €
CDP4.1-8-12	4,1	12	8	1	3,4	4,39 €	CDP7.5-12-10	7,5	10	12	1,5	5,1	4,39 €
CDP4.1-8-16	4,1	16	8	1	4,6	7,87 €	CDP7.5-12-16	7,5	16	12	1,5	8,4	4,95 €
CDP4.5-8-8	4,5	8	8	1	2,1	3,79 €	CDP7.5-12-20	7,5	20	12	1,5	11	8,97 €
CDP4.5-8-12	4,5	12	8	1	3,1	4,39 €	CDP8-12-10	8	10	12	1,5	4,7	4,39 €
CDP4.5-8-16	4,5	16	8	1	4,2	7,87 €	CDP8-12-16	8	16	12	1,5	7,6	4,95 €
CDP5-8-8	5	8	8	1	1,8	3,79 €	CDP8-12-20	8	20	12	1,5	9,6	8,97 €
CDP5-8-12	5	12	8	1	2,8	4,39 €	CDP8.1-15-12	8,1	12	15	2	11	4,57 €
CDP5-8-16	5	16	8	1	3,7	7,87 €	CDP8.1-15-20	8,1	20	15	2	19	5,58 €
CDP5.1-10-10	5,1	10	10	1,5	4,4	4,16 €	CDP8.1-15-25	8,1	25	15	2	24	9,68 €
CDP5.1-10-16	5,1	16	10	1,5	7,1	4,80 €	CDP8.5-15-12	8,5	12	15	2	11	4,57 €

Dimensions in mm

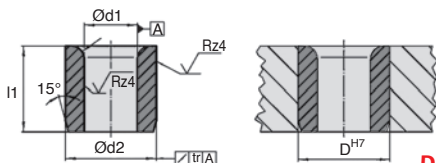

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	Ød1	l1	Ød2 (n6)	r	Weight (g)	Price each 1 to 4	Part number	Ød1	l1	Ød2 (n6)	r	Weight (g)	Price each 1 to 4
CDP8.5-15-20	8,5	20	15	2	18	5,58 €	CDP13-22-36	13	36	22	2	69	12,53 €
CDP8.5-15-25	8,5	25	15	2	23	9,68 €	CDP14-22-16	14	16	22	2	27	5,93 €
CDP9-15-12	9	12	15	2	10	4,57 €	CDP14-22-28	14	28	22	2	49	8,02 €
CDP9-15-20	9	20	15	2	17	5,58 €	CDP14-22-36	14	36	22	2	63	12,53 €
CDP9-15-25	9	25	15	2	22	9,68 €	CDP15-22-16	15	16	22	2	25	5,93 €
CDP9.1-15-12	9,1	12	15	2	10	4,57 €	CDP15-22-28	15	28	22	2	44	8,02 €
CDP9.1-15-20	9,1	20	15	2	17	5,58 €	CDP15-22-36	15	36	22	2	56	12,53 €
CDP9.1-15-25	9,1	25	15	2	21	9,68 €	CDP16-26-16	16	16	26	2	45	8,02 €
CDP9.5-15-12	9,5	12	15	2	9,5	4,57 €	CDP16-26-28	16	28	26	2	71	10,12 €
CDP9.5-15-20	9,5	20	15	2	16	5,58 €	CDP16-26-36	16	36	26	2	92	15,75 €
CDP9.5-15-25	9,5	25	15	2	20	9,68 €	CDP16.1-26-16	16,1	16	26	2	40	12,19 €
CDP10-15-12	10	12	15	2	8,8	4,57 €	CDP16.1-26-28	16,1	28	26	2	71	14,90 €
CDP10-15-20	10	20	15	2	15	5,58 €	CDP16.1-26-36	16,1	36	26	2	91	21,14 €
CDP10-15-25	10	25	15	2	19	9,68 €	CDP16.5-26-16	16,5	16	26	2	39	8,02 €
CDP10.1-18-12	10,1	12	18	2	16	5,32 €	CDP16.5-26-28	16,5	28	26	2	68	10,12 €
CDP10.1-18-20	10,1	20	18	2	27	6,47 €	CDP16.5-26-36	16,5	36	26	2	88	15,75 €
CDP10.1-18-25	10,1	25	18	2	33	10,01 €	CDP17-26-16	17	16	26	2	37	8,02 €
CDP10.5-18-12	10,5	12	18	2	15	5,32 €	CDP17-26-28	17	28	26	2	65	10,12 €
CDP10.5-18-20	10,5	20	18	2	26	6,47 €	CDP17-26-36	17	36	26	2	84	15,75 €
CDP10.5-18-25	10,5	25	18	2	32	10,01 €	CDP18-26-16	18	16	26	2	33	8,02 €
CDP11-18-12	11	12	18	2	14	5,32 €	CDP18-26-28	18	28	26	2	59	10,12 €
CDP11-18-20	11	20	18	2	24	6,47 €	CDP18-26-36	18	36	26	2	77	15,75 €
CDP11-18-25	11	25	18	2	31	10,01 €	CDP19-30-20	19	20	30	3	64	9,90 €
CDP11.1-18-12	11,1	12	18	2	14	5,32 €	CDP19-30-36	19	36	30	3	117	12,42 €
CDP11.1-18-20	11,1	20	18	2	24	6,47 €	CDP19-30-45	19	45	30	3	147	20,05 €
CDP11.1-18-25	11,1	25	18	2	30	10,01 €	CDP20-30-20	20	20	30	3	59	9,90 €
CDP11.5-18-12	11,5	12	18	2	14	5,32 €	CDP20-30-36	20	36	30	3	108	12,42 €
CDP11.5-18-20	11,5	20	18	2	23	6,47 €	CDP20-30-45	20	45	30	3	136	20,05 €
CDP11.5-18-25	11,5	25	18	2	29	10,01 €	CDP20.1-30-20	20,1	20	30	3	59	14,48 €
CDP12-18-12	12	12	18	2	13	5,32 €	CDP20.1-30-36	20,1	36	30	3	108	17,51 €
CDP12-18-20	12	20	18	2	22	6,47 €	CDP20.1-30-45	20,1	45	30	3	135	27,24 €
CDP12-18-25	12	25	18	2	27	10,01 €	CDP22-30-20	22	20	30	3	49	9,90 €
CDP12.1-22-16	12,1	16	22	2	32	5,93 €	CDP22-30-36	22	36	30	3	90	12,42 €
CDP12.1-22-28	12,1	28	22	2	57	8,02 €	CDP22-30-45	22	45	30	3	113	20,05 €
CDP12.1-22-36	12,1	36	22	2	74	12,53 €	CDP25-35-20	25	20	35	3	71	11,69 €
CDP12.5-22-16	12,5	16	22	2	31	5,93 €	CDP25-35-36	25	36	35	3	130	14,48 €
CDP12.5-22-28	12,5	28	22	2	66	8,02 €	CDP25-35-45	25	45	35	3	163	23,29 €
CDP12.5-22-36	12,5	36	22	2	69	12,53 €	CDP30-42-25	30	25	42	3	129	20,99 €
CDP13-22-16	13	16	22	2	30	5,93 €	CDP30-42-45	30	45	42	3	235	25,93 €
CDP13-22-28	13	28	22	2	53	8,02 €	CDP30-42-56	30	56	42	3	293	39,44 €


Dimensions in mm

Fax 0 825 88 6000
 Service 0,15 € / min
 + prix appel

Our other products



PAL
Self locking counter nut, For axial locking

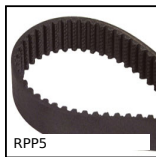

RPP5
RPP-type belt HTD compatible, RPP5



ACLERP
Roller block, Without guide rail



RCC_RCX
Spherical tilt washer - DIN 6319, convex



WINGbrEcrou
Manually tightened wing nut, Brass DIN 315



HW_HT
Half-rail guide, Wheel




ACM_AZ
Manual bonnet fastener, Hook



HTD5M-BAR
Toothed bar stock for RPP-type belt, HTD5



 ZBconique
Machined plastic bevel gear (delrin), 1:1



RAP
Captive washer, Nylon



ACLBTS
Closing system, Spacer for spherical ended stop



SMS
Spiral bevel gear, 1:1

Complementary products



CDPC
Flanged drill bushing, Steel



PRES2HR
Manual bench press, Force up to 200kg



PRES4HR
Manual bench press, Force up to 600kg



PRES5HR
Manual bench press, Force up to 500kg