

Flanged drill bushing

CDPC

Treated steel

- For guiding drill bits during repetitive drilling or countersinking operations
- Good resistance in operation
- Material:
Case hardened steel

Info.

- Bore tolerance: DH7

Advantages

- Facilitates the drilling operation and avoids wear of the drill bit
- Ensures high repeatability




DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	Ød1	I1	Ød2 (n6)	Ød3	I2	Weight (g)	Price each 1 to 4	Part number	Ød1	I1	Ød2 (n6)	Ød3	I2	Weight (g)	Price each 1 to 4
CDPC2-5-6	2	6	5	8	2	1,2	5,32 €	CDPC5-1-10-20	5,1	20	10	13	3	10	9,30 €
CDPC2-5-9	2	9	5	8	2	1,6	5,73 €	CDPC5-5-10-10	5,5	10	10	13	3	5,3	4,95 €
CDPC2-1-5-6	2,1	6	5	8	2	1,2	5,32 €	CDPC5-5-10-16	5,5	16	10	13	3	7,9	5,58 €
CDPC2-1-5-9	2,1	9	5	8	2	1,5	5,73 €	CDPC5-5-10-20	5,5	20	10	13	3	9,6	9,30 €
CDPC2-5-5-6	2,5	6	5	8	2	1,1	5,32 €	CDPC6-10-10	6	10	10	13	3	4,9	4,95 €
CDPC2-5-5-9	2,5	9	5	8	2	1,4	5,73 €	CDPC6-10-16	6	16	10	13	3	7,3	5,58 €
CDPC3-6-8	3	8	6	9	2,5	1,9	5,24 €	CDPC6-10-20	6	20	10	13	3	8,8	9,30 €
CDPC3-6-12	3	12	6	9	2,5	2,6	5,73 €	CDPC6-1-12-10	6,1	10	12	15	3	7,7	5,58 €
CDPC3-6-16	3	16	6	9	2,5	3,2	10,01 €	CDPC6-1-12-16	6,1	16	12	15	3	12	6,09 €
CDPC3-1-6-8	3,1	8	6	9	2,5	1,9	5,24 €	CDPC6-1-12-20	6,1	20	12	15	3	14	9,90 €
CDPC3-1-6-12	3,1	12	6	9	2,5	2,5	5,73 €	CDPC6-5-12-10	6,5	10	12	15	3	7,4	5,58 €
CDPC3-1-6-16	3,1	16	6	9	2,5	3,2	10,01 €	CDPC6-5-12-16	6,5	16	12	15	3	11	6,09 €
CDPC3-5-7-8	3,5	8	7	10	2,5	2,4	4,95 €	CDPC6-5-12-20	6,5	20	12	15	3	14	9,90 €
CDPC3-5-7-12	3,5	12	7	10	2,5	3,4	5,58 €	CDPC7-12-10	7	10	12	15	3	7	5,58 €
CDPC3-5-7-16	3,5	16	7	10	2,5	4,3	10,01 €	CDPC7-12-16	7	16	12	15	3	10	6,09 €
CDPC4-7-8	4	8	7	10	2,5	2,3	4,95 €	CDPC7-12-20	7	20	12	15	3	13	9,90 €
CDPC4-7-12	4	12	7	10	2,5	3,1	5,58 €	CDPC7-1-12-10	7,1	10	12	15	3	6,9	5,58 €
CDPC4-7-16	4	16	7	10	2,5	3,9	10,01 €	CDPC7-1-12-16	7,1	16	12	15	3	10	6,09 €
CDPC4-1-8-8	4,1	8	8	11	2,5	3	4,80 €	CDPC7-1-12-20	7,1	20	12	15	3	13	9,90 €
CDPC4-1-8-12	4,1	12	8	11	2,5	4,2	5,09 €	CDPC7-5-12-10	7,5	10	12	15	3	6,5	5,58 €
CDPC4-1-8-16	4,1	16	8	11	2,5	5,3	8,59 €	CDPC7-5-12-16	7,5	16	12	15	3	9,7	6,09 €
CDPC4-5-8-8	4,5	8	8	11	2,5	2,9	4,80 €	CDPC7-5-12-20	7,5	20	12	15	3	12	9,90 €
CDPC4-5-8-12	4,5	12	8	11	2,5	3,9	5,09 €	CDPC8-12-10	8	10	12	15	3	6	5,58 €
CDPC4-5-8-16	4,5	16	8	11	2,5	5	8,59 €	CDPC8-12-16	8	16	12	15	3	9	6,09 €
CDPC5-8-8	5	8	8	11	2,5	2,6	4,80 €	CDPC8-12-20	8	20	12	15	3	11	9,90 €
CDPC5-8-12	5	12	8	11	2,5	3,6	5,09 €	CDPC8-1-15-12	8,1	12	15	18	3	13	6,32 €
CDPC5-8-16	5	16	8	11	2,5	4,5	8,59 €	CDPC8-1-15-20	8,1	20	15	18	3	25	6,85 €
CDPC5-1-10-10	5,1	10	10	13	3	5,5	4,95 €	CDPC8-1-15-25	8,1	25	15	18	3	26	10,73 €
CDPC5-1-10-16	5,1	16	10	13	3	8,2	5,58 €	CDPC8-5-15-12	8,5	12	15	18	3	13	6,32 €

Dimensions in mm

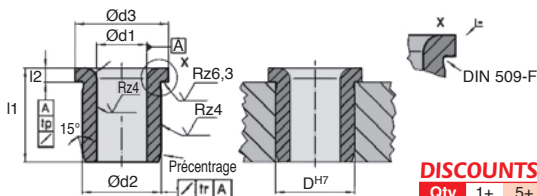

DISCOUNTS

Qty Disc.	1+	5+	10+	20+
	List	-5%	-10%	On request

Part number	Ød1	l1	Ød2 (n6)	Ød3	l2	Weight (g)	Price each 1 to 4	Part number	Ød1	l1	Ød2 (n6)	Ød3	l2	Weight (g)	Price each 1 to 4
CDPC8.5-15-20	8,5	20	15	18	3	20	6,85 €	CDPC13-22-36	13	36	22	26	4	73	16,15 €
CDPC8.5-15-25	8,5	25	15	18	3	25	10,73 €	CDPC14-22-16	14	16	22	26	4	32	7,84 €
CDPC9-15-12	9	12	15	18	3	12	6,32 €	CDPC14-22-28	14	28	22	26	4	53	11,05 €
CDPC9-15-20	9	20	15	18	3	19	6,85 €	CDPC14-22-36	14	36	22	26	4	67	16,15 €
CDPC9-15-25	9	25	15	18	3	23	10,73 €	CDPC15-22-16	15	16	22	26	4	29	7,84 €
CDPC9.1-15-12	9,1	12	15	18	3	12	6,32 €	CDPC15-22-28	15	28	22	26	4	48	11,05 €
CDPC9.1-15-20	9,1	20	15	18	3	19	6,85 €	CDPC15-22-36	15	36	22	26	4	61	16,15 €
CDPC9.1-15-25	9,1	25	15	18	3	23	10,73 €	CDPC16-26-16	16	16	26	30	4	45	9,90 €
CDPC9.5-15-12	9,5	12	15	18	3	11	6,32 €	CDPC16-26-28	16	28	26	30	4	76	12,95 €
CDPC9.5-15-20	9,5	20	15	18	3	18	6,85 €	CDPC16-26-36	16	36	26	30	4	97	17,72 €
CDPC9.5-15-25	9,5	25	15	18	3	22	10,73 €	CDPC16.1-26-16	16,1	16	26	30	4	45	14,13 €
CDPC10-15-12	10	12	15	18	3	11	6,32 €	CDPC16.1-26-28	16,1	28	26	30	4	76	17,51 €
CDPC10-15-20	10	20	15	18	3	17	6,85 €	CDPC16.1-26-36	16,1	36	26	30	4	96	22,93 €
CDPC10-15-25	10	25	15	18	3	20	10,73 €	CDPC16.5-26-16	16,5	16	26	30	4	44	9,90 €
CDPC10.1-18-12	10,1	12	18	22	4	20	6,85 €	CDPC16.5-26-28	16,5	28	26	30	4	73	12,95 €
CDPC10.1-18-20	10,1	20	18	22	4	30	7,46 €	CDPC16.5-26-36	16,5	36	26	30	4	93	17,57 €
CDPC10.1-18-25	10,1	25	18	22	4	37	11,46 €	CDPC17-26-16	17	16	26	30	4	42	9,90 €
CDPC10.5-18-12	10,5	12	18	22	4	19	6,85 €	CDPC17-26-28	17	28	26	30	4	70	12,95 €
CDPC10.5-18-20	10,5	20	18	22	4	29	7,46 €	CDPC17-26-36	17	36	26	30	4	90	17,57 €
CDPC10.5-18-25	10,5	25	18	22	4	36	11,46 €	CDPC18-26-16	18	16	26	30	4	39	9,90 €
CDPC11-18-12	11	12	18	22	4	18	6,85 €	CDPC18-26-28	18	28	26	30	4	64	12,95 €
CDPC11-18-20	11	20	18	22	4	28	7,46 €	CDPC18-26-36	18	36	26	30	4	82	17,57 €
CDPC11-18-25	11	25	18	22	4	34	11,46 €	CDPC19-30-20	19	20	30	34	5	71	12,95 €
CDPC11.1-18-12	11,1	12	18	22	4	18	6,85 €	CDPC19-30-36	19	36	30	34	5	125	17,20 €
CDPC11.1-18-20	11,1	20	18	22	4	28	7,46 €	CDPC19-30-45	19	45	30	34	5	154	25,79 €
CDPC11.1-18-25	11,1	25	18	22	4	34	11,46 €	CDPC20-30-20	20	20	30	34	5	67	12,95 €
CDPC10.1-18-12	11,5	12	18	22	4	17	6,85 €	CDPC20-30-36	20	36	30	34	5	0	17,20 €
CDPC11.5-18-20	11,5	20	18	22	4	26	7,46 €	CDPC20-30-45	20	45	30	34	5	143	25,79 €
CDPC11.5-18-25	11,5	25	18	22	4	33	11,46 €	CDPC20.1-30-20	20,1	20	30	34	5	66	17,20 €
CDPC12-18-12	12	12	18	22	4	16	6,85 €	CDPC20.1-30-36	20,1	36	30	34	5	115	22,52 €
CDPC12-18-20	12	20	18	22	4	25	7,46 €	CDPC20.1-30-45	20,1	45	30	34	5	142	32,96 €
CDPC12-18-25	12	25	18	22	4	31	11,46 €	CDPC22-30-20	22	20	30	34	5	56	12,95 €
CDPC12.1-22-16	12,1	16	22	26	4	37	7,84 €	CDPC22-30-36	22	36	30	34	5	97	17,20 €
CDPC12.1-22-28	12,1	28	22	26	4	62	11,05 €	CDPC22-30-45	22	45	30	34	5	120	25,79 €
CDPC12.1-22-36	12,1	36	22	26	4	78	16,15 €	CDPC25-35-20	25	20	35	39	5	80	16,62 €
CDPC12.5-22-16	12,5	16	22	26	4	36	7,84 €	CDPC25-35-36	25	36	35	39	5	138	20,44 €
CDPC12.5-22-28	12,5	28	22	26	4	60	11,05 €	CDPC25-35-45	25	45	35	39	5	171	30,46 €
CDPC12.5-22-36	12,5	36	22	26	4	76	16,15 €	CDPC30-42-25	30	25	42	46	5	139	24,81 €
CDPC13-22-16	13	16	22	26	4	34	7,84 €	CDPC30-42-45	30	45	42	46	5	245	29,39 €
CDPC13-22-28	13	28	22	26	4	58	11,05 €	CDPC30-42-56	30	56	42	46	5	304	44,81 €

Dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



PTMR

Telescopic furniture foot, threaded stud



PSG08S

Spur gear - precision range, Stainless steel 316



BPFss

Pressed stainless steel flange bearing, Stainless steel



PSG1

Spur gear - precision range, Case hardened steel 20NCD2



DEP

Tools Hygienic Usit® and Hygienic Design®, Protective insert for s...



SLH-M

Nut for toggle clamp, Round ended nut for SLH/SLV clamp



CHCSS

Socket headed screw, Stainless steel - A2



FF30

Offset spur gear reducer, from 21.50 to 83 Nm



RBGpl

Swivel castor with double brake, Steel - grey rubber



 
ADL_M

Male eye bolt conforms to DIN580, Stainless steel



DTR

Chain idler sprocket, Chain idler sprocket - Plastic



PRFbou

Emergency release button for aluminium profile, Emergency release bu...

Complementary products



CDP

Flanged drill bushing, Steel



PRES2HR

Manual workbench press, Force up to 200kg



PRES3HR

Manual workbench press, Force up to 400kg



PRES4HR

Manual workbench press, Force up to 600kg