

Flanged drill bushing

CDPC

Treated steel

- For guiding drill bits during repetitive drilling or countersinking operations
- Good resistance in operation
- Material:
Case hardened steel

Info.

- Bore tolerance: DH7

Advantages

- Facilitates the drilling operation and avoids wear of the drill bit
- Ensures high repeatability




DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	Ød1	I1	Ød2 (n6)	Ød3	I2	Weight (g)	Price each 1 to 4	Part number	Ød1	I1	Ød2 (n6)	Ød3	I2	Weight (g)	Price each 1 to 4
CDPC2-5-6	2	6	5	8	2	1,2	5,32 €	CDPC5-1-10-20	5,1	20	10	13	3	10	9,30 €
CDPC2-5-9	2	9	5	8	2	1,6	5,73 €	CDPC5-5-10-10	5,5	10	10	13	3	5,3	4,95 €
CDPC2-1-5-6	2,1	6	5	8	2	1,2	5,32 €	CDPC5-5-10-16	5,5	16	10	13	3	7,9	5,58 €
CDPC2-1-5-9	2,1	9	5	8	2	1,5	5,73 €	CDPC5-5-10-20	5,5	20	10	13	3	9,6	9,30 €
CDPC2-5-5-6	2,5	6	5	8	2	1,1	5,32 €	CDPC6-10-10	6	10	10	13	3	4,9	4,95 €
CDPC2-5-5-9	2,5	9	5	8	2	1,4	5,73 €	CDPC6-10-16	6	16	10	13	3	7,3	5,58 €
CDPC3-6-8	3	8	6	9	2,5	1,9	5,24 €	CDPC6-10-20	6	20	10	13	3	8,8	9,30 €
CDPC3-6-12	3	12	6	9	2,5	2,6	5,73 €	CDPC6-1-12-10	6,1	10	12	15	3	7,7	5,58 €
CDPC3-6-16	3	16	6	9	2,5	3,2	10,01 €	CDPC6-1-12-16	6,1	16	12	15	3	12	6,09 €
CDPC3-1-6-8	3,1	8	6	9	2,5	1,9	5,24 €	CDPC6-1-12-20	6,1	20	12	15	3	14	9,90 €
CDPC3-1-6-12	3,1	12	6	9	2,5	2,5	5,73 €	CDPC6-5-12-10	6,5	10	12	15	3	7,4	5,58 €
CDPC3-1-6-16	3,1	16	6	9	2,5	3,2	10,01 €	CDPC6-5-12-16	6,5	16	12	15	3	11	6,09 €
CDPC3-5-7-8	3,5	8	7	10	2,5	2,4	4,95 €	CDPC6-5-12-20	6,5	20	12	15	3	14	9,90 €
CDPC3-5-7-12	3,5	12	7	10	2,5	3,4	5,58 €	CDPC7-12-10	7	10	12	15	3	7	5,58 €
CDPC3-5-7-16	3,5	16	7	10	2,5	4,3	10,01 €	CDPC7-12-16	7	16	12	15	3	10	6,09 €
CDPC4-7-8	4	8	7	10	2,5	2,3	4,95 €	CDPC7-12-20	7	20	12	15	3	13	9,90 €
CDPC4-7-12	4	12	7	10	2,5	3,1	5,58 €	CDPC7-1-12-10	7,1	10	12	15	3	6,9	5,58 €
CDPC4-7-16	4	16	7	10	2,5	3,9	10,01 €	CDPC7-1-12-16	7,1	16	12	15	3	10	6,09 €
CDPC4-1-8-8	4,1	8	8	11	2,5	3	4,80 €	CDPC7-1-12-20	7,1	20	12	15	3	13	9,90 €
CDPC4-1-8-12	4,1	12	8	11	2,5	4,2	5,09 €	CDPC7-5-12-10	7,5	10	12	15	3	6,5	5,58 €
CDPC4-1-8-16	4,1	16	8	11	2,5	5,3	8,59 €	CDPC7-5-12-16	7,5	16	12	15	3	9,7	6,09 €
CDPC4-5-8-8	4,5	8	8	11	2,5	2,9	4,80 €	CDPC7-5-12-20	7,5	20	12	15	3	12	9,90 €
CDPC4-5-8-12	4,5	12	8	11	2,5	3,9	5,09 €	CDPC8-12-10	8	10	12	15	3	6	5,58 €
CDPC4-5-8-16	4,5	16	8	11	2,5	5	8,59 €	CDPC8-12-16	8	16	12	15	3	9	6,09 €
CDPC5-8-8	5	8	8	11	2,5	2,6	4,80 €	CDPC8-12-20	8	20	12	15	3	11	9,90 €
CDPC5-8-12	5	12	8	11	2,5	3,6	5,09 €	CDPC8-1-15-12	8,1	12	15	18	3	13	6,32 €
CDPC5-8-16	5	16	8	11	2,5	4,5	8,59 €	CDPC8-1-15-20	8,1	20	15	18	3	25	6,85 €
CDPC5-1-10-10	5,1	10	10	13	3	5,5	4,95 €	CDPC8-1-15-25	8,1	25	15	18	3	26	10,73 €
CDPC5-1-10-16	5,1	16	10	13	3	8,2	5,58 €	CDPC8-5-15-12	8,5	12	15	18	3	13	6,32 €

Dimensions in mm

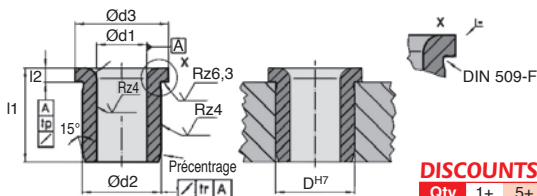

DISCOUNTS

Qty	1+	5+	10+	20+
	Disc.	List	-5%	-10%

Part number	Ød1	l1	Ød2			Weight (g)	Price each		Part number	Ød1	l1	Ød2			Weight (g)	Price each	
			(n6)	Ød3	l2		1 to 4	1 to 4				(n6)	Ød3	l2		1 to 4	1 to 4
CDPC8.5-15-20	8,5	20	15	18	3	20	6,85	€	CDPC13-22-36	13	36	22	26	4	73	16,15	€
CDPC8.5-15-25	8,5	25	15	18	3	25	10,73	€	CDPC14-22-16	14	16	22	26	4	32	7,84	€
CDPC9-15-12	9	12	15	18	3	12	6,32	€	CDPC14-22-28	14	28	22	26	4	53	11,05	€
CDPC9-15-20	9	20	15	18	3	19	6,85	€	CDPC14-22-36	14	36	22	26	4	67	16,15	€
CDPC9-15-25	9	25	15	18	3	23	10,73	€	CDPC15-22-16	15	16	22	26	4	29	7,84	€
CDPC9.1-15-12	9,1	12	15	18	3	12	6,32	€	CDPC15-22-28	15	28	22	26	4	48	11,05	€
CDPC9.1-15-20	9,1	20	15	18	3	19	6,85	€	CDPC15-22-36	15	36	22	26	4	61	16,15	€
CDPC9.1-15-25	9,1	25	15	18	3	23	10,73	€	CDPC16-26-16	16	16	26	30	4	45	9,90	€
CDPC9.5-15-12	9,5	12	15	18	3	11	6,32	€	CDPC16-26-28	16	28	26	30	4	76	12,95	€
CDPC9.5-15-20	9,5	20	15	18	3	18	6,85	€	CDPC16-26-36	16	36	26	30	4	97	17,72	€
CDPC9.5-15-25	9,5	25	15	18	3	22	10,73	€	CDPC16.1-26-16	16,1	16	26	30	4	45	14,13	€
CDPC10-15-12	10	12	15	18	3	11	6,32	€	CDPC16.1-26-28	16,1	28	26	30	4	76	17,51	€
CDPC10-15-20	10	20	15	18	3	17	6,85	€	CDPC16.1-26-36	16,1	36	26	30	4	96	22,93	€
CDPC10-15-25	10	25	15	18	3	20	10,73	€	CDPC16.5-26-16	16,5	16	26	30	4	44	9,90	€
CDPC10.1-18-12	10,1	12	18	22	4	20	6,85	€	CDPC16.5-26-28	16,5	28	26	30	4	73	12,95	€
CDPC10.1-18-20	10,1	20	18	22	4	30	7,46	€	CDPC16.5-26-36	16,5	36	26	30	4	93	17,57	€
CDPC10.1-18-25	10,1	25	18	22	4	37	11,46	€	CDPC17-26-16	17	16	26	30	4	42	9,90	€
CDPC10.5-18-12	10,5	12	18	22	4	19	6,85	€	CDPC17-26-28	17	28	26	30	4	70	12,95	€
CDPC10.5-18-20	10,5	20	18	22	4	29	7,46	€	CDPC17-26-36	17	36	26	30	4	90	17,57	€
CDPC10.5-18-25	10,5	25	18	22	4	36	11,46	€	CDPC18-26-16	18	16	26	30	4	39	9,90	€
CDPC11-18-12	11	12	18	22	4	18	6,85	€	CDPC18-26-28	18	28	26	30	4	64	12,95	€
CDPC11-18-20	11	20	18	22	4	28	7,46	€	CDPC18-26-36	18	36	26	30	4	82	17,57	€
CDPC11-18-25	11	25	18	22	4	34	11,46	€	CDPC19-30-20	19	20	30	34	5	71	12,95	€
CDPC11.1-18-12	11,1	12	18	22	4	18	6,85	€	CDPC19-30-36	19	36	30	34	5	125	17,20	€
CDPC11.1-18-20	11,1	20	18	22	4	28	7,46	€	CDPC19-30-45	19	45	30	34	5	154	25,79	€
CDPC11.1-18-25	11,1	25	18	22	4	34	11,46	€	CDPC20-30-20	20	20	30	34	5	67	12,95	€
CDPC10.1-18-12	11,5	12	18	22	4	17	6,85	€	CDPC20-30-36	20	36	30	34	5	0	17,20	€
CDPC11.5-18-20	11,5	20	18	22	4	26	7,46	€	CDPC20-30-45	20	45	30	34	5	143	25,79	€
CDPC11.5-18-25	11,5	25	18	22	4	33	11,46	€	CDPC20.1-30-20	20,1	20	30	34	5	66	17,20	€
CDPC12-18-12	12	12	18	22	4	16	6,85	€	CDPC20.1-30-36	20,1	36	30	34	5	115	22,52	€
CDPC12-18-20	12	20	18	22	4	25	7,46	€	CDPC20.1-30-45	20,1	45	30	34	5	142	32,96	€
CDPC12-18-25	12	25	18	22	4	31	11,46	€	CDPC22-30-20	22	20	30	34	5	56	12,95	€
CDPC12.1-22-16	12,1	16	22	26	4	37	7,84	€	CDPC22-30-36	22	36	30	34	5	97	17,20	€
CDPC12.1-22-28	12,1	28	22	26	4	62	11,05	€	CDPC22-30-45	22	45	30	34	5	120	25,79	€
CDPC12.1-22-36	12,1	36	22	26	4	78	16,15	€	CDPC25-35-20	25	20	35	39	5	80	16,62	€
CDPC12.5-22-16	12,5	16	22	26	4	36	7,84	€	CDPC25-35-36	25	36	35	39	5	138	20,44	€
CDPC12.5-22-28	12,5	28	22	26	4	60	11,05	€	CDPC25-35-45	25	45	35	39	5	171	30,46	€
CDPC12.5-22-36	12,5	36	22	26	4	76	16,15	€	CDPC30-42-25	30	25	42	46	5	139	24,81	€
CDPC13-22-16	13	16	22	26	4	34	7,84	€	CDPC30-42-45	30	45	42	46	5	245	29,39	€
CDPC13-22-28	13	28	22	26	4	58	11,05	€	CDPC30-42-56	30	56	42	46	5	304	44,81	€

Dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



BSM

Spring plunger with internal hexagonal socket, stainless steel 303 b...



H0

Crossed helical gear crossed axis at 90°, Steel 20NCD2



UCFL_SS

Stainless steel flanged bearing, Stainless steel



CLB_T

Die cast zinc clamping lever - male, Zamak



BPPE

Ball transfer unit push fit, Light



BABTV

Ball lock pins lockable, Stainless steel



PARF110

Pressed steel base rigid foot, Swivelling Ø110




CAP821

Slat top chain acetal, Large range 821



H1

 Crossed helical gear crossed axis at 90°, Machined plastic



PO

Pull handle - Multi-sector, Smooth hole



MDB_MTB

Moulded plastic bevel gear (nylon), 2:1



RT25

Self-centering flanged locking assembly, Medium/high torque

Complementary products



CDP

Flanged drill bushing, Steel



PRES2HR

Manual workbench press, Force up to 200kg



PRES3HR

Manual workbench press, Force up to 400kg



PRES4HR

Manual workbench press, Force up to 600kg