

Flanged drill bushing

CDPC

Treated steel

- For guiding drill bits during repetitive drilling or countersinking operations
- Good resistance in operation
- Material:
Case hardened steel

Info.

- Bore tolerance: DH7

Advantages

- Facilitates the drilling operation and avoids wear of the drill bit
- Ensures high repeatability




DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	Ød1	I1	Ød2 (n6)	Ød3	I2	Weight (g)	Price each 1 to 4	Part number	Ød1	I1	Ød2 (n6)	Ød3	I2	Weight (g)	Price each 1 to 4
CDPC2-5-6	2	6	5	8	2	1,2	5,32 €	CDPC5-1-10-20	5,1	20	10	13	3	10	9,30 €
CDPC2-5-9	2	9	5	8	2	1,6	5,73 €	CDPC5-5-10-10	5,5	10	10	13	3	5,3	4,95 €
CDPC2-1-5-6	2,1	6	5	8	2	1,2	5,32 €	CDPC5-5-10-16	5,5	16	10	13	3	7,9	5,58 €
CDPC2-1-5-9	2,1	9	5	8	2	1,5	5,73 €	CDPC5-5-10-20	5,5	20	10	13	3	9,6	9,30 €
CDPC2-5-5-6	2,5	6	5	8	2	1,1	5,32 €	CDPC6-10-10	6	10	10	13	3	4,9	4,95 €
CDPC2-5-5-9	2,5	9	5	8	2	1,4	5,73 €	CDPC6-10-16	6	16	10	13	3	7,3	5,58 €
CDPC3-6-8	3	8	6	9	2,5	1,9	5,24 €	CDPC6-10-20	6	20	10	13	3	8,8	9,30 €
CDPC3-6-12	3	12	6	9	2,5	2,6	5,73 €	CDPC6-1-12-10	6,1	10	12	15	3	7,7	5,58 €
CDPC3-6-16	3	16	6	9	2,5	3,2	10,01 €	CDPC6-1-12-16	6,1	16	12	15	3	12	6,09 €
CDPC3-1-6-8	3,1	8	6	9	2,5	1,9	5,24 €	CDPC6-1-12-20	6,1	20	12	15	3	14	9,90 €
CDPC3-1-6-12	3,1	12	6	9	2,5	2,5	5,73 €	CDPC6-5-12-10	6,5	10	12	15	3	7,4	5,58 €
CDPC3-1-6-16	3,1	16	6	9	2,5	3,2	10,01 €	CDPC6-5-12-16	6,5	16	12	15	3	11	6,09 €
CDPC3-5-7-8	3,5	8	7	10	2,5	2,4	4,95 €	CDPC6-5-12-20	6,5	20	12	15	3	14	9,90 €
CDPC3-5-7-12	3,5	12	7	10	2,5	3,4	5,58 €	CDPC7-12-10	7	10	12	15	3	7	5,58 €
CDPC3-5-7-16	3,5	16	7	10	2,5	4,3	10,01 €	CDPC7-12-16	7	16	12	15	3	10	6,09 €
CDPC4-7-8	4	8	7	10	2,5	2,3	4,95 €	CDPC7-12-20	7	20	12	15	3	13	9,90 €
CDPC4-7-12	4	12	7	10	2,5	3,1	5,58 €	CDPC7-1-12-10	7,1	10	12	15	3	6,9	5,58 €
CDPC4-7-16	4	16	7	10	2,5	3,9	10,01 €	CDPC7-1-12-16	7,1	16	12	15	3	10	6,09 €
CDPC4-1-8-8	4,1	8	8	11	2,5	3	4,80 €	CDPC7-1-12-20	7,1	20	12	15	3	13	9,90 €
CDPC4-1-8-12	4,1	12	8	11	2,5	4,2	5,09 €	CDPC7-5-12-10	7,5	10	12	15	3	6,5	5,58 €
CDPC4-1-8-16	4,1	16	8	11	2,5	5,3	8,59 €	CDPC7-5-12-16	7,5	16	12	15	3	9,7	6,09 €
CDPC4-5-8-8	4,5	8	8	11	2,5	2,9	4,80 €	CDPC7-5-12-20	7,5	20	12	15	3	12	9,90 €
CDPC4-5-8-12	4,5	12	8	11	2,5	3,9	5,09 €	CDPC8-12-10	8	10	12	15	3	6	5,58 €
CDPC4-5-8-16	4,5	16	8	11	2,5	5	8,59 €	CDPC8-12-16	8	16	12	15	3	9	6,09 €
CDPC5-8-8	5	8	8	11	2,5	2,6	4,80 €	CDPC8-12-20	8	20	12	15	3	11	9,90 €
CDPC5-8-12	5	12	8	11	2,5	3,6	5,09 €	CDPC8-1-15-12	8,1	12	15	18	3	13	6,32 €
CDPC5-8-16	5	16	8	11	2,5	4,5	8,59 €	CDPC8-1-15-20	8,1	20	15	18	3	25	6,85 €
CDPC5-1-10-10	5,1	10	10	13	3	5,5	4,95 €	CDPC8-1-15-25	8,1	25	15	18	3	26	10,73 €
CDPC5-1-10-16	5,1	16	10	13	3	8,2	5,58 €	CDPC8-5-15-12	8,5	12	15	18	3	13	6,32 €

Dimensions in mm

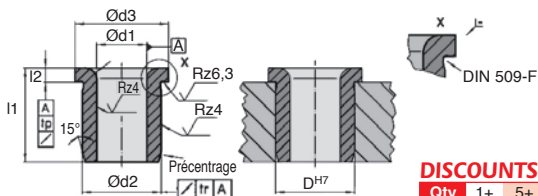

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	Ød1	l1	Ød2 (n6)	Ød3	l2	Weight (g)	Price each 1 to 4	Part number	Ød1	l1	Ød2 (n6)	Ød3	l2	Weight (g)	Price each 1 to 4
CDPC8.5-15-20	8,5	20	15	18	3	20	6,85 €	CDPC13-22-36	13	36	22	26	4	73	16,15 €
CDPC8.5-15-25	8,5	25	15	18	3	25	10,73 €	CDPC14-22-16	14	16	22	26	4	32	7,84 €
CDPC9-15-12	9	12	15	18	3	12	6,32 €	CDPC14-22-28	14	28	22	26	4	53	11,05 €
CDPC9-15-20	9	20	15	18	3	19	6,85 €	CDPC14-22-36	14	36	22	26	4	67	16,15 €
CDPC9-15-25	9	25	15	18	3	23	10,73 €	CDPC15-22-16	15	16	22	26	4	29	7,84 €
CDPC9.1-15-12	9,1	12	15	18	3	12	6,32 €	CDPC15-22-28	15	28	22	26	4	48	11,05 €
CDPC9.1-15-20	9,1	20	15	18	3	19	6,85 €	CDPC15-22-36	15	36	22	26	4	61	16,15 €
CDPC9.1-15-25	9,1	25	15	18	3	23	10,73 €	CDPC16-26-16	16	16	26	30	4	45	9,90 €
CDPC9.5-15-12	9,5	12	15	18	3	11	6,32 €	CDPC16-26-28	16	28	26	30	4	76	12,95 €
CDPC9.5-15-20	9,5	20	15	18	3	18	6,85 €	CDPC16-26-36	16	36	26	30	4	97	17,72 €
CDPC9.5-15-25	9,5	25	15	18	3	22	10,73 €	CDPC16.1-26-16	16,1	16	26	30	4	45	14,13 €
CDPC10-15-12	10	12	15	18	3	11	6,32 €	CDPC16.1-26-28	16,1	28	26	30	4	76	17,51 €
CDPC10-15-20	10	20	15	18	3	17	6,85 €	CDPC16.1-26-36	16,1	36	26	30	4	96	22,93 €
CDPC10-15-25	10	25	15	18	3	20	10,73 €	CDPC16.5-26-16	16,5	16	26	30	4	44	9,90 €
CDPC10.1-18-12	10,1	12	18	22	4	20	6,85 €	CDPC16.5-26-28	16,5	28	26	30	4	73	12,95 €
CDPC10.1-18-20	10,1	20	18	22	4	30	7,46 €	CDPC16.5-26-36	16,5	36	26	30	4	93	17,57 €
CDPC10.1-18-25	10,1	25	18	22	4	37	11,46 €	CDPC17-26-16	17	16	26	30	4	42	9,90 €
CDPC10.5-18-12	10,5	12	18	22	4	19	6,85 €	CDPC17-26-28	17	28	26	30	4	70	12,95 €
CDPC10.5-18-20	10,5	20	18	22	4	29	7,46 €	CDPC17-26-36	17	36	26	30	4	90	17,57 €
CDPC10.5-18-25	10,5	25	18	22	4	36	11,46 €	CDPC18-26-16	18	16	26	30	4	39	9,90 €
CDPC11-18-12	11	12	18	22	4	18	6,85 €	CDPC18-26-28	18	28	26	30	4	64	12,95 €
CDPC11-18-20	11	20	18	22	4	28	7,46 €	CDPC18-26-36	18	36	26	30	4	82	17,57 €
CDPC11-18-25	11	25	18	22	4	34	11,46 €	CDPC19-30-20	19	20	30	34	5	71	12,95 €
CDPC11.1-18-12	11,1	12	18	22	4	18	6,85 €	CDPC19-30-36	19	36	30	34	5	125	17,20 €
CDPC11.1-18-20	11,1	20	18	22	4	28	7,46 €	CDPC19-30-45	19	45	30	34	5	154	25,79 €
CDPC11.1-18-25	11,1	25	18	22	4	34	11,46 €	CDPC20-30-20	20	20	30	34	5	67	12,95 €
CDPC10.5-18-12	11,5	12	18	22	4	17	6,85 €	CDPC20-30-36	20	36	30	34	5	0	17,20 €
CDPC11.5-18-20	11,5	20	18	22	4	26	7,46 €	CDPC20-30-45	20	45	30	34	5	143	25,79 €
CDPC11.5-18-25	11,5	25	18	22	4	33	11,46 €	CDPC20.1-30-20	20,1	20	30	34	5	66	17,20 €
CDPC12-18-12	12	12	18	22	4	16	6,85 €	CDPC20.1-30-36	20,1	36	30	34	5	115	22,52 €
CDPC12-18-20	12	20	18	22	4	25	7,46 €	CDPC20.1-30-45	20,1	45	30	34	5	142	32,96 €
CDPC12-18-25	12	25	18	22	4	31	11,46 €	CDPC22-30-20	22	20	30	34	5	56	12,95 €
CDPC12.1-22-16	12,1	16	22	26	4	37	7,84 €	CDPC22-30-36	22	36	30	34	5	97	17,20 €
CDPC12.1-22-28	12,1	28	22	26	4	62	11,05 €	CDPC22-30-45	22	45	30	34	5	120	25,79 €
CDPC12.1-22-36	12,1	36	22	26	4	78	16,15 €	CDPC25-35-20	25	20	35	39	5	80	16,62 €
CDPC12.5-22-16	12,5	16	22	26	4	36	7,84 €	CDPC25-35-36	25	36	35	39	5	138	20,44 €
CDPC12.5-22-28	12,5	28	22	26	4	60	11,05 €	CDPC25-35-45	25	45	35	39	5	171	30,46 €
CDPC12.5-22-36	12,5	36	22	26	4	76	16,15 €	CDPC30-42-25	30	25	42	46	5	139	24,81 €
CDPC13-22-16	13	16	22	26	4	34	7,84 €	CDPC30-42-45	30	45	42	46	5	245	29,39 €
CDPC13-22-28	13	28	22	26	4	58	11,05 €	CDPC30-42-56	30	56	42	46	5	304	44,81 €

Dimensions in mm

Fax 0 825 88 6000
Service 0,15 €/min + prix appel

Our other products



HW_HT
Half-rail guide, Rail



V3RA_PT
3-spoked handwheel
with handle,
Polyamide



PRF_GAL
Roller for aluminium
profile, Flat roller



SLBS
Stainless steel
indexing plunger,
Stainless steel



STRIPF
Sealing brush strip,
1m length



 
PRF_PL_9090
Joining plate for
aluminium profile,
Joint plate - 90x90
mm



NSO
Housing for open
linear bearing,
Opened - long



HSS
Shoulder screw
ISO7379, Hardened
Steel class 12.9



SHWbr
Washer - DIN125,
Brass



RT61
Self-centering locking
Assembly,



PSG25S
Spur gear - precision
range, Stainless steel



PITA
Locking bolt, with T
handle

Complementary products



CDP
Flanged drill bushing,
Steel



PRES2HR
Manual workbench
press, Force up to
200kg



PRES3HR
Manual workbench
press, Force up to
400kg



PRES4HR
Manual workbench
press, Force up to
600kg