
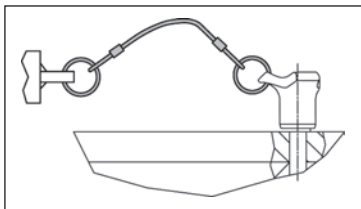


- **With fastening loops**
- **Materials:**
Cable: stainless steel with transparent PVC covering
Rings: stainless steel
- **Maximum operating temperature:**
80°C

Info.

- This cable attaches to the **BAB** clamping pin (except BAB/S)
- Its role is to prevent it from getting lost
- This cable is used to retain BAB clamping pins in the area where they are to be used. It is secured in place with an M6 screw.

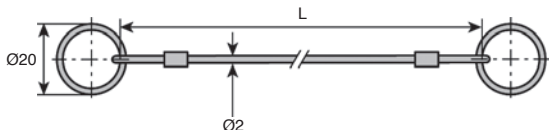

Typical application

DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	L (mm)	Weight (g)	Stock*	Price each 1 to 5
CDR-150	150	5	✓	12,19 €
CDR-200	200	5	✓	13,30 €
CDR-300	300	6	✓	13,68 €

*Depending on availability - Dimensions in mm

Our other products



RPCtcss
Swivel castor with central hole, Stainless steel - Polyamide



RPCtc
Swivel castor with central hole, Steel - Polyamide



PDM_PDV
Detectable plastic palm grip, blue thermoplastic



CFUURSS
Cam follower stainless steel, Standard - stainless steel



PRF-SCL
Lock for aluminium profile, Lock for sliding doors



RHTplss
High Temperature Castor, up to 200kg



SLB
Indexing plunger, steel class 5.8



RAS
90° ball and socket joints DIN71802, Stainless steel



GEC
Rubber latch clamp with strike plate,



SLBS
Stainless steel indexing plunger,



MDB_MTB
Moulded plastic bevel gear (nylon), 3:1

 


SHA_PT
Handwheel with handle, Polyamide

Complementary products



BAB
Hardened Stainless steel ball pin, Stainless steel hardened



CDRs
Retaining cable for ball pin, Retaining cable



BABV
Ball lock pins lockable, Stainless steel



BABTV
Ball lock pins lockable, Stainless steel