

Retaining cable

Sta

CDR

For clamping pin

- With fastening loops

- Materials:



Cable: stainless steel with transparent PVC covering

Rings: stainless steel

- Maximum operating temperature: 80°C

Info.

- This cable attaches to the **BAB** clamping pin (except BAB/S)
- Its role is to prevent it from getting lost
- This cable is used to retain BAB clamping pins in the area where they are to be used. It is secured in place with an M6 screw.

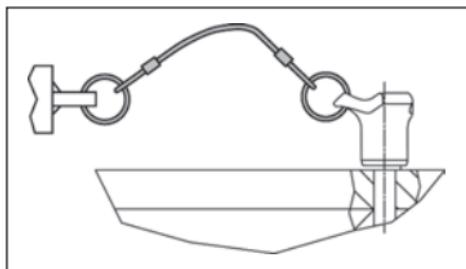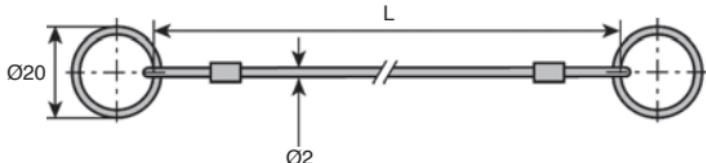

Typical application


DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	L (mm)	Weight (g)	Stock*	Price each 1 to 5
CDR-150	150	5	✓	12,19 €
CDR-200	200	5	✓	13,30 €
CDR-300	300	6	✓	13,68 €

*Depending on availability - Dimensions in mm

Our other products

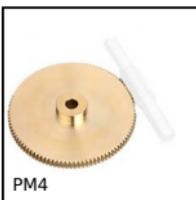


PM4
Worm and wheel set,
Bronze



HK
Manual locking clamp,
Manual locking clamp
T



EFTC
Fixing support,
Stainless steel

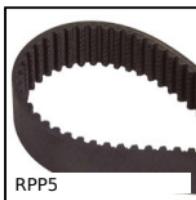

RPP5
RPP heavy duty
timing belt, RPP5



GARBAB
Lock pin for clamping,
Ball lock pin



MHQMEP
Arm with rotating
handle, Square bore



AT10-BAR
AT type tooth bar
stock, AT10



COA-COG
Surface mounting
plate, Surface
mounting plate for
ball joint



MCLred
Reducing sleeve
female/female,
Cylindrical - stainless



LOQ
Manual lock, Manual
latch



COA-COG
Surface mounting
plate, Surface
mounting plate for
ball joint




RESC
Retractable castor for
aluminium profile,
Retractable castor

Complementary products



BAB
Hardened Stainless
steel ball pin,
Stainless steel
hardened

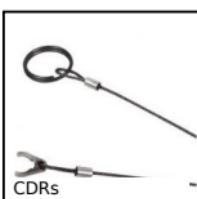

CDRS
Retaining cable for
ball pin, Retaining
cable



BABV
Ball lock pins lockable
, Stainless steel



BABTV
Ball lock pins lockable
, Stainless steel