



- **With fastening loops**
- **Materials:**
Cable: stainless steel with transparent PVC covering
Rings: stainless steel
- **Maximum operating temperature:**
80°C

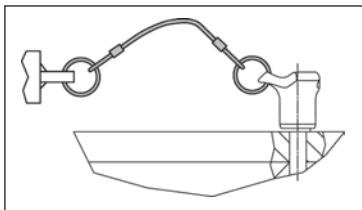

Info.

- This cable attaches to the **BAB** clamping pin (except BAB/S)
- Its role is to prevent it from getting lost
- This cable is used to retain BAB clamping pins in the area where they are to be used. It is secured in place with an M6 screw.

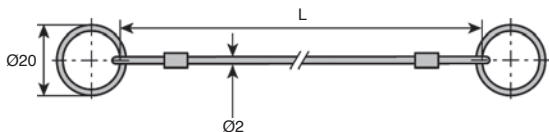

Typical application


DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	L (mm)	Weight (g)	Stock*	Price each 1 to 5
CDR-150	150	5	✓	12,19 €
CDR-200	200	5	✓	13,30 €
CDR-300	300	6	✓	13,68 €

*Depending on availability - Dimensions in mm

 Our other products



RPPM
RPP type belt per metre, RPP14 Steel cored polyurethane



PO
Pull handle - Multi-sector, Tapped recessed insert



V3RA_PT
3-spoked handwheel with handle, Polyamide



PAT85
Pressed stainless steel articulating foot Ø85, Ø 85



CHTRP
Single and dual output gearboxes, Up to 75,7 Nm



GAL22
Conveyor wheel, Zinc plated steel



RFK28C
Hypoid gearbox - Stainless steel, up to 130 Nm



PAS
Pull handle, Reinforced PA thermoplastic



CHAEpac
Square decorative screwed hinges, carbon fibre



RT61ss
Self-centering locking Assembly, Medium/low torque



BOX-NINA
Self locking nut - DIN985, Box set of steel nuts

 


AT5M AT10M
AT type timing belt per metre, AT10 Steel cored polyurethane

Complementary products



BAB
Hardened Stainless steel ball pin, Stainless steel hardened



CDRs
Retaining cable for ball pin, Retaining cable



BABV
Ball lock pins lockable, Stainless steel



BABTV
Ball lock pins lockable, Stainless steel