



- With fastening loops
- Materials:
Cable: stainless steel with transparent PVC covering
- Rings: stainless steel
- Maximum operating temperature: 80°C

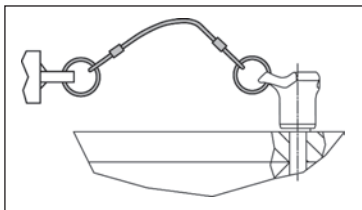

Info.

- This cable attaches to the **BAB** clamping pin (except BAB/S)
- Its role is to prevent it from getting lost
- This cable is used to retain BAB clamping pins in the area where they are to be used. It is secured in place with an M6 screw.

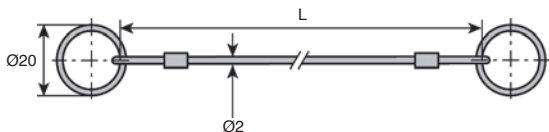

Typical application

DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	L (mm)	Weight (g)	Stock*	Price each 1 to 5
CDR-150	150	5	✓	12,19 €
CDR-200	200	5	✓	13,30 €
CDR-300	300	6	✓	13,68 €

*Depending on availability - Dimensions in mm

Our other products



NSB

Standard linear bearing housing, Closed - Long



PM2

Worm and wheel set, Bronze



LWH

High rigidity linear slide, Rail - from 9320 N to 71300 N



GCH

Linear ball slide - Stainless steel balls, Chariot - from 514 N to 1...



PSG15

Spur gear - precision range, Pre-hardened Steel 35NCD6



 
PRF_BASE

Base plate for aluminium profile, Base plate



CHB

Single output shaft, For CHB gearbox



PTA50

Articulated levelling foot, pressed base Ø50, Ø 50



MCLred

Reducing sleeve female/female, Cylindrical - steel



PMB

Anti-vibration machine mount, Oval base plate



UTKswrr

V shaped channel UtiliTrak®, V rail



BSM_LOK


Long-Lok spring plunger with internal hexagonal socket, LONG-LOK - s...

Complementary products



BAB

Hardened Stainless steel ball pin, Stainless steel hardened

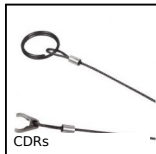

CDRs

Retaining cable for ball pin, Retaining cable



BABV

Ball lock pins lockable, Stainless steel



BABTV

Ball lock pins lockable, Stainless steel