
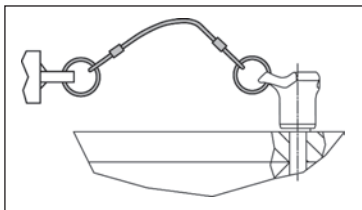


- **With fastening loops**
- **Materials:**  
Cable: stainless steel with transparent PVC covering  
Rings: stainless steel
- **Maximum operating temperature:**  
80°C

### Info.

- This cable attaches to the **BAB** clamping pin (except BAB/S)
- Its role is to prevent it from getting lost
- This cable is used to retain BAB clamping pins in the area where they are to be used. It is secured in place with an M6 screw.

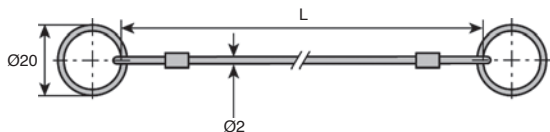

Typical application

### DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	L (mm)	Weight (g)	Stock*	Price each 1 to 5
CDR-150	150	5	✓	12,19 €
CDR-200	200	5	✓	13,30 €
CDR-300	300	6	✓	13,68 €

\*Depending on availability - Dimensions in mm

## Our other products



PFM

Fixed levelling foot,  
Flanged plate



UCP\_SS

Stainless steel pillow  
block bearing,  
Stainless steel



F7-E

Multifunction display,  
With external sensor



M1

Worm and wheel set,  
Bronze



CLG1

Moulded plastic spur  
gear, Moulded plastic  
(nylon)



SH2

Parallel axis helical  
gear, Machined plastic  
(delrin)



VTLF

3 lobed handle,  
Polyamide - Brass



HCA

Magnetic screw with  
socket, Steel



UTKswc

Utilittrak® 3 wheels  
carriage, Series V  
precision steel wheel



DILC

Indexing plunger with  
cam, with cam



BTC\_M

End cap with threaded  
insert for square tube,  
With threaded insert



HLA24

 
Right angle spiro  
bevel gearbox, Up to  
78Nm

## Complementary products



BAB

Hardened Stainless  
steel ball pin,  
Stainless steel  
hardened



CDRs

Retaining cable for  
ball pin, Retaining  
cable



BABV

Ball lock pins lockable  
, Stainless steel



BABTV

Ball lock pins lockable  
, Stainless steel