
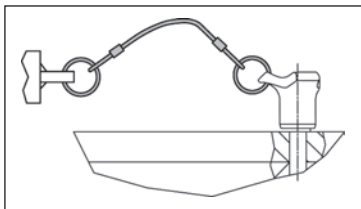


- **With fastening loops**
- **Materials:**
Cable: stainless steel with transparent PVC covering
Rings: stainless steel
- **Maximum operating temperature:**
80°C

Info.

- This cable attaches to the **BAB** clamping pin (except BAB/S)
- Its role is to prevent it from getting lost
- This cable is used to retain BAB clamping pins in the area where they are to be used. It is secured in place with an M6 screw.

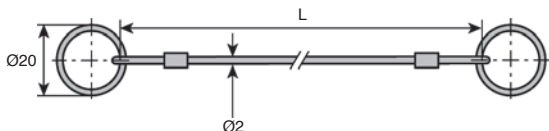

Typical application


DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	L (mm)	Weight (g)	Stock*	Price each 1 to 5
CDR-150	150	5	✓	12,19 €
CDR-200	200	5	✓	13,30 €
CDR-300	300	6	✓	13,68 €

*Depending on availability - Dimensions in mm

 Our other products



Rotary table iglidur®,
Iglidur®, aluminium
and stainless steel



Right angled gearbox,
from 1.10 to 6 Nm



Parallel axis helical
gear - Precision range,
20NCD2 case
hardened s...



Piano hinge, Steel



Retractable castor for
aluminium profile,
Retractable castor



Steel Clamping collar,
Steel



Worm and wheel gear
reducer, up to 57 Nm



Support for Ø12mm
Prox detector, Ø12



Moulded plastic bevel
gear (nylon), 3:1



Adjustable cross
clamp, Adjustable



Knob for gripping,
Mushroom

 


Spring loaded toggle
latch, Standard
(GP75)

Complementary products



Hardened Stainless
steel ball pin,
Stainless steel
hardened



Retaining cable for
ball pin, Retaining
cable



Ball lock pins lockable
, Stainless steel



Ball lock pins lockable
, Stainless steel