
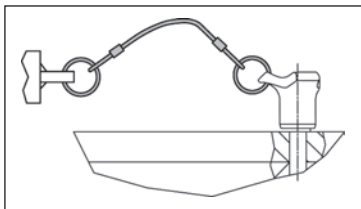


- **With fastening loops**
- **Materials:**
Cable: stainless steel with transparent PVC covering
Rings: stainless steel
- **Maximum operating temperature:**
80°C

Info.

- This cable attaches to the **BAB** clamping pin (except BAB/S)
- Its role is to prevent it from getting lost
- This cable is used to retain BAB clamping pins in the area where they are to be used. It is secured in place with an M6 screw.

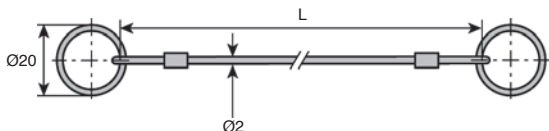

Typical application


DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	L (mm)	Weight (g)	Stock*	Price each 1 to 5
CDR-150	150	5	✓	12,19 €
CDR-200	200	5	✓	13,30 €
CDR-300	300	6	✓	13,68 €

*Depending on availability - Dimensions in mm

Our other products

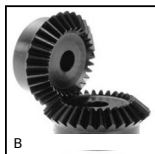

B
Steel bevel gear, 1:1



LWL
Linear ball slide -
Stainless steel balls,
Rail - from 514 N to
1670...



NCT
Square tube
connector, Fixed
angle



RJUM01
Closed polymer
Drylin® R bearing,
Drylin® R



PSG1HC
Skive hobbed spur
gears - precision
range, Case hardened
steel 20NCD2



Q1
Self-aligning radial
ball bearing, Steel



RJA00_02
Sealing strip, Clipping



LRR22
Small dimension latch
with locking system,
Aluminium



CM
Tools Hygienic Usit®
and Hygienic



HRV
V- rail guidance
Simple Select®



PSG15S
Spur gear - precision
range, Stainless steel




SH1
Parallel axis helical
gear, Steel 20NCD2

Complementary products



 BAB
Hardened Stainless
steel ball pin,
Stainless steel
hardened



CDRs
Retaining cable for
ball pin, Retaining
cable



BABV
Ball lock pins lockable
, Stainless steel



BABTV
Ball lock pins lockable
, Stainless steel