


- Axle mounted eccentric cam follower
- Synthetic rubber joints fitted to external ring
- Assemble using a screwdriver
- Diameter of housing 6 to 18mm, tolerance H7
- Material: carbon steel

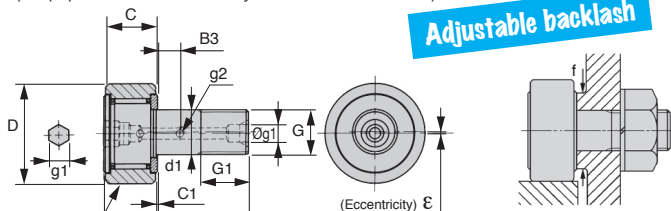

Info.

- All the followers come with grease nipples: at the end of the axle on the roller side, on the threaded side, and on the cylindrical section,
(Except for cam < 10 mm with only one hole on the roller side).



DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	Min. flange Ø f (mm)		Torque (Nm)	C (N)	Max. admissible load (N)	Max. speed (rpm)	Øg1 (mm)	g2 (mm)	r (mm)	Eccentricity ε (mm)
	Basic static load C (N)	Basic dynamic load								
CFES6UUR	11	12.7	3660	3650	1980	-	-	0.3	0.25	
CFES8UUR	13	6.5	4250	4740	4670	-	-	0.3	0.25	
CFES10UUR	16	13.8	5430	6890	6890	-	-	0.3	0.30	
CFES10-1UUR	16	13.8	5430	6890	6890	-	-	0.3	0.30	
CFES12UUR	21	21.9	7910	9790	9790	4	3	0.6	0.40	
CFES12-1UUR	21	21.9	7910	9790	9790	4	3	0.6	0.40	
CFES16UUR	26	58.5	12000	18300	18300	4	3	0.6	0.50	
CFES18UU	29	86.2	14800	25200	25200	6	3	1.0	0.60	

Part number	d1 (h7)	D (h5)	C ^{+0, -0.12}	G	G1	B	B1	B2	B3	C1	Stock*	Price each 1 to 5
CFES8UUR	8	19	11	M8 x 1,25	10	12,2	32,2	20,0	-	0,6	✓	37,82 €
CFES10UUR	10	22	12	M10 x 1,25	12	13,2	36,2	23,0	-	0,6	✓	41,76 €
CFES10-1UUR	10	26	12	M10 x 1,25	12	13,2	36,2	23,0	-	0,6	✓	44,12 €
CFES12UUR	12	30	14	M12 x 1,50	13	15,2	40,2	25,0	6	0,6	-	47,12 €
CFES12-1UUR	12	32	14	M12 x 1,50	13	15,2	40,2	25,0	6	0,6	-	41,70 €
CFES16UUR	16	35	18	M16 x 1,50	17	19,6	52,1	32,5	8	0,8	-	56,70 €
CFES18UU	18	40	20	M18 x 1,50	19	21,6	58,1	36,5	8	0,8	✓	67,32 €

*Depending on availability - Dimensions in mm

Our other products



PTA80

Articulated levelling foot, pressed base Ø80, Ø 80



PRF-SRA

Lock for aluminium profile, Lock



CDP

Flanged drill bushing, Steel



SHN

Hexagonal nut DIN934, Steel (Class 6[8])



PRF-SMA

Closing system for aluminium profile, Easily adjustable lock



ZDB

Machined plastic bevel gear, 2:1



GAL21

Conveyor wheel, Plastic



SH1

Parallel axis helical gear, Steel 20NCD2



RJA00_02

Sealing strip, Clipping



ERC

Quick fitting cable terminal, Fork



AXTR

Axle for tensioner pulley, Shaft



CHB

Worm and wheel gear reducer, up to 41 Nm

Complementary products



CFUURSS

Cam follower stainless steel, Standard - stainless steel