



Steel/self-lubricating bronze contact

CFFRH CFFLH

- Female threaded rod end conforming to
DIN ISO 12240-4 K series

- Materials:

Sphere: Steel 100CG ground and polished

Insert: Bronze

Housing:

sizes 5 to 12- low carbonised steel

sizes 16 to 35 – high carbon steel alloy,

surface is galvanised and passivated


- Working temperature: -30°C to +120°C
(150°C occasionally)

Advantages

- Self-lubricating
- Maintenance free
- Bearing surface wear-resistant
- Low friction

Application

- Oscillating movements

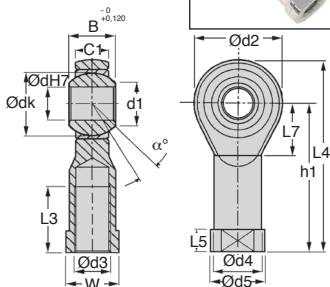

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-15%	-20%	-30%	On request

Part number	Ød	Ød3	B	C1	Ød1	Ød2	Ød4	Ød5	Ødk	h1	L3	L4	L5	L7	W
CFF.00.05	5	M5x0,8	8	6,00	7,70	18	9,00	11	11,112	27	10	36	4,00	10	9
CFF.00.06	6	M6x1	9	6,75	8,90	20	10,00	13	12,700	30	12	40	5,00	11	11
CFF.00.08	8	M8x1,25	12	9,00	10,40	24	12,50	16	15,875	36	16	48	5,00	13	14
CFF.00.10	10	M10x1,5	14	10,50	12,90	28	15,00	19	19,050	43	20	57	6,50	15	17
CFF.00.12	12	M12x1,75	16	12,00	15,40	32	17,50	22	22,225	50	22	66	6,50	17	19
CFF.00.16	16	M16x2	21	15,00	19,30	42	22,00	27	28,575	64	28	85	8,00	23	22
CFF.00.20	20	M20x2,5	25	18,00	24,30	50	27,50	34	34,925	77	33	102	10,00	27	30
CFF.00.30	30	M30x2	37	25,00	34,80	70	40,00	50	50,800	110	51	145	15,00	36	41
CFF.00.35	35	M36x2	43	28,00	37,70	80	46,00	58	57,150	125	56	165	17,00	41	50

Part number	Radial static load F _s (daN)	Axial holding load of the ball (daN)	Movement angle α°	Weight (g)	Stock*		Price each 1 to 5		
					RH	LH	RH	LH	
CFF.00.05/RH	CFF.00.05/LH	600	100	13	19	✓	✓	13,87 €	16,04 €
CFF.00.06/RH	CFF.00.06/LH	700	120	13	26	✓	✓	11,89 €	13,77 €
CFF.00.08/RH	CFF.00.08/LH	1 200	170	14	46	✓	✓	12,49 €	14,45 €
CFF.00.10/RH	CFF.00.10/LH	1 400	200	13	76	✓	✓	14,11 €	16,33 €
CFF.00.12/RH	CFF.00.12/LH	1 900	270	13	110	✓	✓	17,13 €	19,80 €
CFF.00.16/RH	CFF.00.16/LH	4 800	550	15	220	✓	✓	34,40 €	39,72 €
CFF.00.20/RH	CFF.00.20/LH	5 200	600	14	409	✓	-	62,22 €	71,79 €
CFF.00.30/RH	CFF.00.30/LH	10 800	1 200	17	1 140	✓	-	146,95 €	169,57 €
CFF.00.35/RH	CFF.00.35/LH	12 400	1 400	19	1 600	-	-	180,24 €	207,99 €

*Depending on availability - Dimensions in mm

Our other products



DOMI80

Domino 80 adjustable slide, Slide DOMILINE 80



CDGamme

Compression spring
DIN2095, DIN 2095



PTA50ssEB

Articulated foot with
sheet metal base
Ø50, Articulated foot



TCL-CR

T-Clip - Aluminium
profile attachment,
Hook



GPB

Threaded spherical
knob, With brass
insert



F7-SF-SM

Multifunction display,
Mounting bracket for
front mounting



SH2

Parallel axis helical
gear, Machined plastic
(delrin)




CMM

Male rod ends DIN
ISO12240-4, Steel /
bronze



MAX22

 Motor-gearbox 12V
and 24V DC, from



PRT

Rotary table iglidur®,
aluminium



VPRA_M

Handwheel with
handle,



DFG

Flat suction cup,
silicon

Complementary products



CFF_SS

Female rod ends DIN
ISO12240-4, Stainless
steel / bronze -
Economy r...



SFE

Female rod ends,
Stainless steel / PTFE