

Heavy duty plastic hinge, opens 180°

 

CHA

Polyamide

- **Screwed hinge**
- Maximum opening: 180°
- Materials:
 - Black polyamide
 - Nickel plated steel pin

Applications

- Industrial bodywork

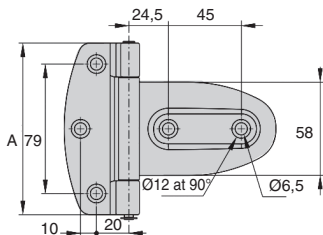

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	Weight (g)	Stock*	Price each 1 to 5
CHA108-131	108	131	9,5	6	98	✓	27,45 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



HBM

Adjustment bushing for half-rail guide, Adjustment bushing



DOMI80

Domino 80 adjustable slide, Slide DOMILINE 80



PO

Pull handle - Multi-sector, Tapped recessed insert



T5_11

T type timing pulley, T5 aluminium



PRF_P

Anchor foot for 45x45 profile, Anchor foot



COA-COG

Surface mounting plate, Surface mounting plate for clevis



BPP

Pressed steel flanged bearing for light loads, Sheet steel



MBEX

Hexagonal ended handle, Hexagonal ended handle



MSP38

Masterplate® glueable insert Ø38, Masterplate® glueable insert Ø38



SLS

Bearing block for leadscrew, Floating



BCM_CC

Modular cylindrical brush, Horsehair



PSP

Support profile, Panel support

Complementary products