

Screwed marine hinge



Stock

Sta

Eco



CHAM

Sheet metal with rolled knuckle

- Hinge for plug door
- Riveted pin
- Material:
stainless steel 304
- Polished finish

Advantages

- High corrosion resistance
- Economic hinge

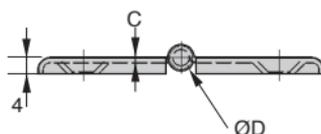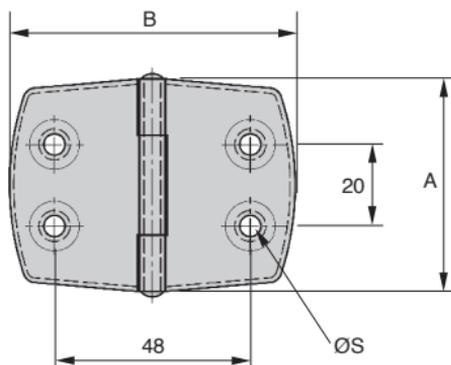

DISCOUNTS

| | | | | |
|------------|-----|------|------------|-----|
| Qty | 1+ | 6+ | 20+ | 50+ |
| Disc. List | -5% | -10% | On request | |

| Part number | A | B | C | ØD | ØS | Weight (g) | Stock* | Price each 1 to 5 |
|-------------|----|----|-----|----|-----|------------|--------|-------------------|
| CHAM5270/SS | 52 | 70 | 1,2 | 4 | 5,2 | 44 | ✓ | 14,84 € |

*Depending on availability - Dimensions in mm

- **Universal hinge for plug door**
- Rolled knuckle
- **Material:**
 Body: stainless steel 316
 Pin: stainless steel

Uses



- Pharmaceutical, chemical and food industries

Advantages

- Economic hinge



stainless steel

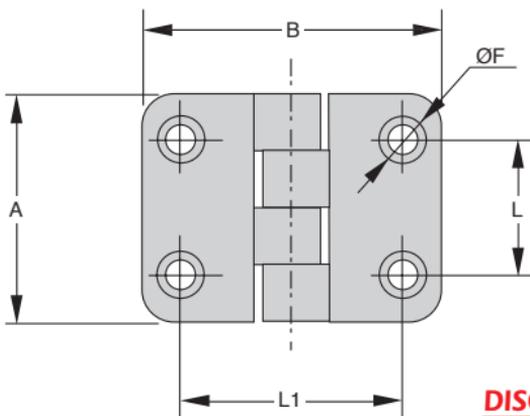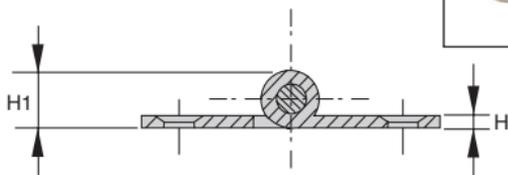

DISCOUNTS

| Qty | 1+ | 6+ | 10+ | 25+ |
|------------|-----|------|------------|-----|
| Disc. List | -5% | -10% | On request | |

| Part number | A | B | L | L1 | ØF | H | H1 | Stock* | Price each 1 to 5 |
|-------------|----|----|------|----|-----|---|-----|--------|-------------------|
| CHA38-38/SS | 38 | 38 | 20,5 | 26 | 5,5 | 2 | 9,5 | ✓ | 18,46 € |
| CHA37-48/SS | 37 | 48 | 22,0 | 36 | 5,5 | 2 | 9,5 | ✓ | 17,22 € |

*Depending on availability - Dimensions in mm


Polyamide face-mounted hinge ★★★ Stock

CHAUPA

Opening up to 270°



- Universal hinge for nested door
- 270° opening
- Fixing with M5 or M6 countersunk screws according to DIN7991
- Molded hinge
- Materials:
 - Black polyamide
 - Stainless steel pin

With countersunk holes

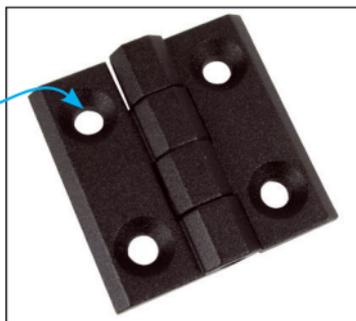

Advantages

- Beautiful finish

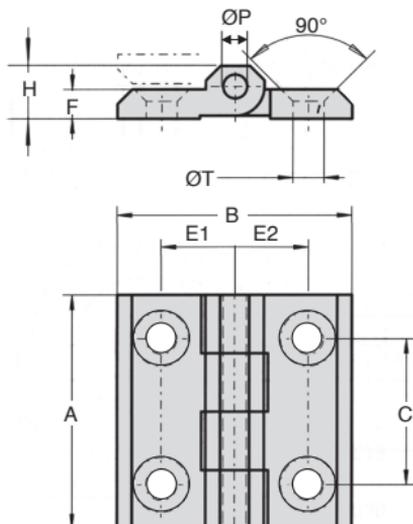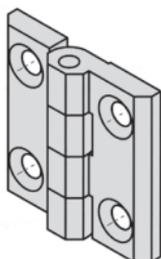

DISCOUNTS


| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 6+ | 20+ | 50+ |
| Disc. | List | -5% | -10% | On request |

| Part number | A | B | C | E1 | E2 | H | F | ØT | ØP | Stock* | Price each 1 to 5 |
|---------------------|----|----|----|------|------|------|---|-----|----|--------|----------------------|
| Square hinge | | | | | | | | | | | |
| CHA1056-U6PA | 40 | 40 | 25 | 12,5 | 12,5 | 9 | 5 | 5,3 | 4 | ✓ | 9,40 € |
| CHA1056-U10PA | 50 | 50 | 30 | 15 | 15 | 11,5 | 6 | 6,2 | 6 | ✓ | 10,94 € |

*Depending on availability - Dimensions in mm



- Universal hinge for nested door
- 270° opening
- Fixing with M5, M6 or M8 countersunk screws according to DIN7991
- Molded hinge
- Materials:
 - Die cast zinc
 - Stainless steel pin

With countersunk holes

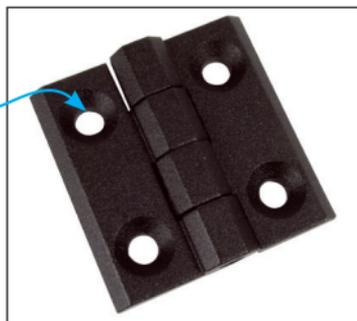

Advantages

- Beautiful finish

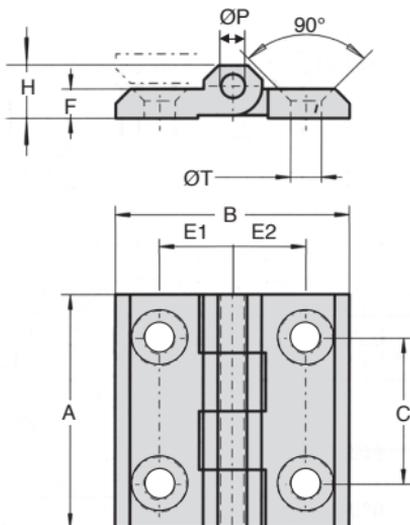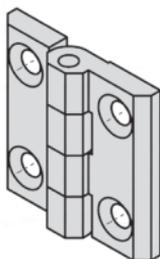

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 6+ | 20+ | 50+ |
| Disc. | List | -5% | -10% | On request |

| Part number | A | B | C | E1 | E2 | H | F | ØT | ØP | Stock* | Price each 1 to 5 |
|--------------------------|----|----|----|------|------|------|---|-----|----|--------|----------------------|
| Square hinge | | | | | | | | | | | |
| CHA1056-U6 | 40 | 40 | 25 | 12,5 | 12,5 | 9 | 5 | 5,3 | 4 | ✓ | 12,57 € |
| CHA1056-U10 | 50 | 50 | 30 | 15 | 15 | 11,5 | 6 | 6,2 | 6 | ✓ | 13,09 € |
| CHA1056-U14 | 60 | 60 | 36 | 18 | 18 | 15 | 8 | 8,3 | 8 | ✓ | 16,35 € |
| Rectangular hinge | | | | | | | | | | | |
| CHA1056-U18 | 50 | 76 | 30 | 28 | 28 | 11 | 6 | 6,2 | 6 | ✓ | 31,35 € |

*Depending on availability - Dimensions in mm



Stainless steel face-mounted hinge ★★★ Stock

CHAuss

With countersunk holes

- Universal hinge for nested door
- 270° opening
- Fixing with M5, M6, M8 countersunk screws according to DIN7991
- Raw finish
- Molded hinge
- Materials:
Stainless steel 316

stainless steel version

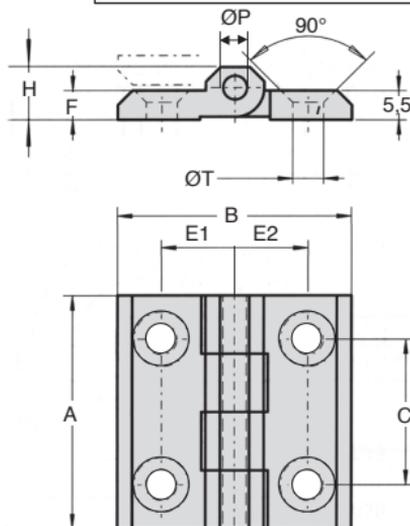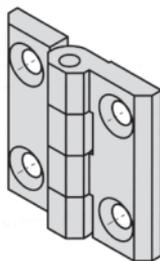

DISCOUNTS

| | | | | |
|------------|-----|------|------------|-----|
| Qty | 1+ | 6+ | 20+ | 50+ |
| Disc. List | -5% | -10% | On request | |



| Part number | A | B | C | E1 | E2 | H | F | ØT | ØP | Stock* | Price each 1 to 5 |
|---------------|----|----|----|------|------|------|---|-----|----|--------|----------------------|
| CHA1056-U6SS | 40 | 40 | 25 | 12,5 | 12,5 | 9 | 5 | 5,3 | 4 | ✓ | 30,09 € |
| CHA1056-U10SS | 50 | 50 | 30 | 15 | 15 | 11,5 | 6 | 6,2 | 6 | ✓ | 32,65 € |
| CHA1056-U14SS | 60 | 60 | 36 | 18 | 18 | 15 | 8 | 8,3 | 8 | ✓ | 32,86 € |

*Depending on availability - Dimensions in mm

- Universal hinge for nested door
- 180° opening
- Nut fixing
- Molded hinge
- Materials:
 - Die cast zinc
 - Stainless steel molded anchors
 - Stainless steel pin

Advantages

- Beautiful finish

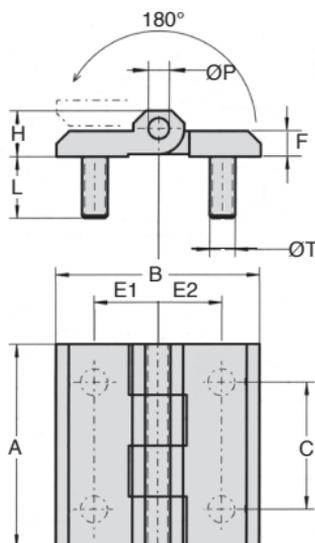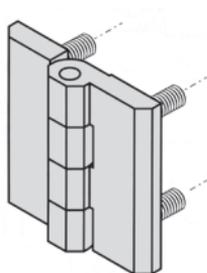

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 6+ | 20+ | 50+ |
| Disc. | List | -5% | -10% | On request |

| Part number | A | B | C | E1 | E2 | H | F | ØT | L | ØP | Stock* | Price each 1 to 5 |
|-------------------------------------|----|----|----|------|------|------|---|----|----|----|--------|----------------------|
| Square hinge | | | | | | | | | | | | |
| CHA1056-U4 | 40 | 40 | 25 | 12,5 | 12,5 | 9 | 5 | M5 | 12 | 4 | ✓ | 17,62 € |
| CHA1056-U8 | 50 | 50 | 30 | 15 | 15 | 11,5 | 6 | M6 | 15 | 6 | ✓ | 17,49 € |
| CHA1056-U12 | 60 | 60 | 36 | 18 | 18 | 15 | 8 | M8 | 14 | 8 | ✓ | 23,16 € |
| Rectangular hinge | | | | | | | | | | | | |
| CHA1056-U16 | 50 | 76 | 30 | 28 | 28 | 11 | 6 | M6 | 12 | 6 | ✓ | 31,75 € |
| Asymmetric rectangular hinge | | | | | | | | | | | | |
| CHA1056-U20 | 60 | 90 | 36 | 18 | 45 | 15 | 8 | M8 | 14 | 8 | ✓ | 32,89 € |

*Depending on availability - Dimensions in mm

Decorative screwed hinge

Alu Stock

CHAE

Aluminium



- Screwed hinge
- Materials :
 - hinges aluminium 6060T5
 - pin : plastic
- Black or colourless anodised finish

Advantage

- Aesthetic design



colourless anodised

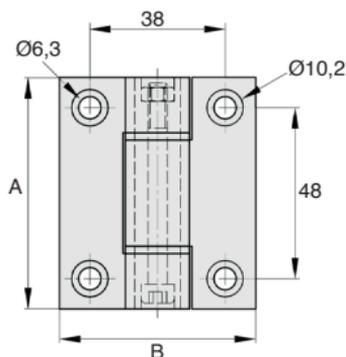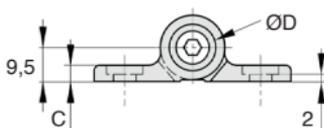

DISCOUNTS

| | | | | |
|------------|-----|------|------------|-----|
| Qty | 1+ | 6+ | 20+ | 50+ |
| Disc. List | -5% | -10% | On request | |

| Part number | A | B | C | ØD | Weight (g) | Finish | Stock* | Price each 1 to 5 |
|-------------|----|----|-----|----|------------|---------------------|--------|-------------------|
| CHAE6555/AI | 65 | 55 | 4,5 | 13 | 130 | Colourless anodised | ✓ | 18,08 € |
| CHAE6555/AN | 65 | 55 | 4,5 | 13 | 130 | Black anodised | ✓ | 18,08 € |

*Depending on availability - Dimensions in mm

Front hinge for aluminium profile

3 materials available

CHA




- Screw-on hinge

- For aluminium profile 30x30mm, 40x40mm or 45x45mm (PRF4545)
- Opening angle 180°
- Material:
 - 316 stainless steel leaves
 - Glass-fibre reinforced Black PA/Nylon
 - Cast aluminium
 - Stainless steel pin
 - PTFE bearing (Aluminium version only)
- Mount using **M6 FHC6** milled head screws



Accessory

- Mount using **M6 FHC6** milled head screws (tome 1 p.560)

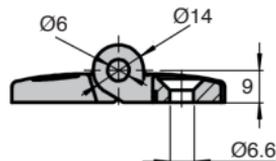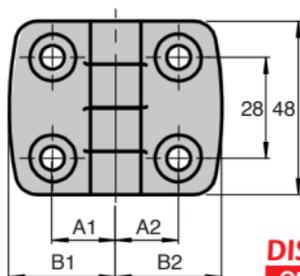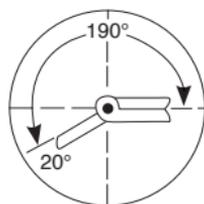

DISCOUNTS

| Qty | 1+ | 6+ | 20+ | 50+ |
|-------|-----|-----|------|------------|
| Disc. | Net | -5% | -10% | On request |

| Part number | A1 | A2 | B1 | B2 | FA max (N) | FR max (N) | Profile section | Weight (g) | Price each 1 to 5 |
|---------------------------------------|------|------|------|------|------------|------------|-----------------|------------|-------------------|
| Stainless steel hinge | | | | | | | | | |
| CHA35-48/SS | 17,5 | 17,5 | 29,5 | 29,5 | 575 | 800 | 30x30 | 167 | 39,99 € |
| CHA45-48/SS | 22,5 | 22,5 | 38,5 | 38,5 | 675 | 900 | 40x40 | 205 | 44,08 € |
| CHA50-48/SS | 25,0 | 25,0 | 42,5 | 42,5 | 675 | 900 | 45x45 | 223 | 49,34 € |
| Glass reinforced plastic hinge | | | | | | | | | |
| CHA35-48/PA | 17,5 | 17,5 | 29,5 | 29,5 | 400 | 700 | 30x30 | 36 | 4,97 € |
| CHA45-48/PA | 22,5 | 22,5 | 38,5 | 38,5 | 450 | 750 | 40x40 | 43 | 5,02 € |
| CHA50-48/PA | 25,0 | 25,0 | 43,5 | 43,5 | 450 | 750 | 45x45 | 46 | 5,14 € |
| Aluminium hinge | | | | | | | | | |
| CHA35-48/AL | 17,5 | 17,5 | 29,5 | 29,5 | 225 | 325 | 30x30 | 65 | 15,16 € |
| CHA45-48/AL | 22,5 | 22,5 | 38,5 | 38,5 | 250 | 400 | 40x40 | 69 | 16,14 € |
| CHA50-48/AL | 25,0 | 25,0 | 43,5 | 43,5 | 250 | 400 | 45x45 | 73 | 16,35 € |

All dimensions in mm

Molded polyamide face-mounted hinge ★★★ Stock



CHAUPA

With anchors

- Universal hinge for plug door
- 180° opening
- Nut fixing
- Molded hinge
- **Materials:**
 - Black polyamide
 - Stainless steel molded anchors
 - Stainless steel pin

Advantages

- Beautiful finish

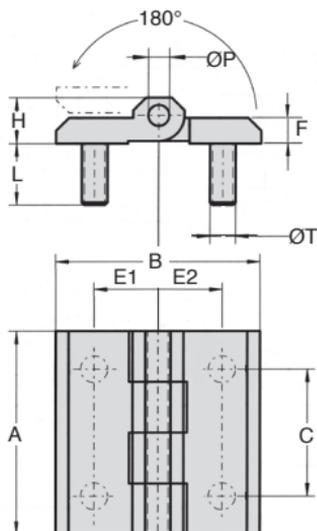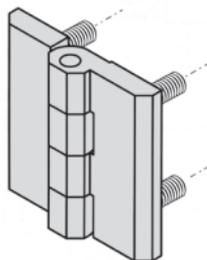

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 6+ | 20+ | 50+ |
| Disc. | List | -5% | -10% | On request |

| Part number | A | B | C | E1 | E2 | H | F | ØT | ØP | Stock* | Price each 1 to 5 |
|---------------------|----|----|----|------|------|------|---|----|----|--------|----------------------|
| Square hinge | | | | | | | | | | | |
| CHA1056-U4PA | 40 | 40 | 25 | 12,5 | 12,5 | 9 | 5 | M5 | 12 | - | 14,19 € |
| CHA1056-U8PA | 50 | 50 | 30 | 15 | 15 | 11,5 | 6 | M6 | 15 | ✓ | 15,55 € |

*Depending on availability - Dimensions in mm



Stylish stainless steel screw hinge

CHAESS

316 stainless steel



- Screw hinge
- For right and left mounting
- 180° opening angle
- Fixed using countersunk screws (M5, M6 or M8 according to DIN 7991)
- The visible surface of the hinge has polished satin finish
- Material:
100% 316 stainless steel

Advantages

- Stylish visual appearance as the pin is not visible
- Vibration proof
- Vandal proof thanks to welds over the pin at both ends.

Non-accessible pin

Impenetrable

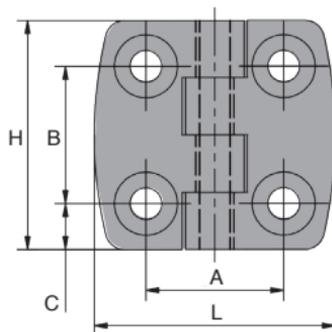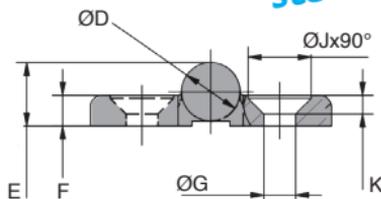

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 6+ | 20+ | 50+ |
| Disc. | List | -5% | -10% | On request |

| Part number | H | L | A | B | C | ØD | E | F | K | ØG | ØJ | Stock* | Price each 1 to 5 |
|-------------|----|----|----|----|------|------|------|---|-----|-----|------|--------|-------------------|
| CHAE4042/SS | 40 | 42 | 25 | 25 | 7,5 | 10,2 | 10,6 | 5 | 3,0 | 5,2 | 10,2 | ✓ | 32,39 € |
| CHAE5050/SS | 50 | 50 | 30 | 30 | 10,0 | 12,0 | 12,5 | 6 | 3,7 | 6,2 | 12,4 | ✓ | 38,43 € |
| CHAE6063/SS | 60 | 63 | 36 | 36 | 12,0 | 15,3 | 16,6 | 8 | 4,9 | 8,3 | 16,5 | ✓ | 47,63 € |

*Depending on availability - Dimensions in mm

CHAE

Polyamide

Screwed hinge

- Materials :

hinges glass fibre reinforced polyamide (30%)



sealed pin : stainless steel 316L

- Asymetrical and symetrical versions available

Advantages

- Aesthetic design

- Max opening angle 270°

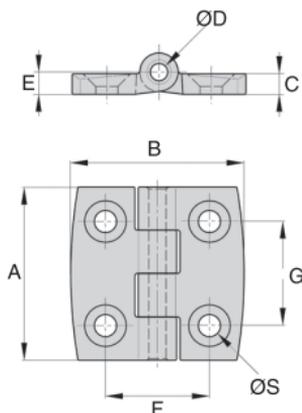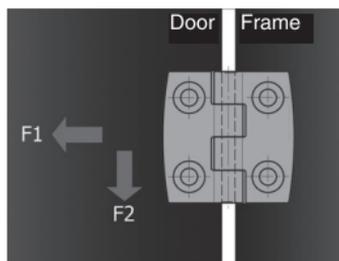

| Part number | Tensile strength F1 (N) | Shear strength F2 (N) | Screw torque (Nm) |
|-------------|----------------------------|--------------------------|----------------------|
| CHAE3030/PA | 1200 | 850 | 1 |
| CHAE4040/PA | 2200 | 1900 | 4 |
| CHAE5050/PA | 3600 | 2100 | 8 |
| CHAE6060/PA | 5100 | 3100 | 8 |

DISCOUNTS

| Qty | 1+ | 6+ | 20+ | 50+ |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number | A | B | C | ØD | E | F | G | ØS | For screw | Stock* | Price each 1 to 5 |
|-------------|----|----|-----|----|-----|----|----|-----|-----------|--------|----------------------|
| CHAE3030/PA | 30 | 30 | 3 | 3 | 3,5 | 18 | 18 | 3,2 | M3 | ✓ | 4,10 € |
| CHAE4040/PA | 40 | 40 | 5,2 | 4 | 5,7 | 25 | 25 | 5,3 | M4 | ✓ | 6,19 € |
| CHAE5050/PA | 50 | 50 | 5,9 | 5 | 6,4 | 30 | 30 | 6,4 | M6 | ✓ | 8,20 € |
| CHAE6060/PA | 60 | 60 | 6,5 | 6 | 7 | 36 | 36 | 6,4 | M6 | ✓ | 8,38 € |



*Depending on availability - Dimensions in mm

Screwed hinge

- Material :
hinges glass fibre reinforced polyamide (30%)
sealed pin : stainless steel 316L
- Corrosion resistant
- Square and asymetrical versions available

Advantages

- Aesthetic design
- Max opening angle 270°

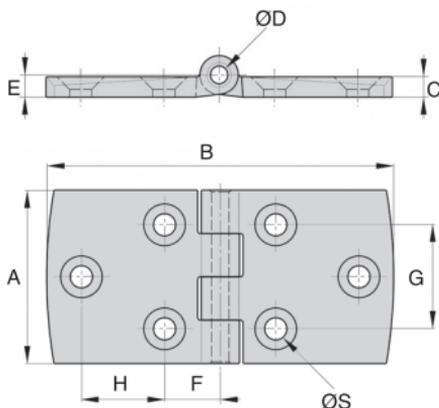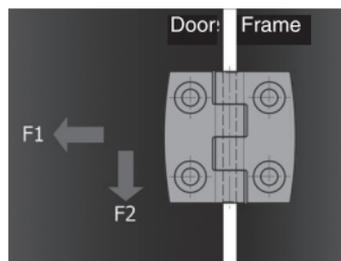

| Part number | Tensile strength F1 (N) | Shear strength F2 (N) | Screw torque (Nm) |
|--------------|----------------------------|--------------------------|----------------------|
| CHAE4080/PA | 2200 | 1900 | 4 |
| CHAE40120/PA | 2200 | 1900 | 4 |
| CHAE50100/PA | 3600 | 2100 | 8 |
| CHAE60120/PA | 5100 | 3100 | 8 |

DISCOUNTS

| Qty | 1+ | 6+ | 20+ | 50+ |
|------------|----|-----|------|------------|
| Disc. List | - | -5% | -10% | On request |

| Part number | A | B | C | ØD | E | F | G | H | ØS | For screw | Stock* | Price each |
|--------------|----|-----|-----|----|-----|------|----|----|-----|-----------|--------|------------|
| | | | | | | | | | | | | 1 to 5 |
| CHAE4080/PA | 40 | 80 | 5,2 | 4 | 5,7 | 13,5 | 25 | 19 | 5,3 | M4 | ✓ | 8,32 € |
| CHAE40120/PA | 40 | 120 | 5,2 | 4 | 5,7 | 14,5 | 25 | 38 | 5,3 | M4 | - | 10,29 € |
| CHAE50100/PA | 50 | 100 | 5,9 | 5 | 6,4 | 16 | 30 | 24 | 6,4 | M6 | ✓ | 10,58 € |
| CHAE60120/PA | 60 | 120 | 6,5 | 6 | 7 | 18 | 36 | 30 | 6,4 | M6 | ✓ | 16,86 € |

*Depending on availability - Dimensions in mm

Decorative **asymmetric** screwed hinge ★★★★ Stock Pla

CHAE_A Polyamide, Aesthetic design

- Screwed hinge

- Materials :




hinges glass fibre reinforced polyamide (30%)
sealed pin : stainless steel 316L

- Square and symmetrical versions also available

Advantage

- Aesthetic design

- Max opening angle 270°

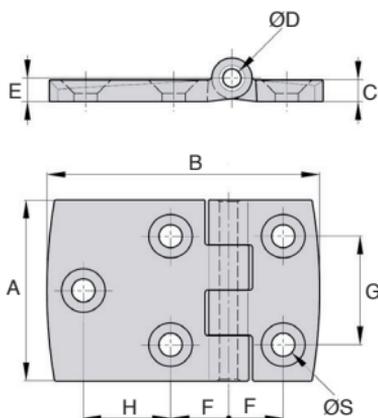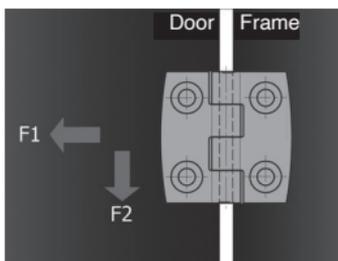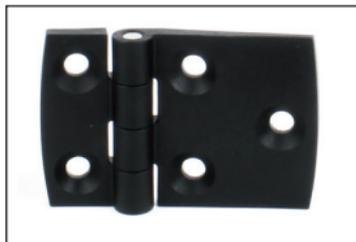

| Part number | Tensile strength | | Shear strength | | Screw torque (Nm) |
|--------------|------------------|------|----------------|------|-------------------|
| | F1 (N) | 2200 | F2 (N) | 2300 | |
| CHAE4060A/PA | 2200 | | 2300 | | 4 |
| CHAE4080A/PA | 2200 | | 2300 | | 4 |
| CHAE5075A/PA | 3600 | | 2500 | | 8 |
| CHAE6090A/PA | 5100 | | 4200 | | 8 |

DISCOUNTS

| Qty | 1+ | 6+ | 20+ | 50+ |
|------------|-----|------|------------|-----|
| Disc. List | -5% | -10% | On request | |

| Part number | A | B | C | ØD | E | F | G | H | ØS | For screw | Stock* | Price each |
|--------------|----|----|-----|----|-----|------|----|----|-----|-----------|--------|------------|
| | | | | | | | | | | | 1 to 5 | |
| CHAE4060A/PA | 40 | 60 | 5,2 | 4 | 5,7 | 13,5 | 25 | 19 | 5,3 | M4 | ✓ | 8,10 € |
| CHAE4080A/PA | 40 | 80 | 5,2 | 4 | 5,7 | 14,5 | 25 | 38 | 5,3 | M4 | ✓ | 8,31 € |
| CHAE5075A/PA | 50 | 75 | 5,9 | 5 | 6,4 | 16 | 30 | 24 | 6,4 | M6 | ✓ | 10,29 € |
| CHAE6090A/PA | 60 | 90 | 6,5 | 6 | 7 | 18 | 36 | 30 | 6,4 | M6 | ✓ | 14,42 € |

*Depending on availability - Dimensions in mm





Square decorative screwed hinges

Polyamide carbon fibre reinforced CHAE_{PAC}

- Square screwed hinge
- Max opening angle 270°
- To be fastened with M8 countersunk screws to DIN7991
- Materials
 - Polyamide 6.6 reinforced 30% carbon fibre
 - Pin 303 stainless steel
- Cycling test: hinge is functional after 10.000 cycles (open/close) for a 80 kg door (dimension 1500 (H) x 750 (W) mm)

Advantages

- Aesthetic design
- Stronger and lighter than an equivalent glass fibre polyamide hinge
- Good corrosion resistance (alternative to stainless steel hinges)

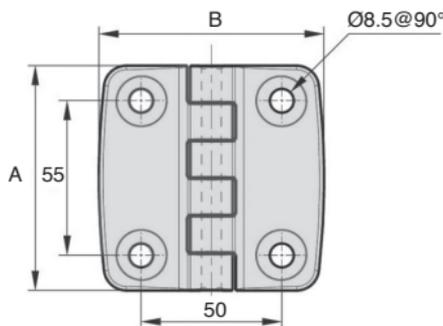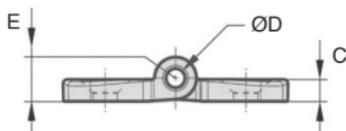

DISCOUNTS

| Qty | 1+ | 6+ | 20+ | 50+ |
|------------|-----|------|------------|-----|
| Disc. List | -5% | -10% | On request | |

| Part number | A | B | C | ØD | E | Weight (g) | Price each 1 to 5 |
|--------------|----|----|-----|----|-----|------------|-------------------|
| CHAE8080/PAC | 80 | 80 | 7,8 | 7 | 8,3 | 68 | 10,70 € |

Dimensions in mm

Heavy duty plastic hinge, opens 180°



CHA

Polyamide

- **Screwed hinge**
- Maximum opening: 180°
- Materials:
 - Black polyamide
 - Nickel plated steel pin

Applications

- Industrial bodywork

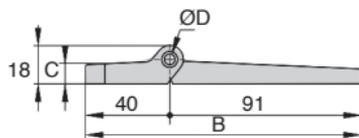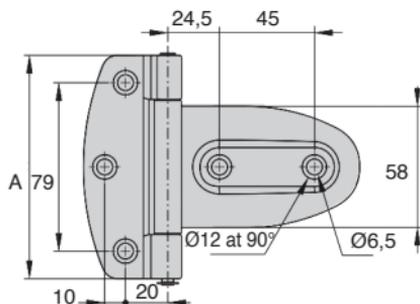

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 6+ | 20+ | 50+ |
| Disc. | List | -5% | -10% | On request |

| Part number | A | B | C | ØD | Weight (g) | Stock* | Price each 1 to 5 |
|-------------|-----|-----|-----|----|------------|--------|-------------------|
| CHA108-131 | 108 | 131 | 9,5 | 6 | 98 | ✓ | 28,26 € |

*Depending on availability - Dimensions in mm

Roll of hinge without pin

Black or white plastic hinge

CHASB

- Roll of polymer hinge without pin



- Sold in rolls of 15.25 meters
- Fastening by screws, rivets, nails or staples
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:
Polypropylene
- Tensile strength 180N/cm

Advantages

- Good resistance to oils, solvents, seawater and most chemical agents
- Good fatigue resistance
- No knots, so no retention of material or possible impurities

Use


- Ideal for horizontal use for hinging a hood

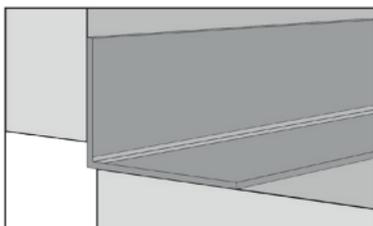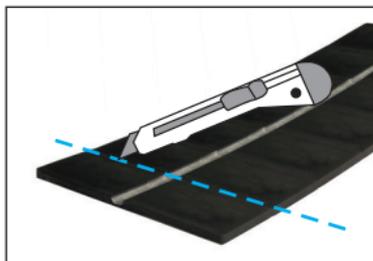

Typical application



Tensile Strength

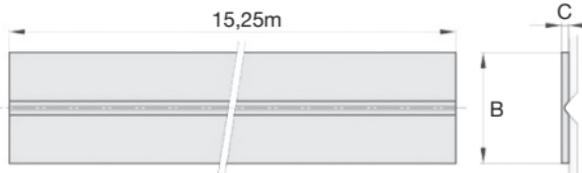

DISCOUNTS

| | | |
|-------|-------|------------|
| Qty | 1+ | 3+ |
| Disc. | Price | On request |

| Part number | B | C | Finishing | Weight roll (g) | Price per unit |
|-------------|------|-----|-----------|-----------------|--------------------|
| CHASB28-R/W | 28.6 | 3.2 | White | 1050 | 1 to 2 293,33 € |
| CHASB28-R/N | 28.6 | 3.2 | Black | 1050 | 293,33 € |
| CHASB38-R/W | 38.1 | 3.2 | White | 1450 | 321,29 € |
| CHASB38-R/N | 38.1 | 3.2 | Black | 1450 | 321,29 € |

*Depending on availability - Dimensions in mm

Hinge without pin

CHASB

Black or white plastic hinge

- **Polymer hinge without pin**
- Fastening with screws or rivets.
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:
Polypropylene
- Tensile strength 180N/cm

Advantages


- Good resistance to oils, solvents, seawater and most chemical agents
- Also, good fatigue resistance
- No knots, so no retention of material or possible impurities

Use

- Ideal for horizontal use for hinging a hood



Tensile strength

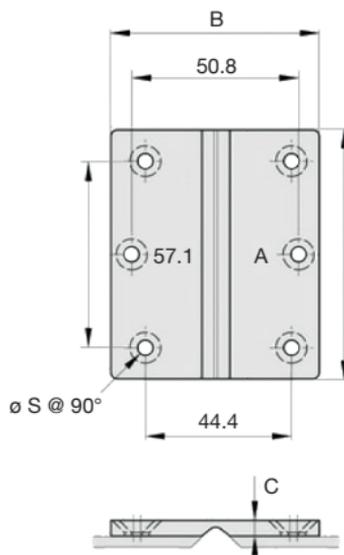

DISCOUNTS

| | | | | |
|-------------|-----|------|-----|------------|
| Qty | 1+ | 6+ | 20+ | 50+ |
| Disc. Price | -5% | -10% | | On request |

| Part number | A | B | C | ØS | Finishing | Weight (g) | Price per unit |
|--------------|------|------|------|------|-----------|------------|----------------|
| | | | | | | | 1 to 5 |
| CHASB63-76/W | 76.2 | 63.5 | 4.76 | 4.62 | White | 16 | 8,48 € |
| CHASB63-76/N | 76.2 | 63.5 | 4.76 | 4.62 | Black | 16 | 8,48 € |

*Depending on availability - Dimensions in mm

Hinge without pin

Black or white plastic hinge

CHASB

 
- Polymer hinge without pin
- Fastening with screws or rivets.
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:
Polypropylene.
- Tensile strength 180N/cm

Advantages


- Good resistance to oils, solvents, seawater and most chemical agents
- Good fatigue resistance
- No knots, so no retention de material or possible impurities

Use

- Ideal for horizontal use for hinging a hood



Tensile strength

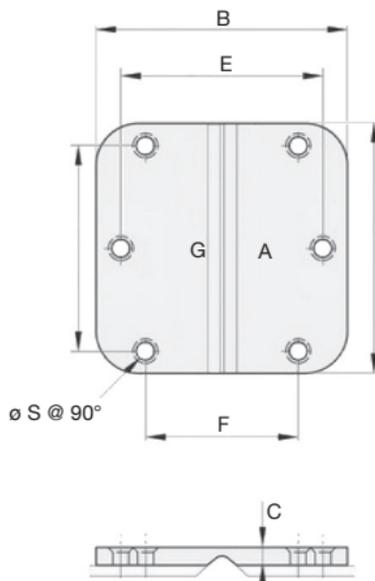

DISCOUNTS

| | | | | |
|-------|-------|-----|------|------------|
| Qty | 1+ | 6+ | 20+ | 50+ |
| Disc. | Price | -5% | -10% | On request |

| Part number | A | B | C | E | F | G | ØS | Finishing | Weight | | Price per unit |
|--------------|------|------|------|------|----|----|----|-----------|--------|--------|----------------|
| | | | | | | | | | (g) | 1 to 5 | |
| CHASB89-89/W | 88.9 | 88.9 | 6.35 | 71.4 | 54 | 73 | 6 | White | 35 | | 12,41 € |
| CHASB89-89/N | 88.9 | 88.9 | 6.35 | 71.4 | 54 | 73 | 6 | Black | 35 | | 12,41 € |

*Depending on availability - Dimensions in mm