

Heavy duty plastic hinge, opens 180°

 

CHA

Polyamide

- **Screwed hinge**
- Maximum opening: 180°
- Materials:
 - Black polyamide
 - Nickel plated steel pin

Applications

- Industrial bodywork

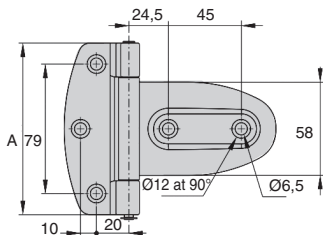

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	Weight (g)	Stock*	Price each 1 to 5
CHA108-131	108	131	9,5	6	98	✓	27,45 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

 
Our other products



RUR
Wheel, Polyurethane -
Aluminium rim (Free
running)



GAL48_OMNI
Omni-directional
roller, Omni-
directional




TPR
High helix leadscrew,
Leadscrew only - up
to 40mm per rotation



BSM_LOK
Long-Lok spring
plunger with internal
hexagonal socket,
LONG-LOK - s...



DZYSS
Stainless steel
cylindrical stop,
stainless steel

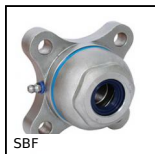

SBF
Open flange bearing
unit for food industry,
cover



LRR
Catch-plate for latch,
Catch-plate



RJUM05
Drylin R® linear
bearing housing,
Closed - Slim



PLM-20SC
Cylindrical magnet,
Cylindrical magnet



BLH50
Right angled gearbox,
from 7.70 to 20 Nm



EHD12
Internal epicyclic
servo reducers, from
60 to 140 Nm



PPCcs
Pad eye on mounting
plate squarred,
Stainless steel

Complementary products