

# Heavy duty plastic hinge, opens 180°

 

## CHA

## Polyamide

- **Screwed hinge**
- Maximum opening: 180°
- Materials:
  - Black polyamide
  - Nickel plated steel pin

### Applications

- Industrial bodywork

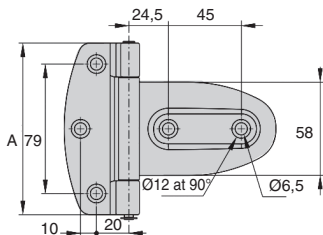

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	Weight (g)	Stock*	Price each 1 to 5
CHA108-131	108	131	9,5	6	98	✓	27,45 €

\*Depending on availability - Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products




PLM-C

Cylindrical holding magnets, Cylindrical holding magnet



PTA50

Articulated levelling foot, pressed base Ø50, Ø 50

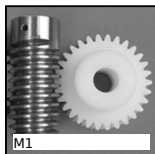

M1

Worm and wheel set, Machined plastic (delrin)



DOMI30

Accessories, Turntable



BABPass

Hardened stainless steel ball pin with ring, With grip ring



BPHT

Ball transfer unit bolt fitting, Heavy



CMM\_SS

Male rod ends DIN ISO12240-4, Stainless steel / bronze - Economy range



PRF\_BM

Base support plate for aluminium profile, Central base fixation



BRI

Panel holder, Panel holder



RJA11\_27

Sealing strip, Not clipping



ES

Bipod support base, Plastic



T5P\_T10P

Connecting plate for T type timing belts, T10

## Complementary products