

Heavy duty plastic hinge, opens 180°

 

CHA

Polyamide

- **Screwed hinge**
- Maximum opening: 180°
- Materials:
 - Black polyamide
 - Nickel plated steel pin

Applications

- Industrial bodywork

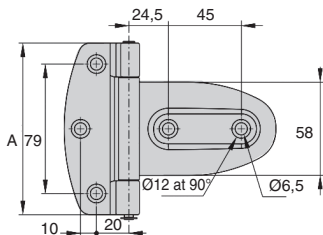

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	Weight (g)	Stock*	Price each 1 to 5
CHA108-131	108	131	9,5	6	98	✓	27,45 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



UGH50

H Type Guide units,
For Ø50 actuators



BIMSS

Indexing plunger mini,
miniature - Stainless
steel



ACAss

Stainless steel splined
shaft, Stainless steel



TCLAr

Automatic chain
tensioner, With wide
guide



GP

Spring loaded toggle
latch, With padlock-
holder



PO

Pull handle - Multi-
sector, Tapped
recessed insert




BAG0

Locking rings in
stainless steel,
Stainless steel



PLA

 Flat magnet, Flat
magnet with threaded
hole



B

Steel bevel gear, 1:1



BPH

Ball transfer unit plain
fit, High



TBEBASE

Base plate for
economic mini-table,



DIA

Ring operated locking
bolt, with ring

Complementary products