


- Polished finish
- Fixed by 8 screws (not supplied)
- Material: stainless steel 304

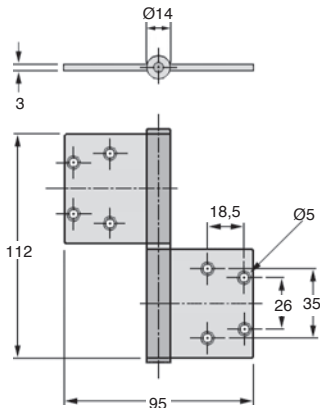

DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	Description	Stock*	Price each 1 to 5
CHA-GC-14/SS	Centred hinged plates	✓	41,48 €

*Depending on availability - Dimensions in mm

Our other products



HW_HT
Half-rail guide, Wheel



RURp
Fixed castor with plate, Polyurethane - Aluminium rim (Free running)



BTE
Universal tension arm, For standard applications



G-ECO
Eco range Spur gear, Steel C45



ASL
45° Hoist ring for welding, for 45° lifts - for welding



DTR
Chain idler sprocket, Chain idler sprocket - Plastic



BPPE
Ball transfer unit push fit, Light



CHM75
Worm and wheel gear reducer, up to 298 Nm



TBbutee
Axial thrust bearing, Steel balls



BOX-CS
Hose clamp, Box set of steel hose clamps



CLM
Male clevis end, Steel short



PSG3
Spur gear - precision range, Case hardened steel 20NCD2

Complementary products



CHA_GC_9SS
Stainless steel garnet hinge, To be welded



CHA_GC_9SS
Stainless steel garnet hinge, To be welded



CHAGC-AL
Screw-in garnet hinge, Screw-on