


- Polished finish
- Fixed by 8 screws (not supplied)
- Material: stainless steel 304

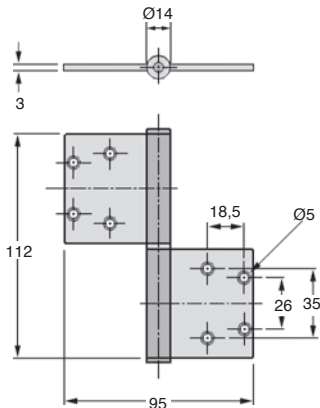


### DISCOUNTS

 Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	Description	Stock*	Price each 1 to 5
CHA-GC-14/SS	Centred hinged plates	✓	41,48 €

\*Depending on availability - Dimensions in mm

## Our other products



RPP8

RPP heavy duty timing belt, RPP8



RJA00\_28

Sealing strip, Clipping



CPAS-H

Folding bracket, For heavy loads



SVR20

Screwjack with travelling nut, with moving nut



LINK64

Synchronous AC Motor and- gearbox , from 1.3 to 6Nm



PW\_PWG05

Worm - precision range, Steel



EBH

Cap nut Hygienic Design®, With collar



INS150

Self tapping insert with collar-coarse thread, With collar-coarse t...



SBS\_L

Chain link, Stainless steel



PSG35

Spur gear - precision range, Stainless steel



BSP

Compact precision slide, from 156 N to



DIA

Ring operated locking bolt, with ring

## Complementary products



CHA\_GC\_9SS

Stainless steel garnet hinge, To be welded



CHA\_GC\_9SS

Stainless steel garnet hinge, To be welded



CHAGC-AL

Screw-in garnet hinge, Screw-on