


- Polished finish
- Fixed by 8 screws (not supplied)
- Material: stainless steel 304

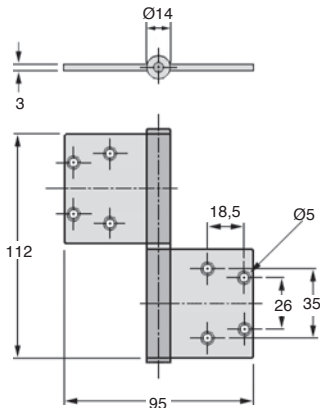

## DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	Description	Stock*	Price each 1 to 5
CHA-GC-14/SS	Centred hinged plates	✓	41,48 €

\*Depending on availability - Dimensions in mm

## Our other products




AT5-10ECO

AT type timing pulley,  
Economy range - AT5  
aluminium



DB

Steel bevel gear, 2:1

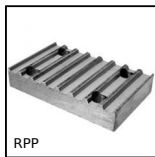

RPP

Connecting plate for  
RPP type timing belts,  
RPP14



PSG1HC

Skive hobbed spur  
gears - precision  
range, Case hardened  
steel 20NCD2



BAC105

Storage bin, 8mm



PSG25

Spur gear - precision  
range, Case hardened  
steel 20NCD2



BOX-TOR-ORFS

Box set of Nitrile O-  
rings NBR90Sh A, 7.65  
x 1.78mm to 37.82 x  
1.78



CHT

Asynchronous AC  
motor 0.12 to 0.22kW,  
0.12 to 0.22kW



PNA\_R

PERIFLEX elastic  
coupling,  
Replacement tyre



MHX

Hexagonal threaded  
sleeve, Hexagonal -  
stainless steel



BABV

Ball lock pins lockable  
, Stainless steel



DER71

Stainless steel AC  
asynchronous motor  
0.25 à 0.37kW, 0.25  
to 0.37kW

## Complementary products



CHA\_GC\_9SS

Stainless steel garnet  
hinge, To be welded



CHA\_GC\_9SS

Stainless steel garnet  
hinge, To be welded



CHAGC-AL

Screw-in garnet  
hinge, Screw-on