


Weld-on

CHAGC_{SS} CHAGD_{SS}

- To be welded
- Materials:
Body: stainless steel 316
Pin: stainless steel


Advantage

- Allows easy removal of the opening part

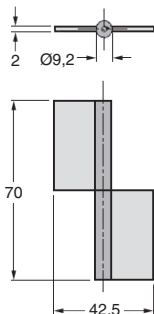

CHA-GC

stainless steel
centred hinge plates

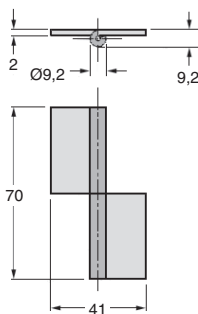

CHA-GD

stainless steel
offset hinge plates

DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	Description	Stock*	Price each 1 to 5
CHA-GC-9/SS	Centred hinge plates	✓	19,30 €
CHA-GD-9/SS	Offset hinge plates	✓	18,53 €

*Depending on availability - Dimensions in mm

Our other products



TB8

Cylindrical roller thrust bearing, Steel




MDB_MTB

Moulded plastic bevel gear (nylon), 2:1



CAP882

Flexible slat top chain acetal, Large range 882

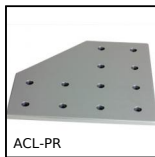

ACL-PR

Joining plate for aluminium profile, Right angled connection



HLC28

Right angle spiro bevel gearbox, Up to 182Nm



 
ACL-PLAngle

Joining plate for aluminium profile, Angle connection



CLLCLLP

Clevis components, long version, Steel - long range



RPP3

RPP heavy duty timing belt, RPP3



CHAE3030PA

Square decorative screwed hinges, Polyamide



PRF4545_P

Stripp Aluminium profile with extendable slot, 45 x



LF

Precision locknut, Precision locknut



AT5M_AT10M

AT type timing belt per metre, AT10 Steel cored polyurethane

Complementary products



CHA_GC_14SS

Stainless steel garnet hinge, To screw



CHA_GC_9SS

Stainless steel garnet hinge, To be welded



CHAGC-AL

Screw-in garnet hinge, Screw-on



CHAGC-AL

Screw-in garnet hinge, Screw-on