


Weld-on

CHAGCss CHAGDss

- To be welded
- Materials:
Body: stainless steel 316
Pin: stainless steel


Advantage

- Allows easy removal of the opening part

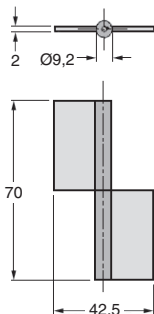

CHA-GC

stainless steel
centred hinge plates

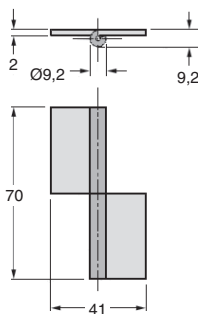

CHA-GD

stainless steel
offset hinge plates

DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	Description	Stock*	Price each 1 to 5
CHA-GC-9/SS	Centred hinge plates	✓	19,30 €
CHA-GD-9/SS	Offset hinge plates	✓	18,53 €

*Depending on availability - Dimensions in mm

Our other products



PTA150

Articulated levelling foot, pressed base Ø150, Ø 150



DFG

Flat suction cup, nitrile



KITbuh

24V DC motorisation kit, Planetary gears



PRF4532

Standard aluminium profile, 45 x 32 mm



B3PAN

Panamech, Multi-Beam stainless steel, Stainless steel - with clampin...



HTD3M_09

HTD Heavy duty timing pulley, HTD3 Aluminium



NK40

Drylin®N miniature guiding system, Withd 40 mm



D-PAR_SS

Stainless steel progressive stop, stainless steel



HW_HT

Half-rail guide, Rail



ACLCHARJ

Hinge for aluminium profile, Adjusts in 2



CHT

Asynchronous AC Motor, 0.55 to 1.1kW



DOMI50

Accessories, Plate

Complementary products



CHA_GC_14SS

Stainless steel garnet hinge, To screw



CHA_GC_9SS

Stainless steel garnet hinge, To be welded



CHAGC-AL

Screw-in garnet hinge, Screw-on



CHAGC-AL

Screw-in garnet hinge, Screw-on