

Heavy duty plastic hinge, opens 180°

 

Polyamide

CHA

- Screw fixed hinge
- Maximum opening: 180°
- Materials:
 - Black polyamide
 - Nickel plated steel pin

Applications

- Industrial bodywork

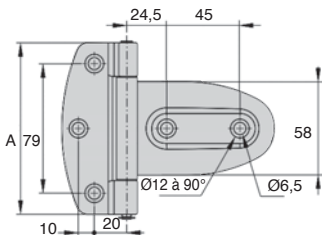


DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request


Part number	A	B	C	ØD	Weight (g)	Price each 1 to 5
CHA108-131	108	131	9,5	6	98	25,34 €

*Depending on availability - Dimensions in mm

 Our other products



 Worm and wheel set,
Machined plastic
(delrin)



Telescopic drawer
runners for groove
mounting, Partial
extension



Hexagonal nut
DIN934, Brass



Self locking counter
nut, For axial locking



Idler chain sprocket,
For hostile
environments



Female rod ends,
Stainless steel / PTFE



Connecting kits, XZ
linking kit



Igubal® flange
bearing, Polymer



Female eye bolt
conforms to DIN582,
Steel



Flat gripping magnet,
Flat holding magnet



Tools Hygienic Usit®
and Hygienic
Design®, Protective



Vertical toggle clamp,
Vertical toggle clamp /
vertical foot

Complementary products