


- Universal hinge for nested door
- 180° opening
- Nut fixing
- Molded hinge
- Materials:
  - Die cast zinc
  - Stainless steel molded anchors
  - Stainless steel pin

### Advantages

- Beautiful finish

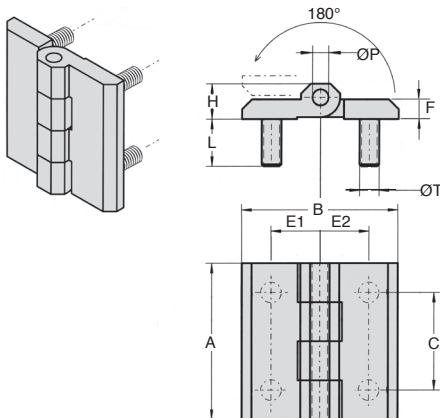

### DISCOUNTS

|       |      |     |      |            |
|-------|------|-----|------|------------|
| Qty   | 1+   | 6+  | 20+  | 50+        |
| Disc. | List | -5% | -10% | On request |

| Part number                         | A  | B  | C  | E1   | E2   | H    | F | ØT | L  | ØP | Stock* | Price each<br>1 to 5 |
|-------------------------------------|----|----|----|------|------|------|---|----|----|----|--------|----------------------|
| <b>Square hinge</b>                 |    |    |    |      |      |      |   |    |    |    |        |                      |
| CHA1056-U4                          | 40 | 40 | 25 | 12,5 | 12,5 | 9    | 5 | M5 | 12 | 4  | ✓      | 17,27 €              |
| CHA1056-U8                          | 50 | 50 | 30 | 15   | 15   | 11,5 | 6 | M6 | 15 | 6  | ✓      | 17,15 €              |
| CHA1056-U12                         | 60 | 60 | 36 | 18   | 18   | 15   | 8 | M8 | 14 | 8  | -      | 22,70 €              |
| <b>Rectangular hinge</b>            |    |    |    |      |      |      |   |    |    |    |        |                      |
| CHA1056-U16                         | 50 | 76 | 30 | 28   | 28   | 11   | 6 | M6 | 12 | 6  | ✓      | 30,07 €              |
| <b>Asymmetric rectangular hinge</b> |    |    |    |      |      |      |   |    |    |    |        |                      |
| CHA1056-U20                         | 60 | 90 | 36 | 18   | 45   | 15   | 8 | M8 | 14 | 8  | ✓      | 32,24 €              |

\*Depending on availability - Dimensions in mm


## Our other products



CHA138  
Screwed hinge with threaded insert, 138 degrees



Q7  
Angular contact ball bearing, Steel

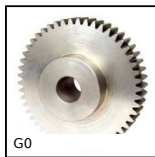


G0  
Steel spur gear, Steel 20NCD2



INStool  
Insertion tool for self tapping inserts, Insertion tool



CHA35  
Hinge for aluminium profile, Hinge

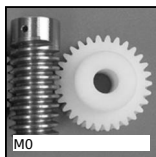

M0  
Worm and wheel set, Machined plastic (delrin)



GLT3-46  
Telescopic drawer,



PT880  
Drive sprocket for slat top chain, Range 880



AT10-25ECO  
AT type timing pulley, Economy range - AT10 aluminium



BAP  
Plastic clamping collar, Ø10 - Ø20



NTM  
Nylon tipped set screw, Nylon-point



TUBE25\_25  
Square Tube, Aluminium or Stainless steel

## Complementary products