

Polyamide face-mounted hinge ★★★ Stock

CHAUPA




Opening up to 270°

- **Universal hinge for nested door**
- 270° opening
- Fixing with M5 or M6 countersunk screws according to DIN7991
- Molded hinge
- Materials:
 - Black polyamide
 - Stainless steel pin

Advantages

- Beautiful finish

With countersunk holes

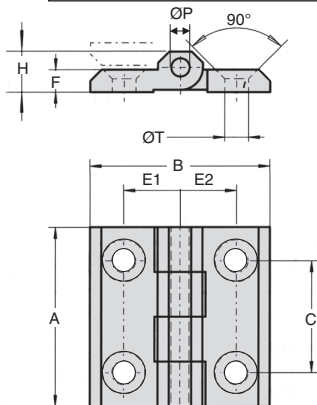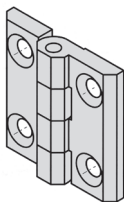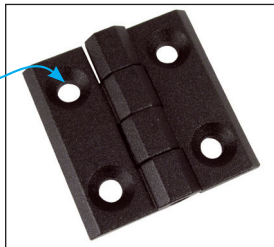

DISCOUNTS


Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	E1	E2	H	F	ØT	ØP	Stock*	Price each 1 to 5
Square hinge											
CHA1056-U6PA	40	40	25	12,5	12,5	9	5	5,3	4	✓	9,21 €
CHA1056-U10PA	50	50	30	15	15	11,5	6	6,2	6	✓	10,72 €

*Depending on availability - Dimensions in mm



- Universal hinge for nested door
- 270° opening
- Fixing with M5, M6 or M8 countersunk screws according to DIN7991
- Molded hinge
- Materials:
 - Die cast zinc
 - Stainless steel pin

With countersunk holes

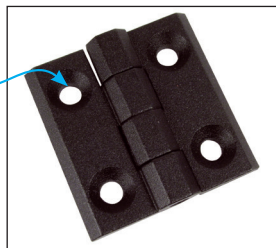

Advantages

- Beautiful finish

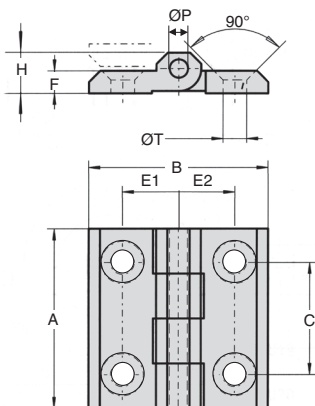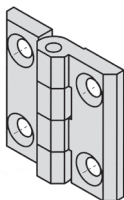

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	E1	E2	H	F	ØT	ØP	Stock*	Price each 1 to 5
Square hinge											
CHA1056-U6	40	40	25	12,5	12,5	9	5	5,3	4	✓	12,32 €
CHA1056-U10	50	50	30	15	15	11,5	6	6,2	6	✓	12,83 €
CHA1056-U14	60	60	36	18	18	15	8	8,3	8	✓	16,03 €
Rectangular hinge											
CHA1056-U18	50	76	30	28	28	11	6	6,2	6	✓	30,73 €

*Depending on availability - Dimensions in mm

Stainless steel face-mounted hinge ★★★ Stock

CHAuss




With countersunk holes

- **Universal hinge for nested door**
- 270° opening
- Fixing with M5, M6, M8 countersunk screws according to DIN7991
- The visible surface is satin polished
- Molded hinge
- Materials:
Stainless steel 316

Advantages

- Beautiful finish

stainless steel version

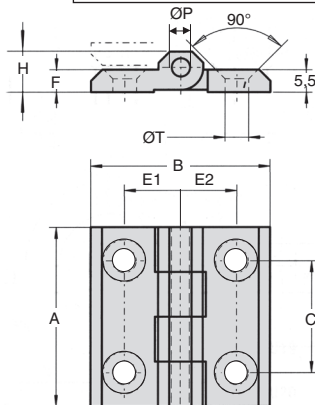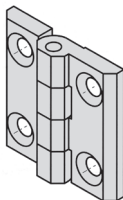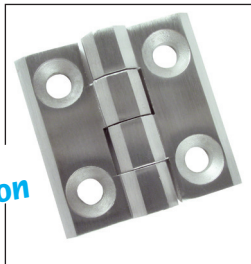

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-10%	On request	



Part number	A	B	C	E1	E2	H	F	ØT	ØP	Stock*	Price each 1 to 5
CHA1056-U6SS	40	40	25	12,5	12,5	9	5	5,3	4	✓	29,50 €
CHA1056-U10SS	50	50	30	15	15	11,5	6	6,2	6	✓	32,01 €
CHA1056-U14SS	60	60	36	18	18	15	8	8,3	8	✓	32,21 €

*Depending on availability - Dimensions in mm

- **Universal hinge for nested door**
- 180° opening
- Nut fixing
- Molded hinge
- **Materials:**
 - Die cast zinc
 - Stainless steel molded anchors
 - Stainless steel pin

Advantages

- Beautiful finish

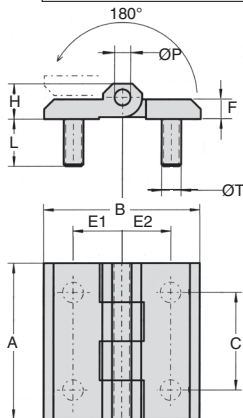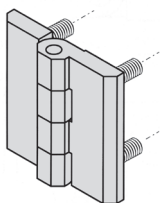

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	E1	E2	H	F	ØT	L	ØP	Stock*	Price each 1 to 5
Square hinge												
CHA1056-U4	40	40	25	12,5	12,5	9	5	M5	12	4	✓	17,27 €
CHA1056-U8	50	50	30	15	15	11,5	6	M6	15	6	✓	17,15 €
CHA1056-U12	60	60	36	18	18	15	8	M8	14	8	-	22,70 €
Rectangular hinge												
CHA1056-U16	50	76	30	28	28	11	6	M6	12	6	✓	30,07 €
Asymmetric rectangular hinge												
CHA1056-U20	60	90	36	18	45	15	8	M8	14	8	✓	32,24 €

*Depending on availability - Dimensions in mm




Molded polyamide face-mounted hinge ★★★ Stock

CHAUPA With anchors

- Universal hinge for plug door
- 180° opening
- Nut fixing
- Molded hinge
- **Materials:**
 - Black polyamide
 - Stainless steel molded anchors
 - Stainless steel pin

Advantages

- Beautiful finish

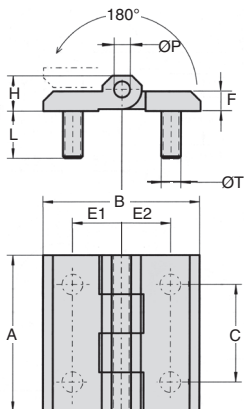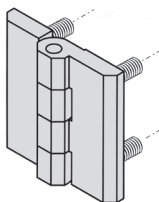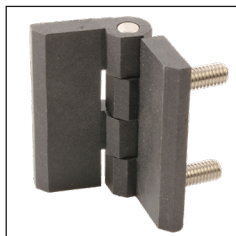

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	E1	E2	H	F	ØT	ØP	Stock*	Price each 1 à 5
Square hinge											
CHA1056-U4PA	40	40	25	12,5	12,5	9	5	M5	12	-	13,91 €
CHA1056-U8PA	50	50	30	15	15	11,5	6	M6	15	✓	15,24 €

*Depending on availability - Dimensions in mm

Our other products



FRss

Stainless steel thread inserts, Stainless steel



BLHB60

Right angled gearbox, bored shafts, up to 70 Nm



 
PLS

Cylindrical spacer, Stainless steel 303



SHW

Plain washer, Steel




MO

Worm and wheel set, Machined plastic (delrin)



SSHBRA

 Stainless steel bevel gear, 1,5:1 2:1 3:1



M1

Worm and wheel set, Machined plastic (delrin)



PSG25S

Spur gear - precision range, Stainless steel 316



PTAS0

Articulated levelling foot, pressed base



RNAS1

Cam follower without axial guide, Without



SLB

Indexing plunger, stainless steel



MRA_SS

Stainless steel Quick link, Staineless steel

Complementary products