


Polyamide face-mounted hinge ★★★ Stock

CHAUPA

Opening up to 270°



- Universal hinge for nested door
- 270° opening
- Fixing with M5 or M6 countersunk screws according to DIN7991
- Molded hinge
- Materials:
 - Black polyamide
 - Stainless steel pin

With countersunk holes

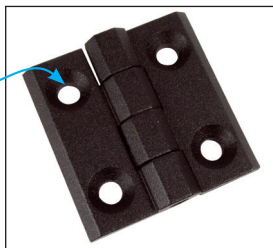

Advantages

- Beautiful finish

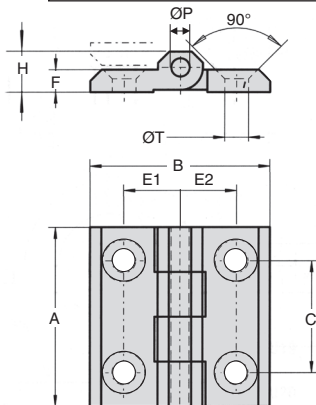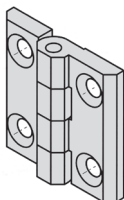

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	E1	E2	H	F	ØT	ØP	Stock*	Price each 1 to 5
Square hinge											
CHA1056-U6PA	40	40	25	12,5	12,5	9	5	5,3	4	✓	9,21 €
CHA1056-U10PA	50	50	30	15	15	11,5	6	6,2	6	✓	10,72 €

*Depending on availability - Dimensions in mm

HPC


WEB
04/2021

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel




- Universal hinge for nested door
- 270° opening
- Fixing with M5, M6 or M8 countersunk screws according to DIN7991
- Molded hinge
- Materials:
 - Die cast zinc
 - Stainless steel pin

With countersunk holes

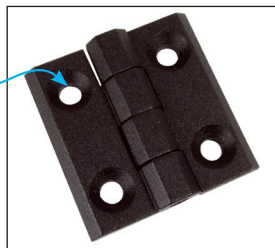

Advantages

- Beautiful finish

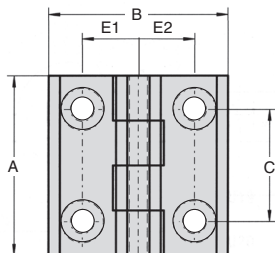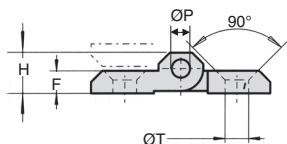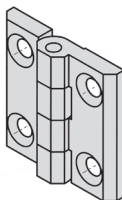

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	E1	E2	H	F	ØT	ØP	Stock*	Price each 1 to 5
Square hinge											
CHA1056-U6	40	40	25	12,5	12,5	9	5	5,3	4	✓	12,32 €
CHA1056-U10	50	50	30	15	15	11,5	6	6,2	6	✓	12,83 €
CHA1056-U14	60	60	36	18	18	15	8	8,3	8	✓	16,03 €
Rectangular hinge											
CHA1056-U18	50	76	30	28	28	11	6	6,2	6	✓	30,73 €

*Depending on availability - Dimensions in mm

Stainless steel face-mounted hinge ★★★ Stock

CHAuss




With countersunk holes

- **Universal hinge for nested door**
- 270° opening
- Fixing with M5, M6, M8 countersunk screws according to DIN7991
- The visible surface is satin polished
- Molded hinge
- Materials:
Stainless steel 316

Advantages

- Beautiful finish

stainless steel version

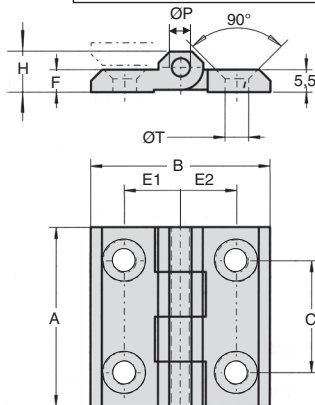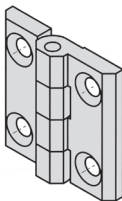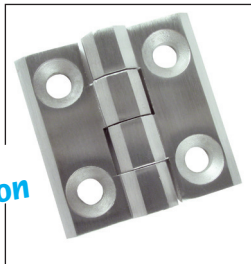

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-10%	On request	

Part number	A	B	C	E1	E2	H	F	ØT	ØP	Stock*	Price each 1 to 5
Square hinge											
CHA1056-U6SS	40	40	25	12,5	12,5	9	5	5,3	4	✓	29,50 €
CHA1056-U10SS	50	50	30	15	15	11,5	6	6,2	6	✓	32,01 €
CHA1056-U14SS	60	60	36	18	18	15	8	8,3	8	✓	32,21 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2021



www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

- **Universal hinge for nested door**
- 180° opening
- Nut fixing
- Molded hinge
- Materials:
 - Die cast zinc
 - Stainless steel molded anchors
 - Stainless steel pin

Advantages

- Beautiful finish

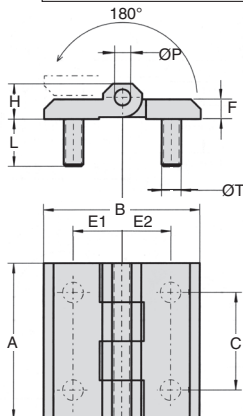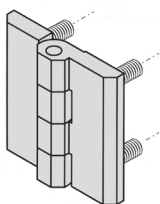

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	E1	E2	H	F	ØT	L	ØP	Stock*	Price each 1 to 5
Square hinge												
CHA1056-U4	40	40	25	12,5	12,5	9	5	M5	12	4	✓	17,27 €
CHA1056-U8	50	50	30	15	15	11,5	6	M6	15	6	✓	17,15 €
CHA1056-U12	60	60	36	18	18	15	8	M8	14	8	-	22,70 €
Rectangular hinge												
CHA1056-U16	50	76	30	28	28	11	6	M6	12	6	✓	30,07 €
Asymmetric rectangular hinge												
CHA1056-U20	60	90	36	18	45	15	8	M8	14	8	✓	32,24 €

*Depending on availability - Dimensions in mm

Molded polyamide face-mounted hinge



CHAUPA

With anchors

- Universal hinge for plug door

- 180° opening

- Nut fixing

- Molded hinge

- **Materials:**




Black polyamide

Stainless steel molded anchors

Stainless steel pin

Advantages

- Beautiful finish

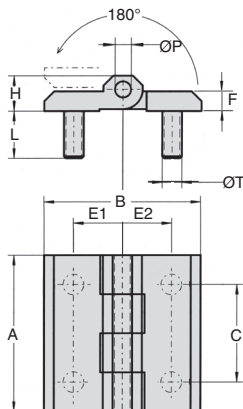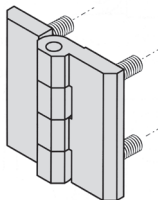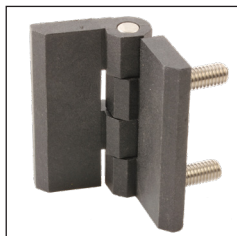

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	E1	E2	H	F	ØT	ØP	Stock*	Price each 1 à 5
Square hinge											
CHA1056-U4PA	40	40	25	12,5	12,5	9	5	M5	12	-	13,91 €
CHA1056-U8PA	50	50	30	15	15	11,5	6	M6	15	✓	15,24 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2021

 
www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



MDB_MTB
Moulded plastic bevel gear (nylon), 3:1



H1
Crossed helical gear
crossed axis at 90°,
Machined plastic
(delrin)




ZAmm
Shaft for linear
guides, Hardened
ground steel




CHT
Asynchronous AC
Motor 1.1 to 1.85kW,
1.1 to 1.85kW




PRF_BR
Clamp for aluminium
profile, Clamp for
profile

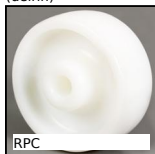

RPC
Wheel, Polyamide

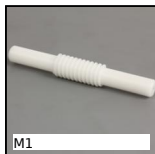

M1
Worm and wheel set,
Machined plastic
(delrin)

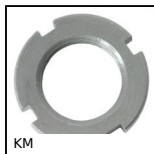

KM
Bearing locknut,
Locknut KM




ZBconique
Machined plastic
bevel gear, 1:1



UCFL
Cast iron flanged
bearing, Cast iron



SEV
Vertical stirrup toggle
clamp, Vertical Latch
Clamp - steel

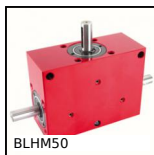

BLHM50
Right angled gearbox,
double output shafts,
up to 30 Nm

Complementary products