

Bolt-on hinge



CHA

Opens to 135°




- Element for square tube structure
- Face frame hinge
- Materials:
Hinge: reinforced polyamide
Pin: zinc plated steel

Info.

- Not sold individually, please contact us for details

Accessories

- Magnetic lock **SER**
- Doorstop **BLOC**
- Manual lock **LOQ**

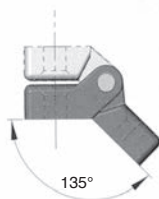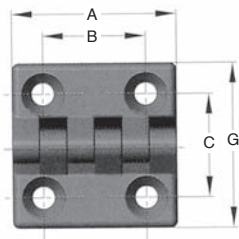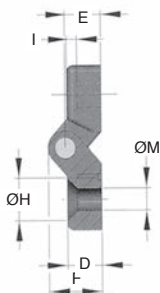

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	A	B	C	D	E	F	G	ØH	I	ØM	Stock*	Price each 1 to 49
CHA135-48	48	30	30	10	10	15	48	13,5	3,0	6,5	✓	5,22 €
CHA135-64	64	40	40	13	13	19	64	13,5	3,0	6,5	✓	7,01 €
CHA135-96	96	60	63	16	17	24	96	16,0	4,6	8,0	✓	9,16 €

*Depending on availability - Dimensions in mm

Our other products



Moulded plastic bevel gear (nylon), 1:1



Brush strip per meter horsehair fibres Ø0.2, Black horsehair



Double universal joint eco series, Low duty



 
Horizontal hook toggle clamp, Horizontal Hook clamp - steel




Masterplate® glueable insert rectangular, rectangular with




Hexagonal spacer, Brass



 Automatic chain tensioner, With 180° guide



 
Worm and wheel gear reducer, up to 164 Nm



Articulated levelling foot, pressed base Ø150, Ø 150



 Sliding nut, For T slot



Steel bevel gear, 1:1



Manually tightened wing nut DIN315, Brass DIN 315

Complementary products



Doorstop, Doorstop



Magnetic doorstop for aluminium profile, Magnetic doorstop