

# Bolt-on hinge



## CHA

## Opens to 135°




- Element for square tube structure
- Face frame hinge
- Materials:  
Hinge: reinforced polyamide  
Pin: zinc plated steel

### Info.

- Not sold individually, please contact us for details

### Accessories

- Magnetic lock **SER**
- Doorstop **BLOC**
- Manual lock **LOQ**

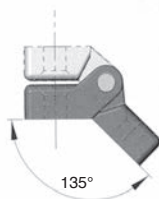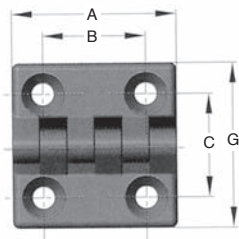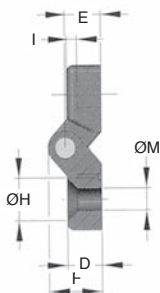

### DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	A	B	C	D	E	F	G	ØH	I	ØM	Stock*	Price each 1 to 49
CHA135-48	48	30	30	10	10	15	48	13,5	3,0	6,5	✓	5,22 €
CHA135-64	64	40	40	13	13	19	64	13,5	3,0	6,5	✓	7,01 €
CHA135-96	96	60	63	16	17	24	96	16,0	4,6	8,0	✓	9,16 €

\*Depending on availability - Dimensions in mm

## Our other products



SLB  
Indexing plunger,  
steel class 5.8



HSE-HSB  
Hexagonal spacer,  
Brass



CHA135  
Screwed hinge, 135  
degrees



VDS  
Sliding lock  
adjustment system,  
Sliding lock for oblong  
hole



AKN  
Bellows coupling  
Gerwah®, from 22 to  
180Nm



H2  
Crossed helical gear  
crossed axis at 90°,  
Steel 20NCD2



MFB\_MHB  
Moulded plastic bevel  
gear (nylon), 4:1



PHG05  
Parallel axis helical  
gear - Precision range,  
20NCD2 case  
hardened s...



G-ECO  
Eco range Spur gear,  
Steel C45



PRFSRAD  
Dual lock for  
aluminium profile,  
Quick fitting, self



AC156-157  
Strike for toggle latch,  
25.5mm



SCR  
Suction cup threaded  
insert, Adaptator for  
insert

## Complementary products



BLOC  
Doorstop, Doorstop



SER  
Magnetic doorstop for  
aluminium profile,  
Magnetic doorstop