

Opens to 138°

CHA



- Element for square tube structure
- Face frame hinge
- Materials:
Hinge: reinforced polyamide
Pin: zinc plated steel
Inserts: brass

Info.

- Not sold individually, please contact us for details

Accessories

- Magnetic lock **SER**
- Doorstop **BLOC**
- Manual lock **LOQ**

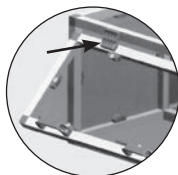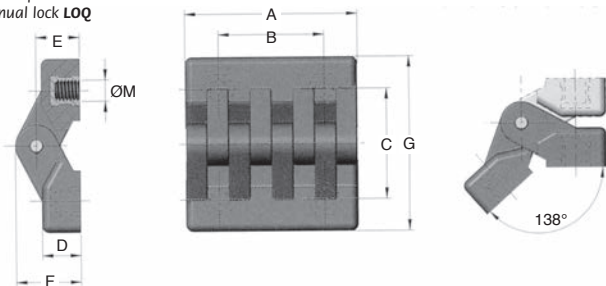

Typical application

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty | 1+ | 50+ | 100+ |
| Disc. | List | -5% | On request |

| Part number | A | B | C | D | E | F | G | ØM | Stock* | Price each 1 to 49 |
|--------------|----|----|----|----|----|----|----|----|--------|-----------------------|
| CHA138-49-M5 | 49 | 30 | 32 | 11 | 13 | 19 | 49 | M5 | - | 18,39 € |
| CHA138-49-M6 | 49 | 30 | 32 | 11 | 13 | 19 | 49 | M6 | ✓ | 18,39 € |

*Depending on availability - Dimensions in mm

Our other products



ATZYSS
Stainless steel diablo shaped elasto mount,
Stainless steel



SA_SAKH
Housing for linear bearing, Closed - light load



UGPC
Actuator guide kit,
Short bearing



CHINV
Invisible hinge,
Invisible - Opening up to 90°



DOMI80
Accessories, Fixing kit



TCC_SS
Stainless steel rigging screw (hook/hook),
Stainless steel



RAGFLOW
Floway2® roller track,
Roller track



BAN
Angular clamp,
Universal



V3RA_PTR
3-spoked handwheel
with foldable handle,



LRX
Linear roller slide, Rail
- from 9410 N to



CDPC
Flanged drill bushing,
Steel



PRF_JL5
Lip seal for panel,
Door seal - Ø 5mm

Complementary products



BLOC
Doorstop, Doorstop



SER
Magnetic doorstop for
aluminium profile,
Magnetic doorstop