

Opens to 138°

CHA



- Element for square tube structure
- Face frame hinge
- Materials:
Hinge: reinforced polyamide
Pin: zinc plated steel
Inserts: brass

Info.

- Not sold individually, please contact us for details

Accessories

- Magnetic lock **SER**
- Doorstop **BLOC**
- Manual lock **LOQ**

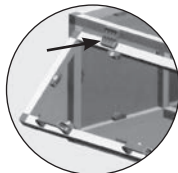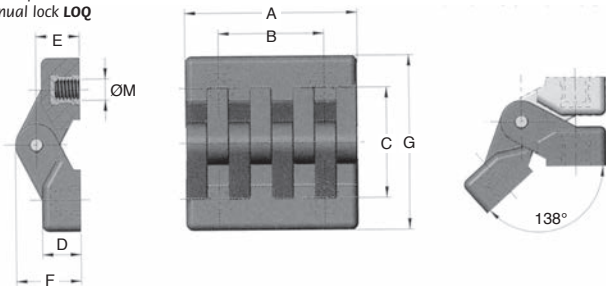

Typical application

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	A	B	C	D	E	F	G	ØM	Stock*	Price each 1 to 49
CHA138-49-M5	49	30	32	11	13	19	49	M5	-	18,39 €
CHA138-49-M6	49	30	32	11	13	19	49	M6	✓	18,39 €

*Depending on availability - Dimensions in mm

Our other products



CLG3

Moulded plastic spur gear, Moulded plastic (nylon)



BL15

Right angled gearbox, from 1.10 to 6 Nm



BSPM

Miniature ballscrew, Nut+rolled ballscrew



BAGSS

Stainless steel Clamping collar, Stainless steel



SLV

Vertical toggle clamp, Vertical Lever Clamp - stainless steel



NT122

Spur gear coaxial gearbox, from 32 to 85 Nm - In-line



E30

Right angle helical reducers, from 1.50 to 9 Nm



BEAS

Star shaped anti-static handle, Star, anti-static



PRS30

Stainless steel articulated foot Ø30,



ZDB

Machined plastic bevel gear, 2:1



HRV

V-rail guidance Simple Select®



T5_11

T type timing pulley, T5 aluminium

Complementary products



BLOC

Doorstop, Doorstop



SER

Magnetic doorstop for aluminium profile, Magnetic doorstop